

Surface Mount Soldering Practice Kit (with 135 SMD parts)

Product Highlights

RoHS 3 Compliant

Immersion Gold PCB Finish

Comes with 135 SMD parts to assemble

Description

Great for training, educational classroom use, or learning at home.

Includes PCB and 135 surface mount parts


Specifications

PCB construction:

PCB operating temperature range:

PCB reflow maximum temperature:

PCB dimensions:

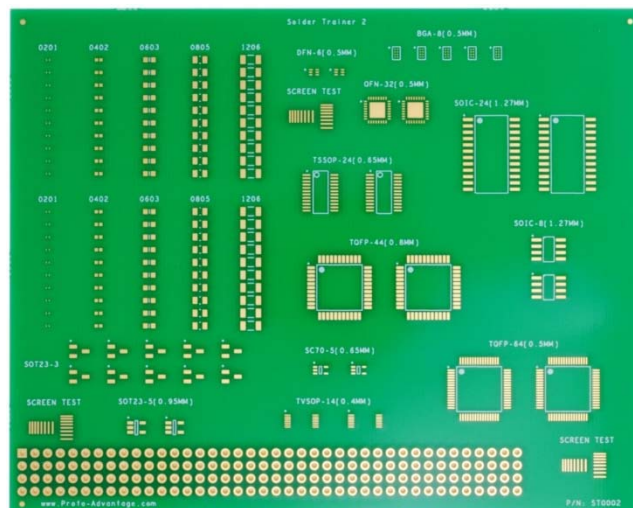

FR-4 UL94V-0

-40°C to +130°C

+260°C

5" x 4" x 0.063"

Parts included:

20x 0201

20x 0402

20x 0603

20x 0805

20x 1206

10x SOT23-3 (0.95mm pitch)

5x BGA-8 (0.5mm pitch)

2x SOIC-8 (1.27mm pitch)

2x SOIC-24 (1.27mm pitch)

2x SOT23-5 (0.95mm pitch)

2x SC70-5 (0.65mm pitch)

2x DFN-6 (0.5mm pitch)

2x TVSOP-14 (0.4mm pitch)

2x TSSOP-24 (0.65mm pitch)

2x QFN-32 (0.5mm pitch)

2x TQFP-44 (0.8mm pitch)

2x TQFP-64 (0.5mm pitch)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Chip Quik:

ST0002