

## FP-2S-2

### MicroGripper - 0.5mm to 0.2mm Lead Pitch

#### Features


- Used with SMT packages down to 0.2mm lead pitch
- Thin clip body width allows many lead Grippers to be mounted side-by-side for simultaneous testing
- Maximum frequency is 100MHz



#### SPECIFICATIONS

Temperature Range:	0-70°C
Conductor Resistance:	60 mOhms
Contact Resistance:	10 mOhms
Tines Diameter:	0.08mm
Body Height:	14mm
Body Material:	ABS
Voltage Usage:	+/-40V
Rating:	500 WVDC
Bandwidth:	(3db) >100MHz
Inductance:	< 1mH @ 1KHz
Capacitance:	< 2.0pF @ 1KHz
Material:	Steel wire or stainless steel, Nickel-plated

#### DIMENSIONS

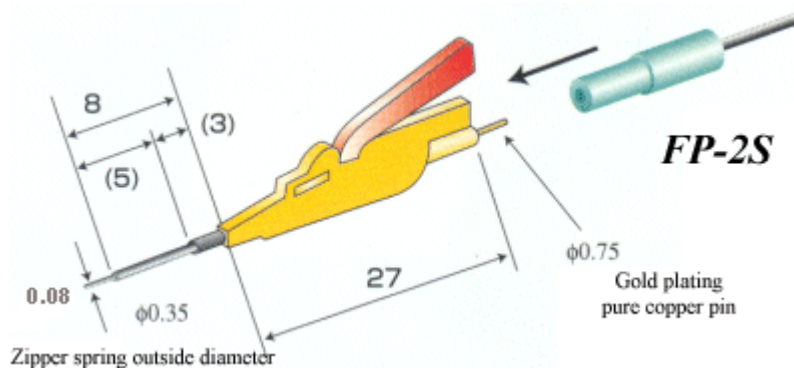

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Chip Quik:

FP-2S-2