

## FP-LA1C-10

### MicroGripper - 1.25mm to 0.3mm Lead Pitch

#### FEATURES


- New low-cost MicroGripper
- Multi-colored Grippers
- Conductor Resistance 40 mOhms
- Flexible stand wires included with each package of 10



#### SPECIFICATIONS

Temperature Range:	0-70°C
Conductor Resistance:	40 mOhms
Contact Resistance:	10 mOhms
Accessible Lead Pitch:	1.25mm-0.3mm
Tines Diameter:	0.15mm
Body Height:	7mm
Body Material:	ABS
Voltage Usage:	+/-40V
Rating:	500 WVDC
Bandwidth:	(3db) >100MHz
Inductance:	< 1mH @ 1KHz
Capacitance:	< 2.0pF @ 1KHz
Barrel Width:	0.5mm
Width of Lead to Be Gripped:	0.7mm
Cord Length:	200mm
Material:	Steel wire or stainless steel, nickel-plated

#### DIMENSIONS

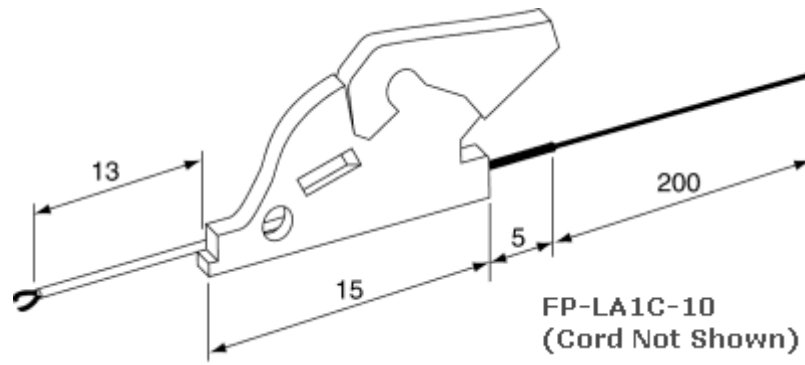

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Chip Quik:](#)

[FP-LA1C-10](#)