




NthDegree






PRINTING THE IMPOSSIBLE™

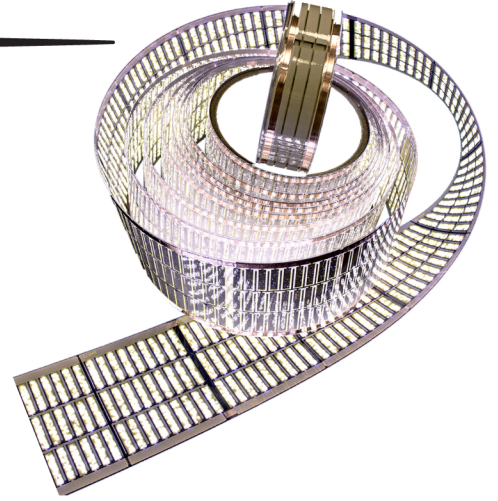

Input Voltage Max.	12 VDC
Current (A)	.450
Power (W)	5.4
Dimmable	Yes
Efficacy (lm/W)	40.0
Test Size (W) x (L)	63.5mm. x 305mm. / 2.5" x 12"
Thickness	.045cm. ± .017 / 0177in. ± .007
Operating Temperature	-40 ~ 80°C / -40 ~ 176°F
Color Temp. (CCT)	5800K <i>avg.</i>
Color Accuracy (CRI)	76 <i>avg.</i>
Weight per Ft. Gram / Oz.	6.8g / .24oz.
Lumens per Gram / Oz.	0.17 lpg / .006 lpoz.
Lumens per Meter / Foot	131 / 40.0
Surface Brightness (cd/M²)	~5300

Nth-Light SL16-1018

- Exceptional Light Uniformity
- Low Glare & Shadowing
- Flexible
- Low Profile, Thin as .006"
- Lightweight
- Impact Resistant
- Cleanable Surface
- Low Power Consumption
- Easily Installed

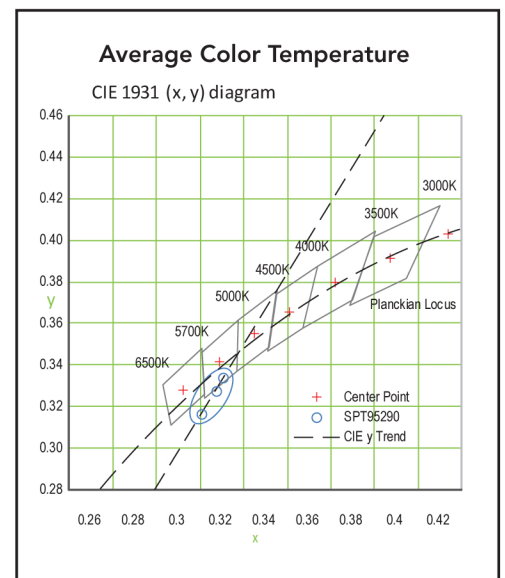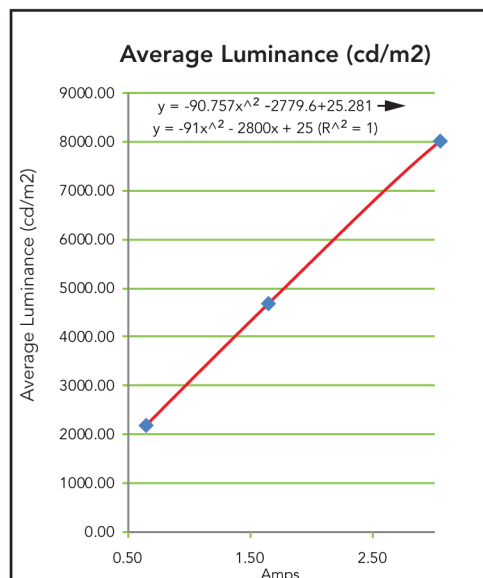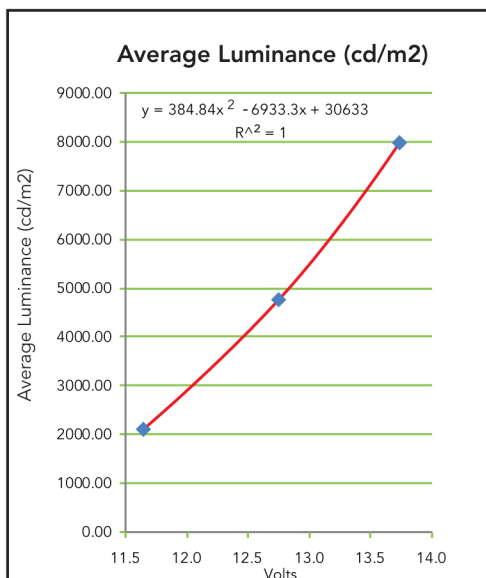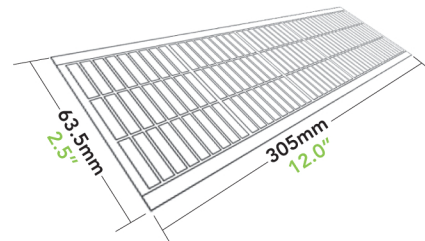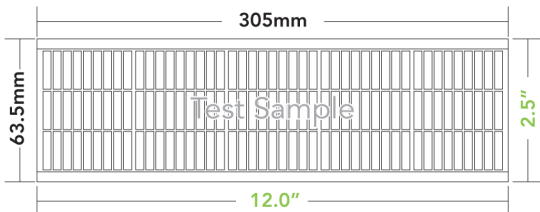

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adafruit:](#)

[3683](#)