




Ultra Thin Side View LED Digital Bar

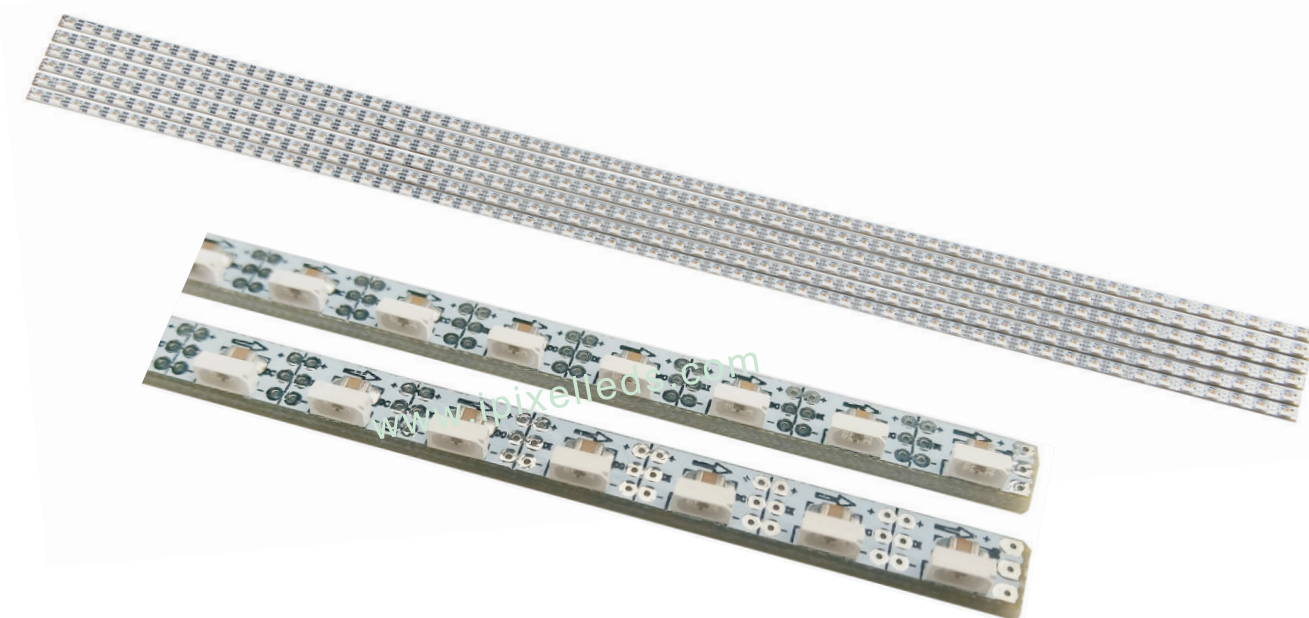


Product Description

This bar looks like the same as other ultra thin

board 5mm width but it included 60pcs side

view and addressable LED (SK6812 Side)

which means the board's thickness comes 3mm.

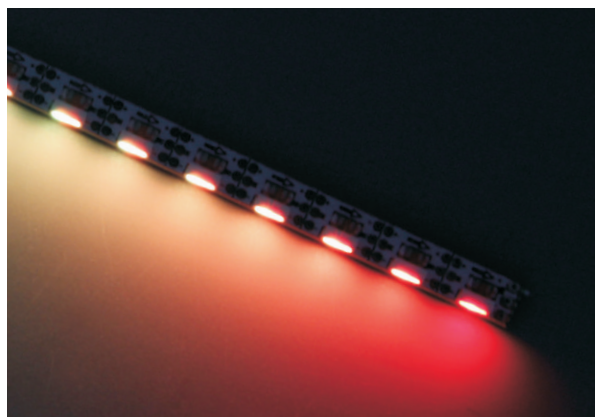

The bar's biggest feature is side light emitting.

Wow, look, it has a wide range of application

where don't have big gap to install the led strip,

now you have one more option.



Product Datasheet

Product	Number	B60SK6812SIDEV5		
Light	Source	SK6812SIDE		
Beam	Angle	120°		
LED	Quantity	60leds/pcs		
Size	(mm)	L 5000* W 5* H 4 mm		
Emitting	Color	Full color		
Operating	Voltage	DC5V		
Power	(W)	15w/m		
Control	(IC)	SK6812		
Waterproof	Rating	IP20		
Luminance(MCD)		R:90000mcd	G:132000mcd	B:6000mcd
Wavelength		R:620-625nm	G:520-525nm	B:465-470nm

Application




1. Hotels, restaurants,nights clubs;

2. Back lighting; edge lighting;

3. Advertising signs, brightening;

4.Dancefloor background;

Outline Dimension

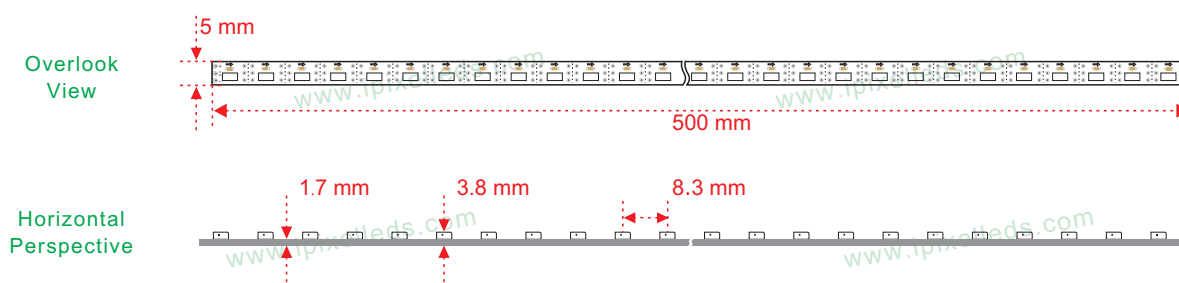

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adafruit:](#)

[3729](#)