






APA102 2020 SMD Rigid Bar

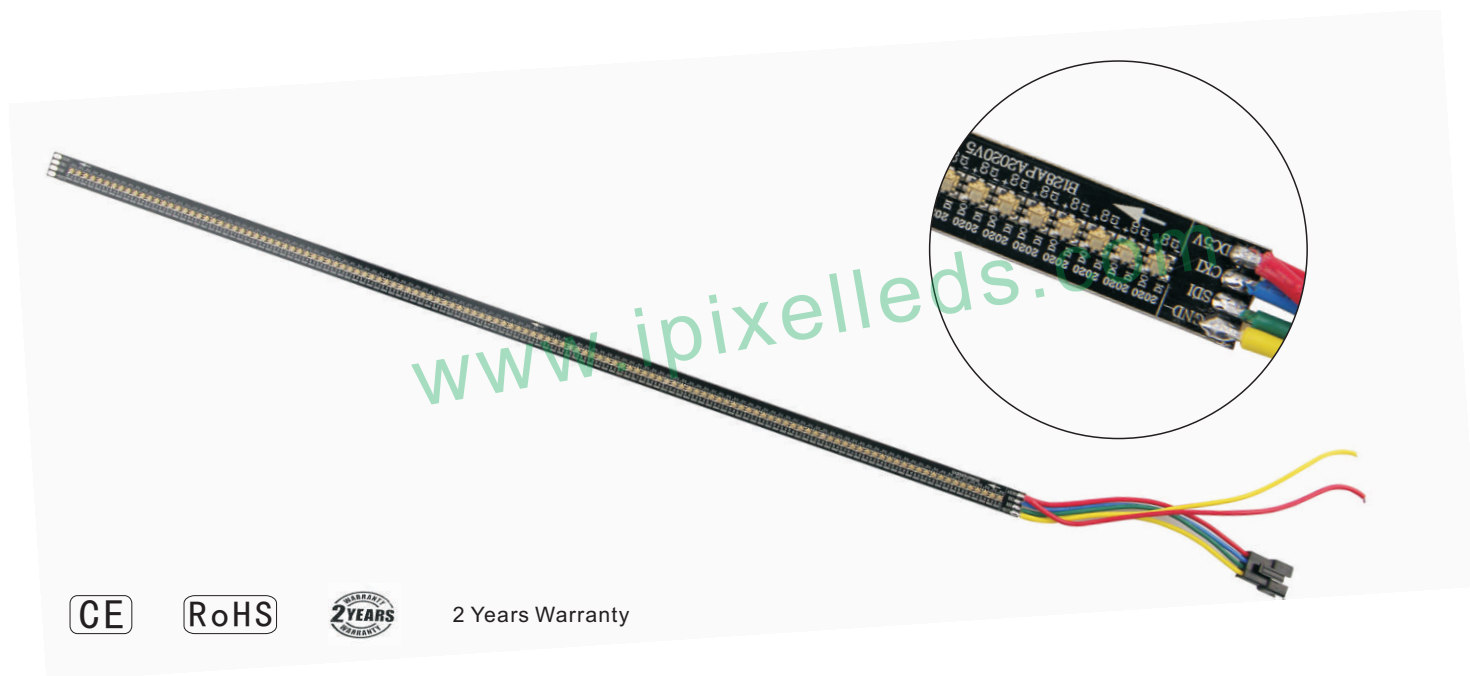

2 Years Warranty

Product Description

- The bar's biggest feature is lamp beads are very dense, brightness, no shadow.
- Pixel pitch approx 3mm for this rigid bar.
- Input DC5V, The power of the bar is about 17W.

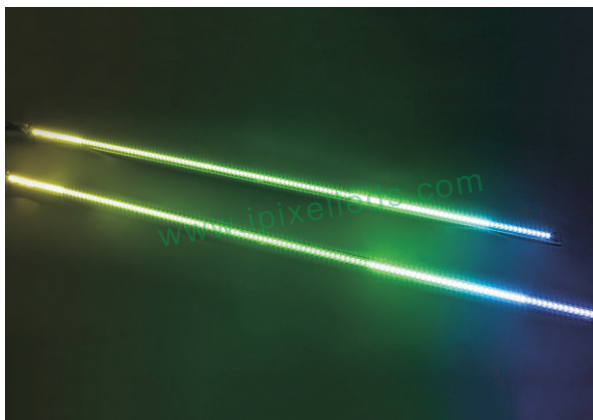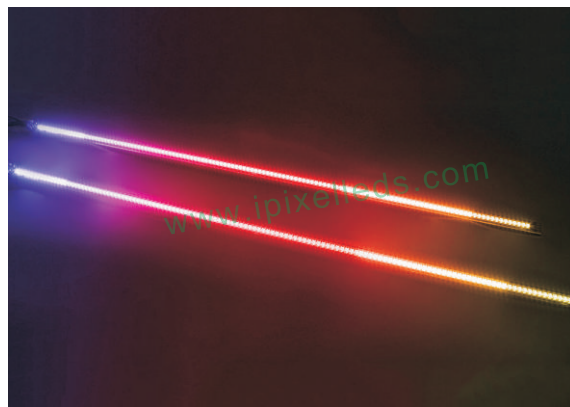

- The actual length approx 400mm, the leftover space (16mm)can be used for attaching cables.
- 10mm pcb wide would be great to dissipate heat.
- Ip20, non-waterproof



Product Datasheet

Product	Number	B128APA2020V5		
Light	Source	APA102-2020		
Beam	Angle	120°		
LED	Quantity	128leds/pcs		
Size	(mm)	L 384* W 10* H 1.5 mm		
Emitting	Color	Full color		
Operating	Voltage	DC5V		
Power	(W)	17w±0.5W/pcs		
Control	(IC)	APA102		
Waterproof	Rating	IP20		
Luminance(MCD/LED)		R:300-500mcd	G:500-850mcd	B:120-200mcd
Wavelength		R:619-626nm	G:520-535nm	B:465-475nm

Application



1. Hotels, restaurants, nights clubs.
2. Back lighting, edge lighting.
3. Advertising signs, brightening.
4. Dancefloor background.

Outline Dimension

Overlook View :



Horizontal Perspective :



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adafruit:](#)

[3776](#)