

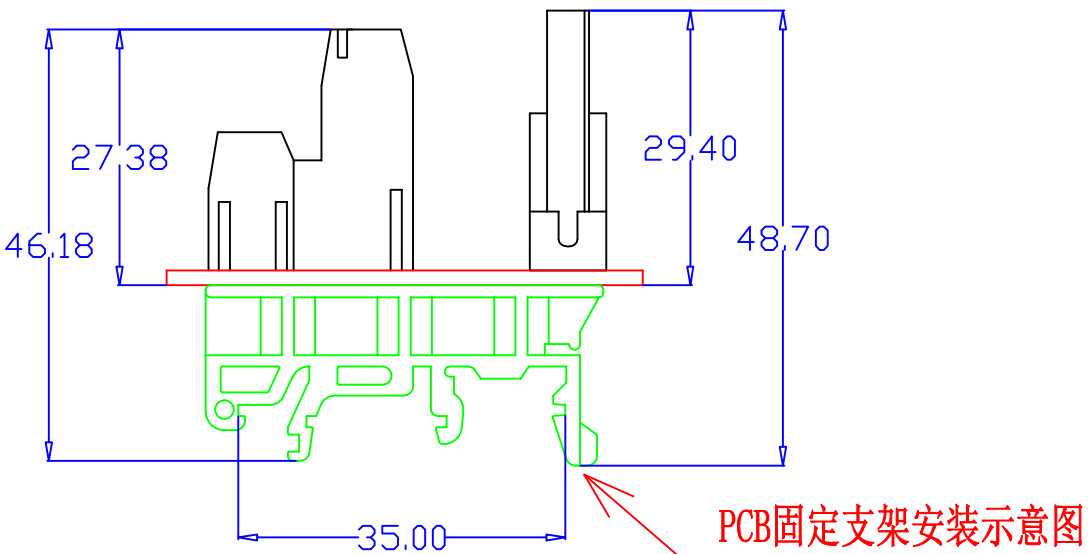


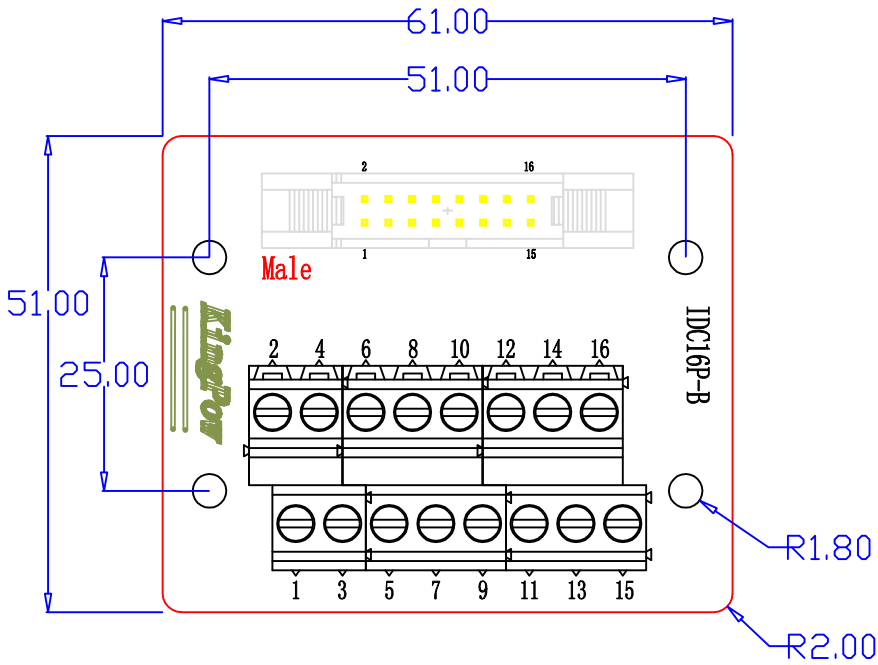

Pin number

背面引脚长度≤3mm

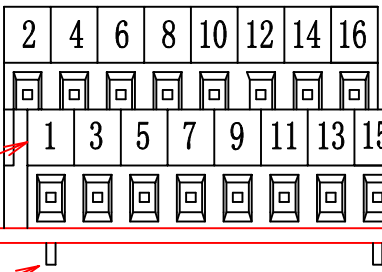

IDC16P转端子

B款


C45

优质端子

 
厂家直销 规格齐全

parameter table:

Num	Category	Describe
1	Max Current	0.8A
2	Cable gauge (AWG)	14-26 AWG
3	IDC Pitch:	Pitch:2.54mm
4	PCB Material	FR4
5	IDC Withstanding voltage	300V AC/MINUTE
6	IDC Operating temperature	-20℃ to 105℃
7	Rated voltage according to	UL:XXXXXX
8	Rated current according to	UL:XXXXXX
9	IDC Material:	INSULATOR:PBT 30%GF; CONTACT:COPPER ALLOY
10	Box size w/label	L90*W65*H44mm
11	Packing	

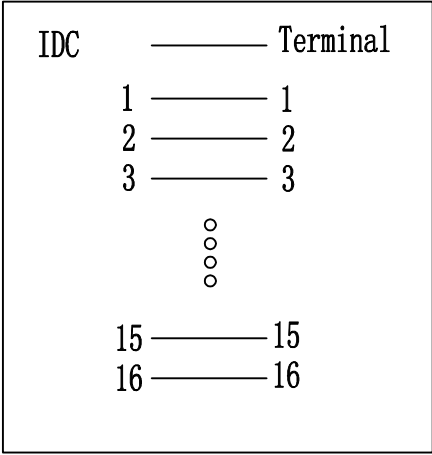

Pin assignment

制作	Hero. Xu		日期	2019. 11. 15		名称	端子台	型号	IDC16P-B			
审核						版本	Ver:1.0	客户编号				
核准												
							摄影角度	图纸比例	第 1 张 共 1 张			
未注线性公差GB1804-m级（单位mm）								1:1	中山市肯博电子科技有限公司 www.kingpow.cn			
尺寸	≤3	3-6	6-30	30-120	120-400	400-1000				1000-2000	2000-4000	角度公差 ± 0.5 °
公差	0.1	0.15	0.2	0.3	0.5	0.8				1.2	2.0	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Adafruit:](#)

[4436](#)