

Description

Standard 5x3.2mm SMD crystal with four pads.
Ceramic package with a seam sealed metal lid, hermetically sealed.

Model CFPX-104
Model Issue number 9

Frequency Parameters

Frequency 9.90MHz

Environmental Parameters

Shock: 1500G, 0.5ms, 3 times in each of 3 mutually perpendicular perpendicular planes.

Vibration: 20G (20Hz-2000Hz), 1.52mm amplitude, 20mins in 3 mutually perpendicular planes, 4 cycles

Storage Temperature Range: -55 to 125°C

Compliance


RoHS Status Compliant
REACH Status Compliant
MSL Rating (JDEC-STD-033): Not Applicable

Packaging Details

Pack Style: Reel Tape & reel in accordance with EIA-481-D
Pack Size: 1,000



Outline (mm)

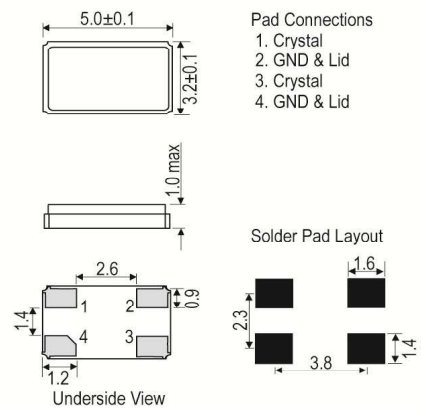

Sales Office Contact Details:

UK: +44 (0)1460 270200
Germany: 0800 1808 443

France: 0800 901 383
USA: +1.760.318.2824

Email: info@iqdfrequencyproducts.com
Web: www.iqdfrequencyproducts.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[IQD Frequency Products:](#)

[LFX TAL075997Reel](#)