


ANT-RRP9I5SMA-Y



902-928MHz Reverse Polarity SMA Right Angled Antenna

Electrical Specifications	
Frequency Range	902-928MHz
Nominal Impedance	50 Ω
Maximum Input Power	20W
Polarization	Vertical
Radiation Pattern	Omni
Gain	2dB
VSWR	≤ 1.5
Connector	RP SMA

Mechanical Specifications	
Material	Rugged Antenna
Antenna dimensions	77mm x 17mm
Antenna weight	6g
Ambient Temperature	-40°C to 60°C

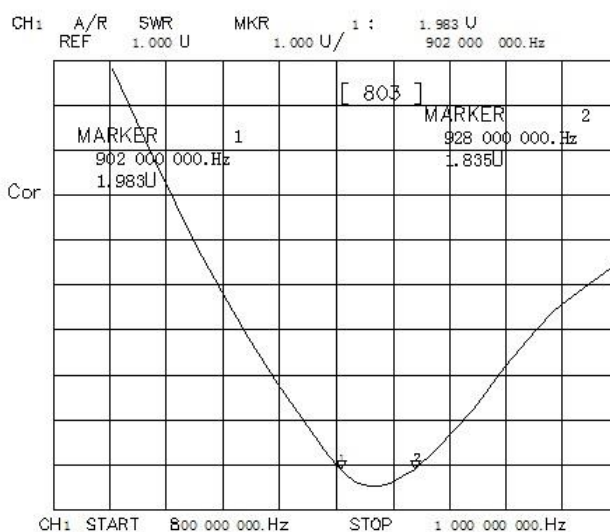

Order Code	ANT-RRP9I5SMA-Y
------------	-----------------

Version	Date	Revision	Known Issues
VI.0	18/03/2013	Initial release	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

LPRS:

[ANT-RRP915SMA-Y](#)