

Product Name	Current transformer	Model	SCT013-000
--------------	---------------------	-------	------------

Characteristics: Opening size 13mm*13mm, 1m leading wire, standard $\Phi 3.5$ three-core plug output.

Current output type

Purpose: Used for current measurement, monitor and protection for AC motor, lighting equipment, air compressor etc.

Patent No.: ZL 2015 3 0060067. X


Technical Data

I_{PN}	Rated input	0-100A
I_{PM}	Max. detection input	
I_{OUT}	Rated output	0-50mA
X	Accuracy	$\pm 1\%$
ϵ_L	Linearity	$\pm 3\%$
N	Turns ratio	1:1800
Φ	Phase shift	$\leq 180^\circ$
R_L	Max. Sampling resistance	10 Ω
V_{PN}	Work voltage	660V
f	Work frequency	50-1KHz
T_A	Operating temperature	-25..+70 $^\circ$ C
T_S	Storage temperature	-40..+85 $^\circ$ C
Vd	Dielectric strength, 50 Hz, 1 min	3KV




Fire resistance	UL94-V0
Material of core	Ferrite
Mounting type	Suspension
Weight	55g


Dimension (mm(in). 1 mm= 0.0394 inch)

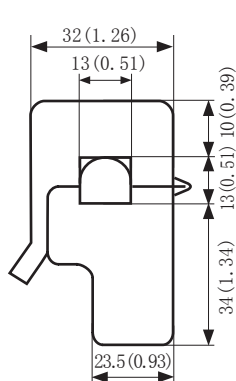


Front view

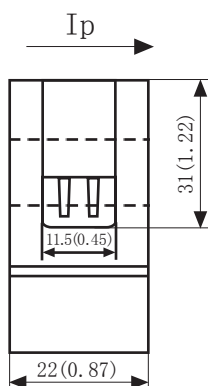

Side view

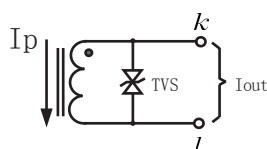

current output type

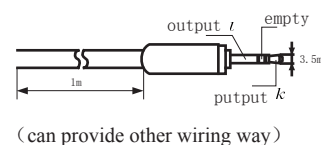

Standard three-core plugs
schematic diagram

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Seeed Studio:](#)

[101990029](#)