

标记	版本	文件编号	变更前	变更后	日期	变更人
	A		/	新版图	2013.07.25	WZW

Performance characteristics:

1. The dimensions with "\*" are key control size

2. Main body part material

Insulator: NYLON UL94V-0

Contact: Brass

3. Plating

Contact: Tin-plated according to customer needs

4. Electrical requirements:

Current rating: 2 A

Voltage rating: 250V

Contact resistance: ≤10 mΩ





Insulation resistance: ≥1000 MΩ

Withstanding voltage: 800 V AC, 60s


5. Environment specification

Working temperature: -25℃~85℃

Method of packing: 1000 pcs per bag

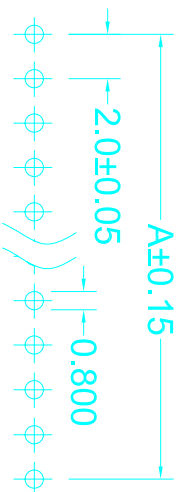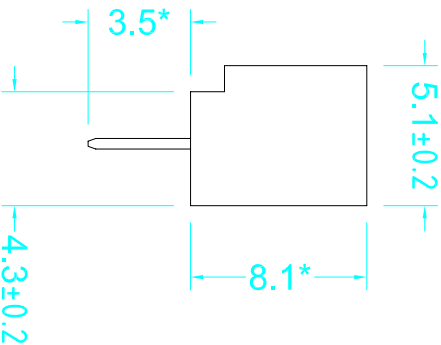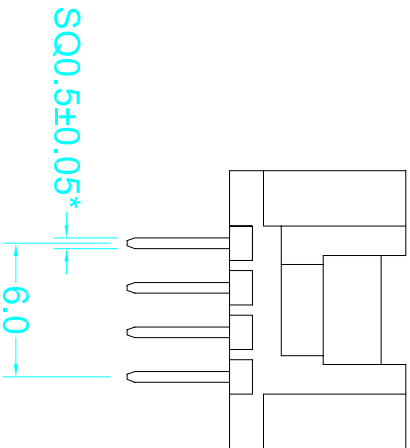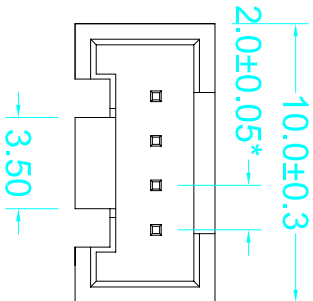

PCB LAYOUT

DRAWN	DATE	 SHENZHEN NS-TECH CO.,LTD.
WZW	2013.07.25	
CHECKED	DATE	TITLE: 1125S-4P SPEC: 不打K 环保
APPROVED	DATE	PART NO.
		CLIENT P/N
		UNIT: mm
		SCALE: free
		FILE NO.:NS-1125-W00008
		REV A
		HC

未注公差表	
.X ±0.5	X. ±5°
.XX ±0.3	.X ±3°
.XXX ±0.1	.XX ±1°

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Seeed Studio:](#)

[110990030](#)