


ACE-A622A

220W 1U Type ATX Power Supply



Dimensions (Unit: mm)

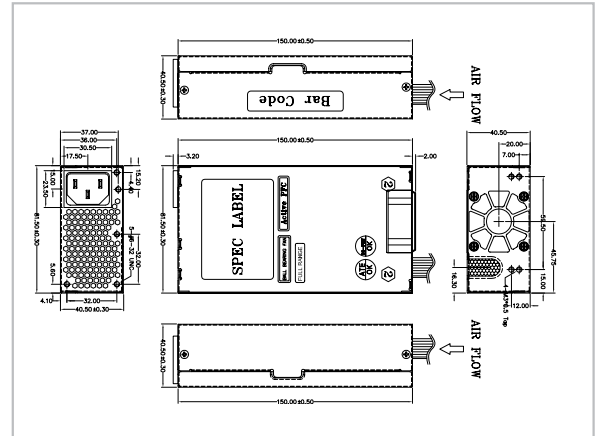

Specifications

Input Type	90~264 VAC Full Range					
Output Voltage	+3.3 V	+5 V	+12 V	+12 V 2	-12 V	+5 Vsb
	14 A (0.5 A min.)	16 A (0.5 A min.)	16 A (1 A min.)	10 A (1 A min.)	0.8 A (0 A min.)	2.5 A (0 A min.)
Efficiency	80%					
Temperature	Operating: 0°C ~ 50°C, Storage: -20°C ~ 80°C					
MTBF (hrs)	100,000 hr					
Output Connector	20-pin ATX, 4-pin 12 V, three HDD and one FDD					
Dimensions	150 x 81.5 x 40.5 (mm)					

Ordering Information

Part No.	Description
ACE-A622A-RS-R11	220W AC-DC 1U flex ATX Power Supply, with PFC/ErP, meet 80 PLUS

ACE-A618A


180W 1U Type ATX Power Supply



Specifications

Input Type	90~264 VAC Full Range				
Output Voltage	+3.3 V	+5 V	+12 V	-12 V	+5 Vsb
	14 A (0.3 A min.)	16 A (0.3 A min.)	14 A (1.5 A min.)	0.5 A (0 A min.)	2.0 A (0 A min.)
Efficiency	68%				
Temperature	Operating: 0°C ~ 50°C, Storage: -20°C ~ 80°C				
MTBF (hrs)	100,000 hr				
Output Connector	1 x 20-pin ATX, 1 x 4-pin 12V CPU, 3 x HDD, 1 x FDD				
Dimensions	150 x 81.5 x 40.5 (mm)				

Dimensions (Unit: mm)

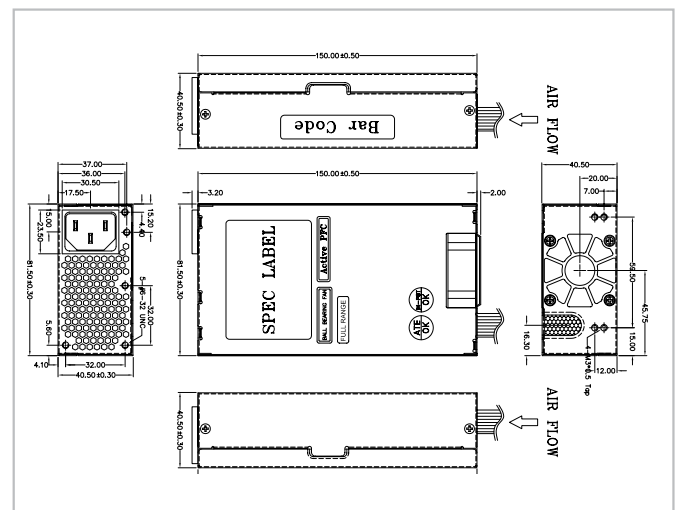

Ordering Information

Part No.	Description
ACE-A618A-RS-R11	180WAC-DC 1U flex ATX Power Supply, with PFC/ErP

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

IEI:

[ACE-A618A-RS-R11](#) [ACE-A622A-RS-R11](#)