

FSP150-ABAN3

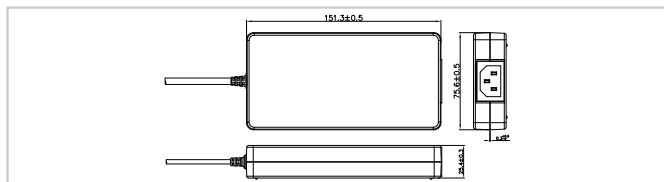
150 W AC/DC Adapter



Plug Type: Power mini-DIN (4P)

****Meet ErP & PSE****Specifications**

- Input Voltage Range: 90-264 VAC
- Input Frequency: 47-63 Hz
- Output Voltage: 19 V
- Output Current: 7.89 A
- Output Watts: 150 W
- Efficiency: 87%
- Operating Temperature: 0°C ~ 40°C
- Storage Temperature: -20°C ~ 80°C

Dimensions (Unit: mm)**Ordering Information**

Part No.	Description
63040-010150-700-RS	19 V 150W power adapter, 90~264 VAC input, ErP, PSE

FSP120-AHAN3

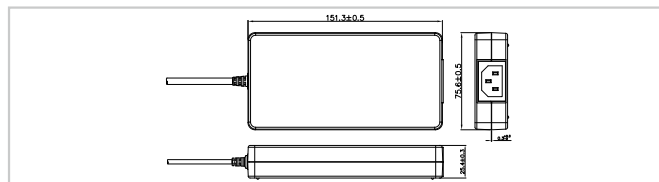
120 W AC/DC Adapter



Plug Type: Power mini-DIN (4P)

****Meet ErP & PSE****Specifications**

- Input Voltage Range: 90-264 VAC
- Input Frequency: 47-63 Hz
- Output Voltage: 12 V
- Output Current: 10 A
- Output Watts: 120 W
- Efficiency: 87%
- Operating Temperature: 0°C ~ 40°C
- Storage Temperature: -20°C ~ 80°C

Dimensions (Unit: mm)**Ordering Information**

Part No.	Description
63040-010120-300-RS	12 V 120W power adapter, 90~264 VAC input, ErP, PSE

FSP096-AHAN3

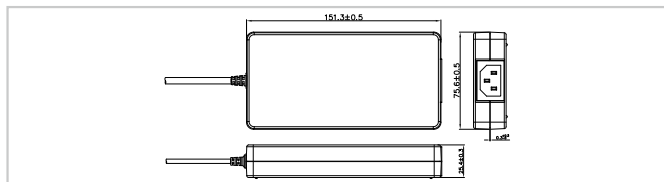
96 W AC/DC Adapter



Plug Type: Power mini-DIN (4P)

****Meet ErP & PSE****Specifications**

- Input Voltage Range: 90-264 VAC
- Input Frequency: 47-63 Hz
- Output Voltage: 12 V
- Output Current: 8 A
- Output Watts: 96 W
- Efficiency: 88%
- Operating Temperature: 0°C ~ 40°C
- Storage Temperature: -20°C ~ 80°C

Dimensions (Unit: mm)**Ordering Information**

 
Part No.	Description
63040-010096-040-RS	12 V 96W power adapter with DIN 4-pin/lock 90~264 VAC input
63040-010096-231-RS	12 V 96W power adapter with $\Phi 2.5/\Phi 5.5$ /lock 90~264 VAC input
63040-010096-050-RS	12 V 96W power adapter with $\Phi 2.5/\Phi 5.5$ / 90~264 VAC input

FSP090-DBBN3

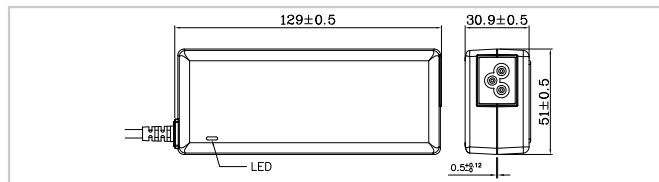
87 W AC/DC Adapter



Plug Type: Power mini-DIN (4P)

****Meet ErP & PSE****Specifications**

- Input Voltage Range: 90-264 VAC
- Input Frequency: 47-63 Hz
- Output Voltage: 19 V
- Output Current: 4.74 A
- Output Watts: 90 W
- Efficiency: 88%
- Operating Temperature: 0°C ~ 40°C
- Storage Temperature: -20°C ~ 80°C

Dimensions (Unit: mm)**Ordering Information**

Part No.	Description
63040-010090-070-RS	19 V 90W power adapter with DIN 4-pin/lock 90~264 VAC input, ErP

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

IEI:

[63040-010096-040-RS](#) [63040-010096-231-RS](#) [63040-010096-050-RS](#)