

IKARPC-07A

Vehicle Computer Series

Features

- 7" sunlight readable TFT LCD with projected capacitive touchscreen
- Optional HSUPA/GPRS/GSM, Wi-Fi and Bluetooth
- Built-in GPS receiver
- Built-in OBD-II/J1939




Specifications

Model Name		IKARPC-07A-A9	IKARPC-07A-BT
Chassis	Color	Black C + Silver	Black C + Silver
	Dimensions (WxHxD) (mm)	210 x 154 x 28	210 x 154 x 28
	System Fan	Fanless	Fanless
	Chassis Construction	PC + ABS plastic	PC + ABS plastic
Display	Size	7"	7"
	Resolution	1024 × 3 (RGB) × 600	1024 × 3 (RGB) × 600
	Brightness (cd/m ²)	500	500
	Contrast Ratio	700:1	700:1
	Pixel Pitch (mm)	0.05 (W) × 0.15 (H)	0.05 (W) × 0.15 (H)
	Viewing Angle (H/V)	130° (H) / 140° (V)	130° (H) / 140° (V)
	Touchscreen	Projected capacitive touch with USB interface	Projected capacitive touch with USB interface
	CPU	Freescale™ i.MX 6 Cortex™-A9 (quad-core, 1.0 GHz)	Intel® Atom™ processor E3826 (dual-core, 1.46 GHz, 7W)
Motherboard	Chipset	N/A	SoC
	System Memory	On-board 1 GB SDRAM	On-board 2 GB SDRAM
	SD Card	1 x SD slot (supports SD 2.0, max. 32 GB)	1 x Micro SD slot (supports SD 2.0, max. 32 GB)
Storage	Flash	On-board 8 GB iNAND flash	N/A
	mSATA	N/A	1 x mSATA (SATA 3Gb/s) optional
	WLAN	On-board Wi-Fi 802.11a/b/g/n	PCIe Mini Wi-Fi 802.11a/b/g/n/ac (optional)
Communication	Bluetooth	Bluetooth 3.0+HS	BT 4.0/3.0+HS (combo with WLAN optional module)
	WWAN	PCIe Mini WCDMA/HSDPA/HSUPA (Built-in)	PCIe Mini WCDMA/HSDPA/HSUPA (optional)
	RFID	13.56 MHz ISO4443 A/B, read-write capable, ISO 14443A (MIFARE), ISO 14443B (FeliCa)	N/A
	GPS	On board GPS	On board GPS
	20-pin Connector	1 x 10/100 LAN 1 x OBD-II/J1939 1 x USB 2.0	1 x GbE LAN 1 x OBD-II/J1939 1 x USB 2.0
I/O Interfaces	24-pin Connector	1 x Audio line-out (R+L) 1 x Audio line-in 1 x RS-232 4-bit digital I/O (2-bit input, 2-bit output)	1 x Audio line-out (R+L) 1 x Audio line-in 1 x RS-232 4-bit digital I/O (2-bit input, 2-bit output)
	8-pin Connector	Video input	N/A
	USB 3.0	N/A	1
	USB 2.0	2	1
	Display	N/A	1 x HDMI
	SIM	1 x on board SIM card slot	2 x on board SIM card slot
	Antenna	1 x GPS, 1 x WWAN	1 x GPS, 1 x WWAN
	Expansions	PCIe Mini	1 x Full-size PCIe Mini (reserved for mSATA module), 1 x Full-size PCIe Mini (reserved for WWAN module), 1 x Half-size PCIe Mini (reserved for WLAN module)
Multimedia	Speaker	1 x Speaker (2 W)	1 x Speaker (2 W)
	Camera	5-megapixel CMOS	2-megapixel CMOS
LED Indicator & Button	Indicator	Power/BT/Wi-Fi/3G	Power/HDD/Wi-Fi/3G
	Button	1 x Power button	1 x Power button
Power	Power Input	Cigarette lighter power cable, DC 9 V~30 V	Cigarette lighter power cable, DC 9 V~30 V
	Consumption	12 V @ 0.8 A	12V @ 1.25 A
Reliability	Mounting	VESA 75	VESA 75
	Operating Temperature	-20°C ~ 60°C with air flow	-20°C ~ 60°C with air flow
	Storage Temperature	-30°C ~ 70°C	-30°C ~ 70°C
	Humidity	10% ~ 95%, non-condensing	10% ~ 95%, non-condensing
	Operating Shock	Half-sine wave shock 5G, 11ms, 3 shocks per axis	Half-sine wave shock 5G, 11ms, 3 shocks per axis
	Operating Vibration	MIL-STD-810F 514.5C-2 (with SSD)	MIL-STD-810F 514.5C-2 (with SSD)
	Weight (Net/Gross)	0.9 kg/2.1 kg	0.9 kg/2.1 kg
	Safety/EMC	CE/FCC/E-Mark/IP 54 compliant front panel	CE/FCC/E-Mark/IP 54 compliant front panel
OS	Supported OS	Android 4.2.2	Microsoft® Windows® Embedded 8, Microsoft® Windows® Embedded Standard 7 E



Fully Integrated I/O

Dimensions (Unit: mm)

IKARPC-07A-A9 Rear view

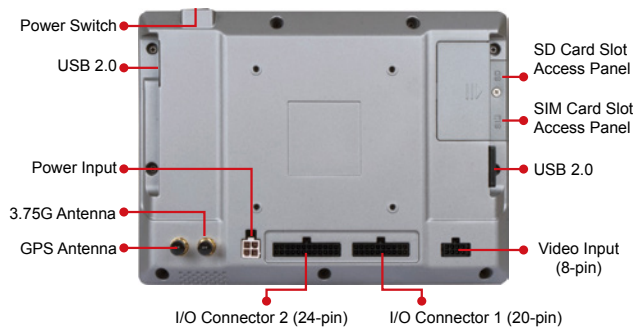

IKARPC-07A-BT Rear view

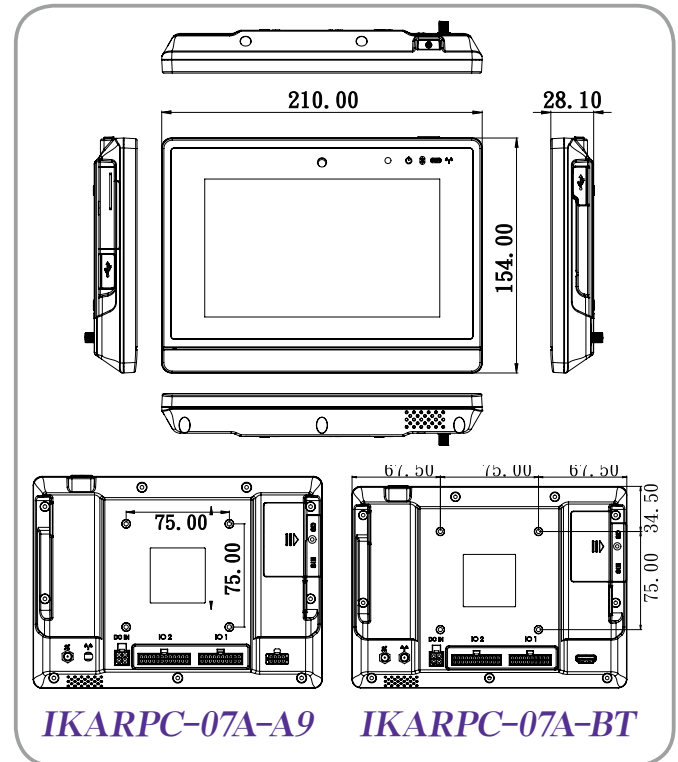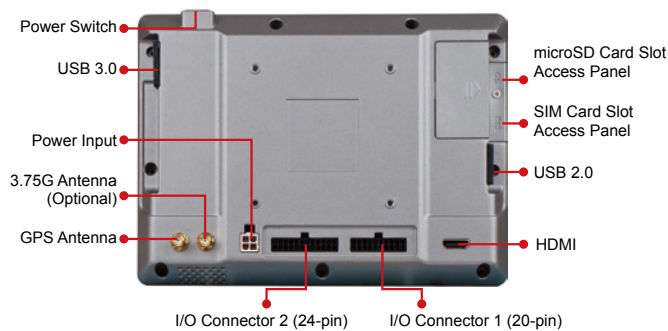

Ordering Information

Part No.	Description
IKARPC-07A-A9-R11	7" 500 cd/m2 1024 x 600, In Vehicle Panel PC with Freescale iMX6 Qual core Processor, 1.0GHz, 1GB SDRAM, 8GB EMMC Flash, 5M Camera, RFID Reader, OBDII, HSUPA, GPS, WIFI/BT, ROHS
IKARPC-07A-BT-E3/2G-R11	7" 500 cd/m2 1024 x 600 In Vehicle Panel PC with Intel® Atom E3826 1.46GHz, 7W TDP, 2GB DDR3L on board memory, OBDII, GPS on board, 2M Camera, ROHS

Options

Item	Part No.	Description
Power adapter	IVIPOWER-4PIN-R10	Power adapter with 4-pin transfer cable, RoHS
Cigarette lighter power cable	32002-004000-100-RS	Round cable, power cable, car cigarette lighter cable, 2000 mm, 18 AWG, (A) cigarette lighter (5 A 250 V)+ ψ 3 green LED, (B) MOLEX 5557-0400 P=4.2, SHANGHAI YING YU, RoHS
VESA mount stand	IVI-MK03-R10	138mm 75x75 VESA mount stand
OBD-II cable	32025-003400-100-RS	Round cable, OBD-II cable, 2000 mm, 24 AWG, (A) OBD-II 16P male, (B) D-sub 9P female, one piece package with label, NIAN YEONG, RoHS

IKARPC-07A-A9 Series

Item	Part No.	Description
I/O connector 1 cable (20-pin)	32024-002400-100-RS	Round cable, integration cable, I/O cable, 300 mm, 24 AWG, (A)terminal block 3P P=5.08, (B)USB A type female+2 NUT, (C)PCB jack: RJ-45 8P8C, (D)D-sub 9P male, (E)MOLEX 5557-2000 P=3.0, one piece package with label, RoHS
I/O connector 2 cable (24-pin)	32024-002900-100-RS	Round cable, integration cable, I/O cable, 300 mm, 22 AWG, (A)terminal block 8P P=5.08, (B)MOLEX 43025-2400 P=3.0, (C)D-sub 9P male, (D)phone jack 3.5_3P+NUT, (E)phone jack 3.5_5P+NUT, one piece package with label, RoHS
Video input cable (8-pin)	32010-001700-100-RS	Round cable, video cable, 300 mm, 26 AWG, (A)MOLEX 43025-0800 P=3.0, (B)RCA jack, yellowx4, RoHS

IKARPC-07A-BT Series

Item	Part No.	Description
I/O connector 1 cable (20-pin)	32024-003000-100-RS	Round cable, integration cable, I/O cable, 300 mm, 24 AWG (A)terminal block 3P P=5.08, (B)USB A type female+2 NUT, (C)PCB jack: RJ-45 8P8C, (D)D-sub 9P male, (E)MOLEX 5557-2000 P=3.0, one piece package with label, RoHS
I/O connector 2 cable (24-pin)	32124-003700-100-RS	Round cable, integration cable, I/O cable, 300 mm, 22 AWG, (A)terminal block 8P P=5.08, (B)MOLEX 43025-2400 P=3.0, (C)D-sub 9P male, (D)phone jack 3.5_3P+NUT, (E)phone jack 3.5_5P+NUT, one piece package with label, RoHS
OS: Windows Embedded 7 (DVD-ROM)	IKARPC-07A-BT-WES7P-R10	OS image with Windows® Embedded Standard 7 E for IKARPC-07A-BT Series, DVD-ROM, RoHS
OS: Windows Embedded 8 (DVD-ROM)	IKARPC-07A-WE8S-R10	OS image with Windows® Embedded Standard 8 E for IKARPC-07A-BT Series, WE8S license label, DVD-ROM, RoHS
Wireless kit	IKARPC-WIFI-KIT01-R10	1T1R wifi module kit for embedded system, IEEE 802.11b/g/n, 1 x wifi module, RoHS
WWAN kit	IKARPC-3G-KIT02-R10	F260 3.75G module kit for embedded system, with BT V2.1, RoHS

Packing List

Product	Item	Part No.	Qty	Description
IKARPC-07A-A9	Power Cable	32002-001900-100-RS	1	Round cable, power cable, 3000mm, RoHS
	GPS/GSM Antenna	32506-000100-100-RS	1	Integration antenna, GPS/GSM, RG 174, 5000mm/5000mm, PPF-5423SA5X-999, Magnetic mount: ϕ 55x22mm, 1575.42MHz/850MHz/900MHz/1800MHz/1900MHz, SMA plug x 2
IKARPC-07A-BT	Power Cable	32002-001900-100-RS	1	Round cable, power cable, 3000mm, RoHS
	Screw pack	44045-020031-RS	2	Screw pack
	GPS/GSM Antenna	32506-000100-100-RS	1	Integration antenna, GPS/GSM, RG 174, 5000mm/5000mm, PPF-5423SA5X-999, Magnetic mount: ϕ 55x22mm, 1575.42MHz/850MHz/900MHz/1800MHz/1900MHz, SMA plug x 2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

IEI:

[IKARPC-07A-BT-WES7P-R10](#) [IKARPC-07A-WE8S-R10](#) [IKARPC-07A-A9-R11](#) [IKARPC-07A-BT-E3/2G-R11](#)