

PUZZLE-IN003A

Desktop Network Appliance with Intel® Atom® Processor C3000 Processor, up to 8 x 1 GbE on Board with 2 (by sku) bypass segments, 1 x eMMC 32GB



Features

- Intel® Atom® processor C3558 8M Cache, up to 2.20 GHz
- Support 4 x 1 GbE NIC via Intel® I211, 4 x 1 GbE PHY via Marvell 88E1543
- Support bypass function (by sku)
- DDR4 2133MHz ECC (by CPU) or non-ECC UDIMM/R-DIMM Up to 128GB
- 1 x M.2 A key (USB 2.0, PCIe x1), 1 x miniPCIe (USB 2.0, PCIe x1) with SIM card slot, 1 x eMMC 32GB

Specifications

		PUZZLE-IN003A-C1	PUZZLE-IN003A-C3
Platform	Form Factor	Desktop	
	CPU	Intel® Atom® processor C3558 8M cache, up to 2.20 GHz	Intel® Atom® Processor C3336 4M Cache, 1.50 GHz
	Chipset	Integrated in CPU	
Memory	Memory Technology	DDR4 2133MHz ECC (By CPU) or non-ECC UDIMM, Support DDR4 RDIMM	
	Memory Capacity	UDIMM up to 64GB / RDIMM up to 128GB	
	Memory Socket	2 x 288-pin DIMM	1 x 288-pin DIMM
Network and Security	Network Acceleration and Security Function	<ul style="list-style-type: none"> • Intel® AES New Instructions • Intel® Software Guard Extensions (Intel® SGX) • Intel® Virtualization Technology for Directed I/O (VT-d) • Intel® QuickAssist Technology (Intel® QAT) 	<ul style="list-style-type: none"> • Intel® Virtualization Technology for Directed I/O (VT-d) • Intel® Virtualization Technology (VT-x) • Intel® QuickAssist Technology (Intel® QAT)
	TPM	1 x TPM 2.0 pin header	
Networking	Ethernet IC	1 GbE NIC: Intel® i211-AT 1 GbE PHY: Marvell 88E1543	
	Ethernet Port	4 x GbE from Intel® i211-AT 4 x GbE from Marvell 88E1543	4 x GbE from Intel® i211-AT 2 x GbE from Marvell 88E1543
	Bypass	Yes, 2 bypass segments	
	Network Module Slot	N/A	
	PCIe Slot	N/A	
Expansion Slot	PCIe Mini Card Slot	1 x PCIe Mini card (PCIe 3.0, USB 2.0) with SIM slot	
	M.2	1 x M.2 A key (PCIe 3.0 & USB 2.0)	
	Storage	1 x SATA 3.0 + 1 x 5V power connector (for SATA DOM) 1 x M.2 M key 2260/2280 Support PCIe 3.0 x4 NVME	
Storage	eMMC	1 x eMMC 32GB	
	SD Card	N/A	
	USB	1 x USB 2.0 1 x USB 3.2 Gen 1	
External I/O	Console	1 x RJ45	
	HDMI	N/A	
Internal I/O	USB	N/A	
	Power Switch	1 x Power switch	
Power and Mechanical	Reset Button	1 x Reset button	
	Power Input	1 x DC jack	
	Type/Watt	12 V DC-in, 60W	
	Processor Cooling	Passive CPU heatsink	
	System Cooling	Fanless	
	Antenna Hole	2 x Antenna hole	
	Storage Temperature	-20°C ~ 75°C (-4°F ~ 167°F)	
Physical and Environmental	Operating Temperature	0°C ~ 40°C (32°F ~ 104°F)	
	Operating Humidity	5% ~ 90% non-condensing	
	Dimensions (W x L x H) (mm)	225 x 206 x 44.2	
	Weight	2 kg	
OS and Certifications	Certification	CE / FCC / RoHS	
	Operating System	Linux Ubuntu 18.04.04 CentOS 7 / Red Hat / Fedora EPEL Microsoft Windows 10	
Indicators	LCM	N/A	
	LED	1 x Power LED, 1 x Storage LED, 1 x Alert LED	

Ordering Information

Part No.	Description
PUZZLE-IN003A-C1-R10	Desktop network appliance with Intel® ATOM® C3558 processor, 8 x 1GbE on Board with up to 2 bypass segments, eMMC 32GB & 2 x M.2 slot, RoHS
PUZZLE-IN003A-C1/8G-R10	Desktop network appliance with Intel® ATOM® C3558 processor, 8 x 1GbE on Board with up to 2 bypass segments, 8GB DDR4, eMMC 32GB & 2 x M.2 slot, RoHS
PUZZLE-IN003A-C3-R10	Desktop network appliance with Intel® ATOM® C3336 processor, 6 x 1GbE on Board with up to 1 bypass segments, eMMC 32GB & 2 x M.2 slot, RoHS
PUZZLE-IN003A-C3/8G-R10	Desktop network appliance with Intel® ATOM® C3336 processor, 6 x 1GbE on Board with up to 1 bypass segments, 8GB DDR4, eMMC 32GB & 2 x M.2 slot, RoHS

Packing List


	PUZZLE-IN003A-C1-R10	PUZZLE-IN003A-C1/8G-R10	PUZZLE-IN003A-C3-R10	PUZZLE-IN003A-C3/8G-R10
Power cord	1	1	1	1
Power adapter	1	1	1	1
Rack mounting ears	Option	2	Option	2
Screws for rack mounting ears	Option	6	Option	6
USB to console cable	Option	1	option	1
RS-232 to console cable	1	Option	1	Option

Options


Item	Part No.	Description
USB to console cable	32013-004000-100-RS	Round cable, LAN cable, FTDI console cable, 2, 1800MM, (A) USB A TYPE 4P MALE+PCB:FTDI_FT232RL, (B) RJ45 8P8C, RoHS
RS-232 to console cable	32005-005100-100-RS	Round cable, RS-232/422/485, PUZZLE RS-232 cable, 2, 500MM, 24AWG, (A) D-SUB 9P MALE+#4-40 screw, (B) RJ45 PLUG 8P8C, ONE PCS PKG, TC&C, RoHS
Rack ear mounting kit	19B00-000417-00-RS	Accessory module: PUZZLE-IN003 series rack ear mounting kit

IO Interface


PUZZLE-IN003A-C1

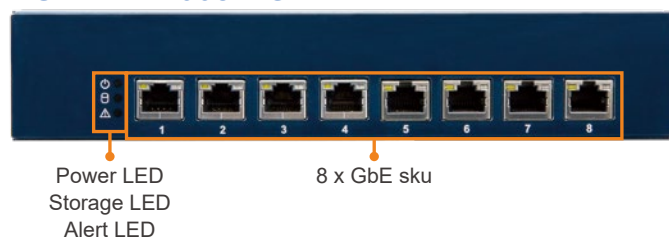


PUZZLE-IN003A-C3

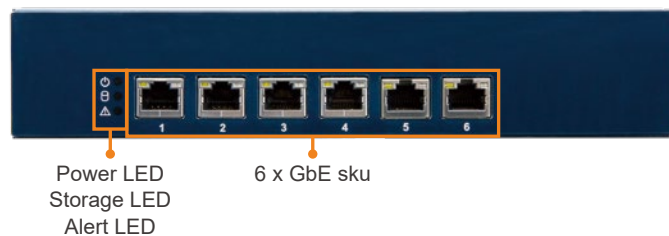

Rear view

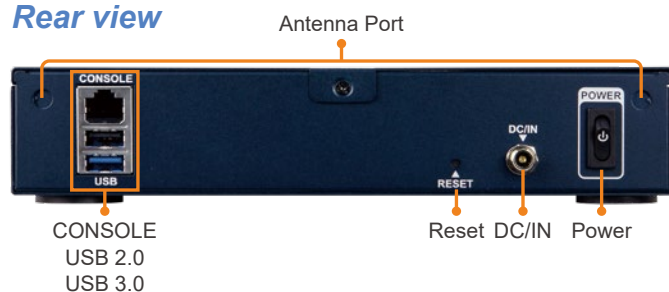

Dimensions (Unit: mm)

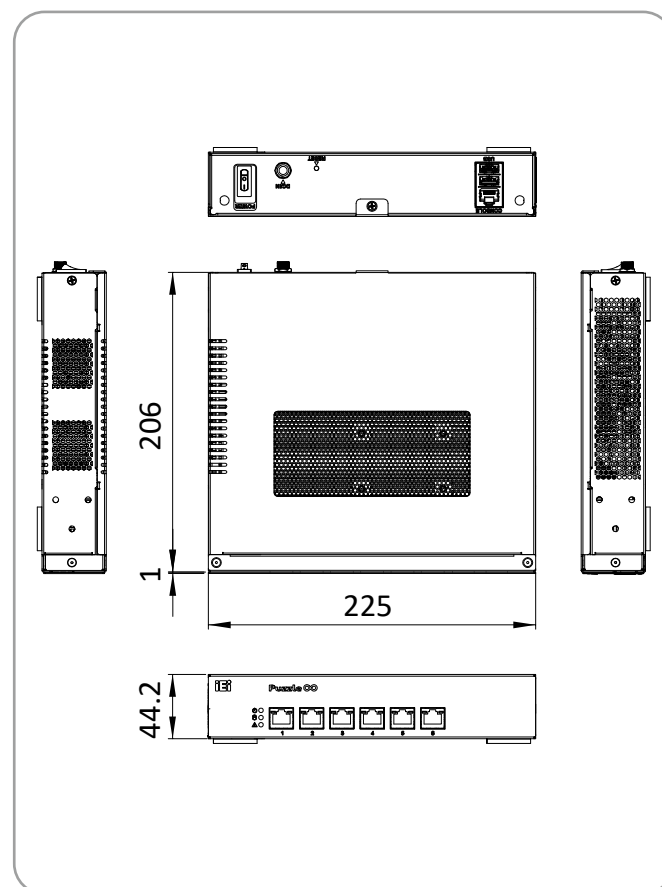

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

IEI:

[PUZZLE-IN003A-C1-R10](#) [PUZZLE-IN003A-C3-R10](#)