

PuIM-10G4SF-MLX

Mellanox ConnectX-4 Lx based Network Interface Card support Quad 10GbE with 4 x SFP+ by 2 PCIe 3.0 x4 Interface



Features

- 2 x Mellanox ConnectX-4
- 4 ports 10 GbE SFP+ connector
- 2 PCIe 3.0 x4
- RoHS/CE/FCC compliant

Specifications

Model Name	PuIM-10G4SF-MLX
Form Factor	IEI Networking Module - PuIM
NIC	Mellanox ConnectX-4
LAN Bypass	N/A
LAN Interface	SFP+
Speed	1GbE/10GbE
Ports	4
Host Interface	2 PCIe 3.0 x4
Storage Temp.	-20°C ~ 75°C (-4°F ~ 167°F)
Operating Temp.	0°C ~ 40°C (32°F ~ 104°F)
Humidity	5% ~ 90% RH, Non-condensing
Dimensions (mm)	165.50 (L) x 77.8 (W) x 44.2 (H)
Compliance	RoHS/CE/FCC


Packing List

1 x PuIM-10G4SF-MLX module	1 x L-shaped T10 Plum Wrench
2 x Torx Screws	1 x QIG


Ordering Information

Part No.	Description
PuIM-10G4SF-MLX-R10	Mellanox ConnectX-4 Lx based Network Interface Card support Quad 10GbE with 4 x SFP+ by 2 PCIe 3.0 x4 Interface, RoHS

Dimensions (Unit: mm)

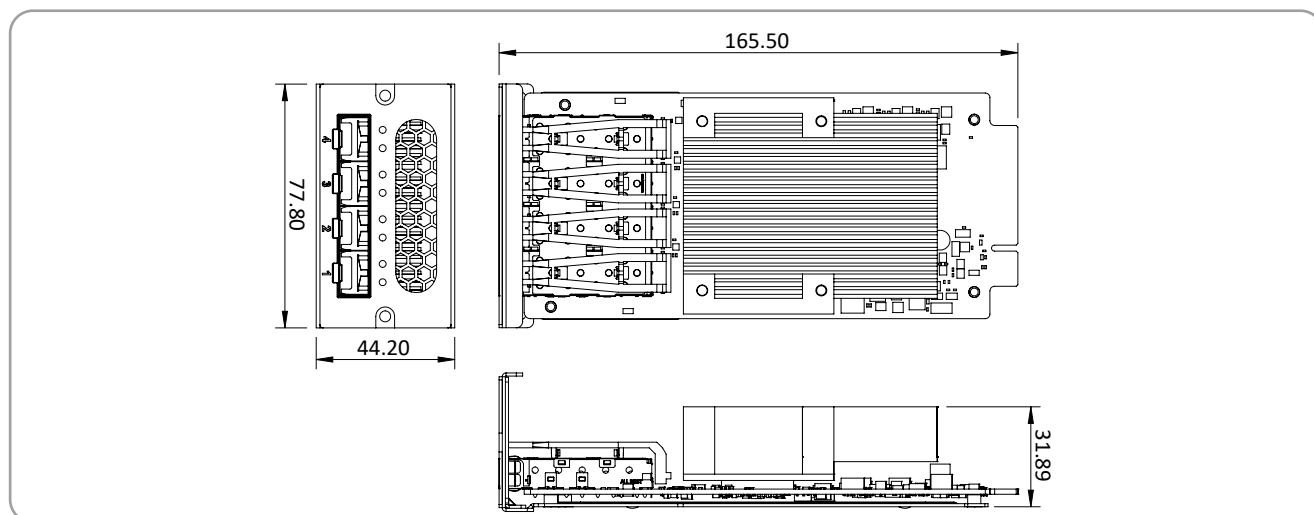


Block Diagram

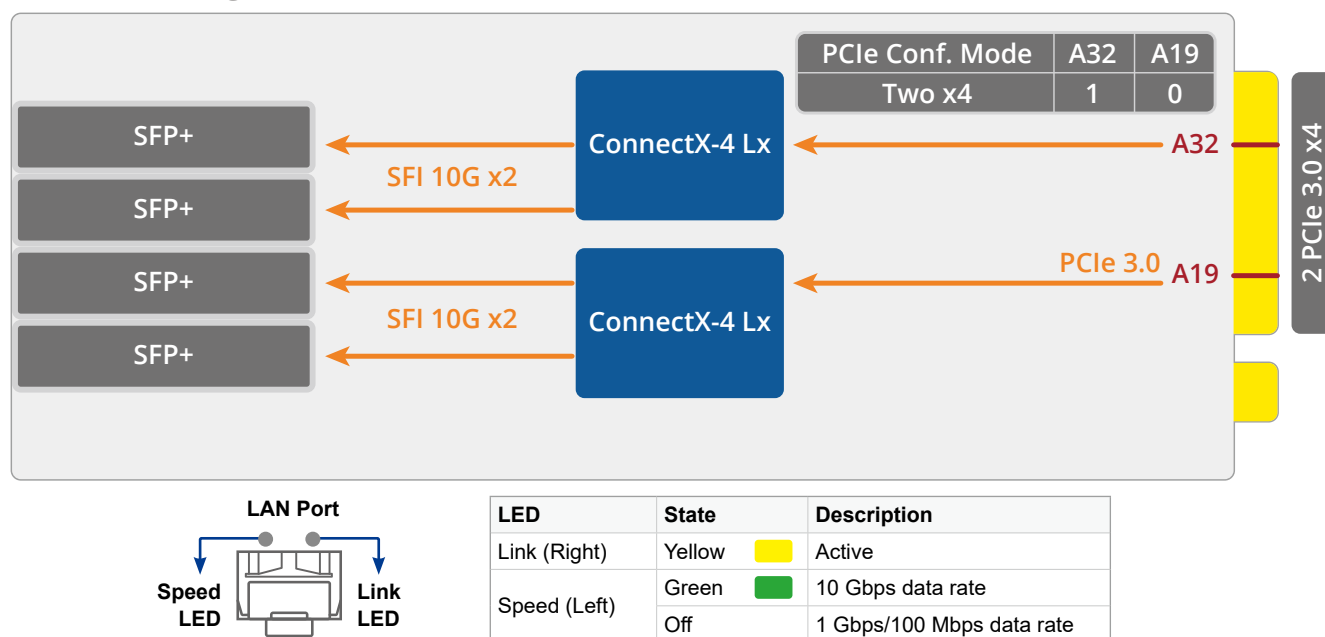

Hardware Installation

Install the PuIM-10G4SF-MLX networking module into the slot of the PUZZLE series. The Slot A supports 8 lanes from CPU (1 PCIe x8 or 2 PCIe x4); the Slot B supports 8 lanes from PCH (2 PCIe x4 or 4 PCIe x2). The PuIM-10G4SF-MLX is can installed into the Slot A & Slot B.

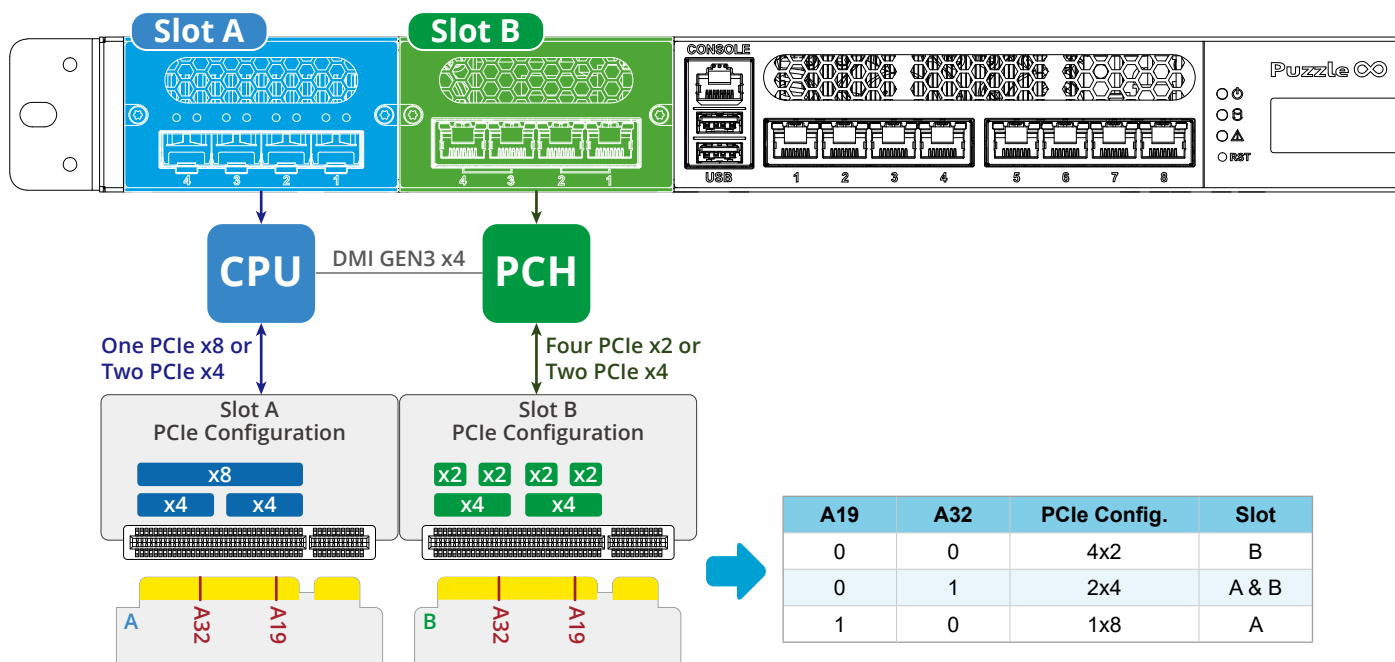

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

IEI:

[PuIM-10G4SF-MLX](#)