


# RACK-220G

2U 6-slot Full-size Rackmount Chassis

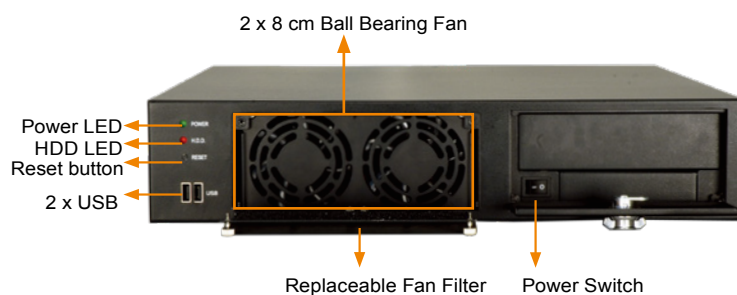

CD-ROM, and HDD are not included in package




RACK-220GBATX



RACK-220GB  
B-Black

## Dimensions (Unit: mm)

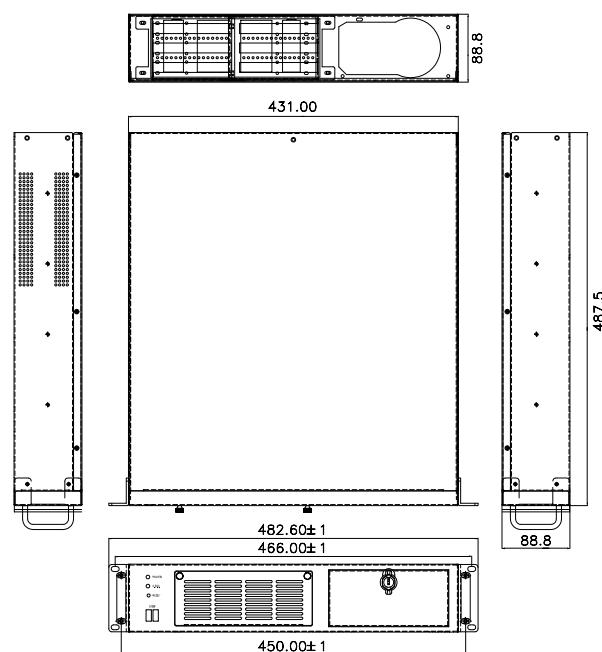

## Features

- RoHS compliant design
- Two USB ports on the front panel
- Two 8 cm cooling fans with replaceable fan filter
- One 5.25" and one 3.5" drive bays
- One 3.5" internal hard drive bay
- Lockable door prevents unauthorized access

## Specifications

◆ Construction	Heavy duty metal
◆ SBC Form Factor	Full-size, slot CPU card
◆ Drive Bays	1 x 5.25" 1 x 3.5" 1 x 3.5" HDD (internal)
◆ Cooling Fans	2 x 8 cm
◆ I/O Ports	2 x USB
◆ Expansion Slots	6 slots
◆ Indicators	Power, HDD
◆ Button	Power switch, reset button
◆ Operating Temperature	0°C ~ 50°C
◆ Operating Humidity	10% ~ 90%
◆ Color	Black
◆ Weight (Net/Gross)	8.2 kg/12.4 kg
◆ Dimensions (DxWxH)	488 mm x 431 mm x 89 mm

## Selection Guide

Model No.	SBC Type	PSU Type	Color
RACK-220G	PICMG 1.0	PS/2	Black
RACK-220G  ATX	microATX MB	PS/2	Black

## Backplane Options

Model No.	SBC Type	PCI	ISA	PCIe			PSU Connector
				x1	x4	x16	
PCI-5SDA-RS	PICMG 1.0	L2+R2	0	0	0	0	AT/ATX
PCI-5SD6-RS	PICMG 1.0	L2+R2	0	0	0	0	ATX
PCI-6SD-RS	PICMG 1.0	L1+R1	L1+R1	0	0	0	ATX

## Ordering Information

Part No.	Description
RACK-220G /A130C	2U 6-slot full-size rackmount chassis for PICMG 1.0 SBC, (black), 2 x 8 cm fan, with ACE-A130C-R10 (300W ATX model), RoHS
RACK-220G  ATX/A130C	2U microATX motherboard rackmount chassis, (black), 2 x 8 cm fan, with ACE-A130C-R10 (300W ATX model), RoHS

## Power Supply Options

Type	Model No.	Watt
AT	ACE-925AP-U-RS	250W
	ACE-935AL-RS	300W
ATX	ACE-A130C-R10	300W
	ACE-A140A-S-R11	400W

RACK-220G supports single PS/2 PSU. For more IEI PSU models, please refer to section 5 or visit [www.ieiworld.com](http://www.ieiworld.com).

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

IEI:

[RACK-220GB/A130C](#) [RACK-220GBATX/A130C](#)