


RACK-360G

4U 14-slot Full-size Rackmount Chassis

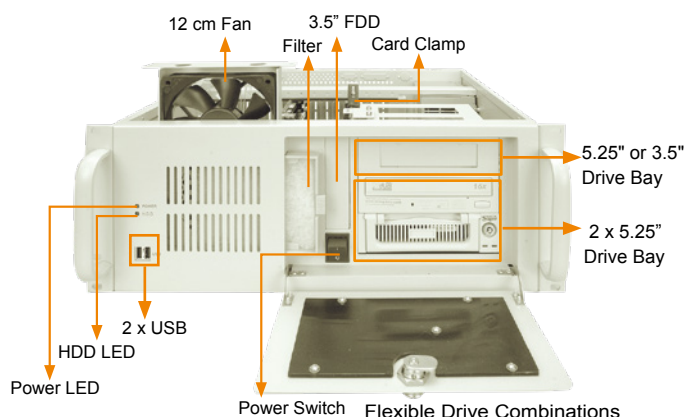

RACK-360GW


RACK-360GB



Replaceable fan filter



Front accessible I/O

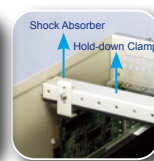

Anti-vibration card clamp


Features

- Cost-effective, RoHS compatible design
- Flexible drive combinations
- Two USB ports on the front panel
- 12 cm cooling fan with replaceable fan filter
- Lockable door prevents unauthorized access

Specifications

◆ Construction	Heavy duty metal
◆ SBC Form Factor	Full-size, slot CPU card
◆ Drive Combinations	3 x 5.25" + 1 x 3.5" HDD or 2 x 5.25" + 2 x 3.5" HDD or 2 x 5.25" + 1 x 3.5" HDD + 1 x front accessible 3.5" or 2 x 5.25" + 2 x front accessible 3.5"
◆ Cooling Fans	1 x 12 cm
◆ I/O Ports	2 x USB
◆ I/O Openings	2 x COM, 2 x LPT
◆ Expansion Slots	14 slots for RACK-360G 7 slots for RACK-360GATX
◆ Indicators	Power, HDD
◆ Button	Power switch, reset button
◆ Operating Temperature	0°C ~ 50°C
◆ Operating Humidity	10% ~ 90%
◆ Color	B: Black/W: White
◆ Weight (Net/Gross)	11 kg/15.4 kg
◆ Dimensions (DxWxH)	435.5 mm x 431 mm x 176 mm

Dimensions (Unit: mm)

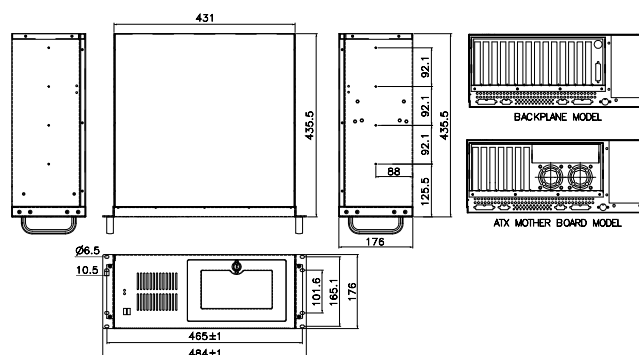

Backplane Options

Model No.	SBC Type	PCI	ISA	PCIX	PCIe			PSU Connector
					x1	x4	x16	
PCI-13SD-RS	PICMG 1.0	3+4	3+3	0	0	0	0	AT/ATX
PCI-14S2-RS	PICMG 1.0	4	8	0	0	0	0	AT/ATX
PCI-14S3-RS	PICMG 1.0	4	9	0	0	0	0	AT/ATX
PX-14S3-RS	PICMG 1.0	12	2	0	0	0	0	AT/ATX
PX-14S5-RS	PICMG 1.0	7	6	0	0	0	0	AT/ATX
PE-6S	PICMG 1.3	2	0	0	2	0	1	ATX
PE-10S	PICMG 1.3	4	0	0	4	0	1	ATX
PE-10S2	PICMG 1.3	4	0	0	4	0	1	ATX
PXE-12S	PICMG 1.3	4	0	6	0	0	1	ATX
PE-13SD	PICMG 1.3	4	0	0	4	1	2	ATX
PXE-13S	PICMG 1.3	8	0	0	3	0	1	ATX
SPXE-14S	PICMG 1.3	0	0	0	12	0	0	ATX

Ordering Information

Part No.	Description
RACK-360G □ -R23/ACE-935AL	4U 14-slot rackmount chassis, USB, (black/white), with ACE-935AL-RS PSU (300W), RoHS
RACK-360G □ -R23/A130C	4U 14-slot rackmount chassis, (black/white), 1 x 12 cm fan, with ACE-A130C-R10 (300W ATX model), RoHS
RACK-360G □ ATX-R23/A130C	4U ATX motherboard rackmount chassis, (black/white), 1 x 12 cm fan, with ACE-A130C-R10 (300W ATX model), RoHS
RACK-360E □ -R23/A130C	4U 14-slot Rackmount Chassis, (black/white), 1x 12cm fan, w/ACE-A130C-R10 (300W ATX power)
RACK-360E □ -R23/ACE-935AL	4U 14-Slot Rackmount Chassis, USB, (black/white), W/ACE-935AL-RS PSU (300W AT power), RoHS
RACK-360E □ ATX-R23/A130C	4U ATX motherboard Rackmount Chassis, (black/white), 1x 12cm fan, w/ACE-A130C-R10 (300W ATX power)

□ Color Code: B-Black W-White
Model variations are listed below:

* RACK-360G: with paint coating inside * RACK-360E: without paint coating inside

Power Supply Options

Type	Model No.	Watt
ATX	ACE-935AL-RS	300W
	ACE-A130C-R10	300W
	ACE-A140B-S-R10	400W
	ACE-A160B-R10	600W
ATX Redundant	ACE-A210A-R10	1000W
	ACE-R4130AP-RS	300W
	ACE-R4140AP-RS	400W

RACK-360G supports single PS/2 PSU. For more IEI PSU models, please refer to section 5 or visit www.ieiworld.com.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

IEI:

[RACK-360GB-R23/A130C](#) [RACK-360GWATX-R23/A130C](#) [RACK-360GW-R23/A130C](#)