

UPC Series

 
UPC-V312-D525

Intel® Atom™ D525 Dual Core Processor



Features

- Fully IP 65 compliant with Intel® Atom™ D525 1.8GHz dual-core processor
- 12.1" 600 nits 1024 x 768 LCD with LED backlight
- Dual DC input, 9V ~ 36V and 10.5V ~ 36V, switch automatically
- Dual-band 2.4/5 GHz Wi-Fi 802.11 a/b/g/n 3T3R MIMO design
- Reserved space for 3.75G HSUPA USB module
- Optional GPS receiver
- Optional EM or Mifare RFID reader
- Optional Bluetooth module
- Built-in 2-megapixel webcam with AF, AE and AWB capabilities
- CAN-bus interface with isolation
- Robust die-casting aluminum chassis



Specifications

Model Name		UPC-V312-D525-R13
Display	LCD Size	12.1"
	Max. Resolution	1024(W) x 768(H)
	Brightness (cd/m²)	600
	Contrast Ratio	700:1
	LCD Color	16.2M
	Pixel Pitch (mm) (HxV)	0.24(H) x 0.24(V)
	Viewing Angle (V/H)	150° / 130°
	Backlight MTBF (hrs)	50000
Touch	Touchscreen	5-wire resistive type with RS-232 interface
	Touch Controller	DMC 9000
Motherboard	SBC	UPCMB-V312-D525-R10
	CPU	Intel® Atom™ D525 1.8GHz dual-core processor
	Chipset	Intel® ICH8M
	RAM	On-board 2GB DDR3 SO-DIMM (system max. 2GB)
	Ethernet	Realtek RTL8111CP PCIe GbE controller
I/O Ports and Switches	Audio Codec	Realtek ALC888 audio codec
		RS-422/485 (4-pin box header)
		RS-232 (DB-9 connector)
		CAN-bus (3-pin terminal block)
		GbE LAN (RJ-45 connector)
		4 x USB connector
		Audio jack (Line-out, Mic)
		VGA port (DB-15 connector)
		DC-IN 1 (terminal block) / DC-IN 2 (DC jack)
		Reset button
		AT/ATX switch
Connectivity	Wireless	IEEE 802.11a/b/g/n 3T3R module (WIFI-RT5393-DB-R10) Telecom certified
	Bluetooth	Bluetooth V2.0+EDR with USB interface (optional)
Driver Bay	3G	Reserved USB connector (optional)
	SSD	CF Type II / mSATA (SATA2 signal)
Physical	Front Panel Construction	Aluminum die-casting
	Chassis Construction	Extruded aluminum alloy
	Mounting	VESA 100mm x 100mm and 75mm x 75mm with M8 screws
	Front Panel Color	Orange (Pantone 151C)
	Dimensions (WxHxD) (mm)	338.5 x 276.25 x 62.86
	Cut Out Dimensions (WxH) (mm)	338.5 x 276.25
Expansion Slot		4.5 kg/ 6.8 kg
		PCIe Mini slot for Wi-Fi module
System Cooling		PCIe Mini slot
		Fanless
Environment	Operating Temperature	-20°C~60°C
	Storage Temperature	-40°C~85°C
	Vibration	MIL-STD-810F 514.5C-2 (with CF card or SSD)
	Shock	Half-sine wave shock 3G; 11ms; 3 shocks per axis
	IP Level	Full IP 65
	Safety & EMC	CE / FCC
Power	Adapter	65W power adapter (meets PSE) (Power adapter supports operating temperature 0°C ~ 40°C) Input: 90VAC~264VAC, 50/60Hz; Output: 19V DC
	Requirement	Power 1: 9V (+/-0.3)~36V Power 2: 10.5V (+/-0.3)~36V
	Consumption	52W

Ordering Information

Part No.	Description
UPC-V312-D525/R/2G-R13	12.1" 600cd/m ² XGA fanless full IP 65 panel PC with Intel® Atom™ D525 dual core 1.8GHz, 802.11a/b/g/n wireless module, resistive touch screen, 2-megapixel camera, microphone, 2GB DDR3 RAM, R13


Options

Item	P/N
Arm	ARM-11-RS/ARM-31-RS
Wall Mounting Kit	AFLWK-19B/ AFLWK-12
Stand	STAND-A19-RS/STAND-A21-R10/STAND-210-R11
EM RFID Kit	UPC-EM-RFID-KIT01-R10
MIFARE RFID Kit	UPC-MF-RFID-KIT01-R11
OS: Win CE 6.0 (128MB CF Card)	UPCCF-V312-D525-CE060-128M-R10
OS: Win XPE (4GB CF Card)	UPCCF-V312-D525-XPE-4G-R10
OS: Win 7 Embedded (4GB CF Card)	UPCCF-V312-D525-WES7E-4G-R10


Packing List

Item	P/N	Q'ty
Utility CD	7B000-000741-RS	1
One Key Recovery CD		1
IR Remote Controller	7Z000-SLPCB005-RS	1
RJ-45 to DB-9 COM Port Cable	32005-000200-200-RS	1
M8 Screw	44325-080081-RS	8
M4 Screw	44005-040082-RS	8
Mounting Bracket	41003-0382C2-00-RS	2
Screw Driver	45019-001004-00	1
Power Adapter	63040-010065-200-RS	1
Power Cord (European Standard)	32702-000401-100-RS	1
RS-422 Cable	32205-002400-100-RS	1
Power Transfer Cord	32702-000300-100-RS	1
M8 to M4 Screw	44300-040061-RS	8

I/O Interface

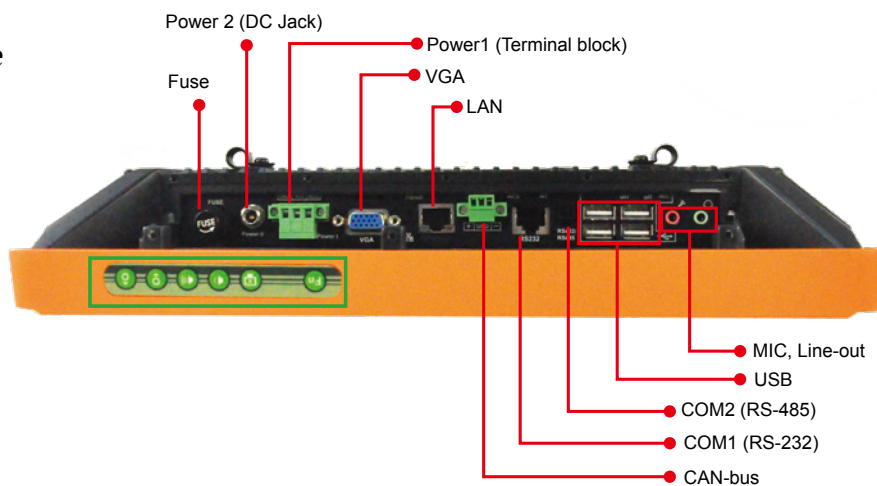

UPC-V312 Dimensions (Unit: mm)

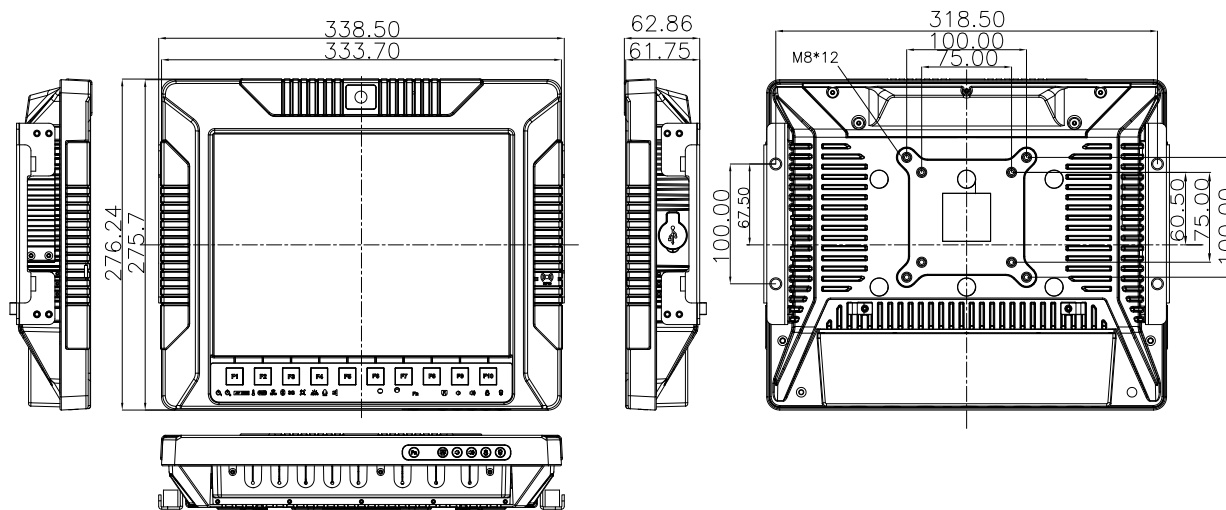

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

IEI:

[UPC-V312-D525/R-MF/2G-R11](#) [UPC-V312-D525/R-EM/2G-R11](#) [UPC-V312-D525/R/2G-R13](#) [UPC-V312-D525/R/2G-R12](#)