


3.5" SBC supports Intel® 6th/7th Generation ULT Processor with DDR4 SO-DIMM/On-board Memory Support, Triple Display, PCIe Mini with SIM Card Slot/mSATA Support, SATA 6Gb/s, COM, Audio, and RoHS

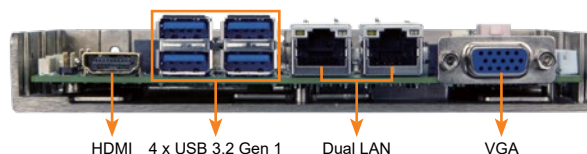

Features

- ◆ CPU
 - 7th generation Intel® mobile ULT processor
 - Intel® Core™ i7-7600U (up to 3.9GHz, dual-core, 4MB cache, TDP=15W)
 - Intel® Core™ i5-7300U (up to 3.5GHz, dual-core, 3MB cache, TDP=15W)
 - Intel® Core™ i3-7100U (up to 2.4GHz, dual-core, 3MB cache, TDP=15W)
 - 6th generation Intel® mobile ULT processor
 - Intel® Core™ i7-6600U (up to 3.4GHz, dual-core, 4MB cache, TDP=15W)
 - Intel® Core™ i5-6300U (up to 3.0GHz, dual-core, 3MB cache, TDP=15W)
 - Intel® Core™ i3-6100U (up to 2.3GHz, dual-core, 3MB cache, TDP=15W)
 - Intel® Celeron® processor 3955U (up to 2.0GHz, dual-core, 2MB cache, TDP=15W)
- ◆ BIOS: AMI UEFI BIOS
- ◆ Memory
 - 1 x 260-pin 2133MHz DDR4 SDRAM SO-DIMM (channel 1, supports up to 16GB)
 - On-board 4GB DDR4 memory (channel 2, optional support by request)
- ◆ Graphics Engine
 - Intel® HD Graphics
- ◆ Display Output
 - Triple independent display
 - 1 x VGA (up to 1920x1200@60Hz)
 - 1 x HDMI (up to 4096x2160@30Hz)
 - 1 x 18/24-bit dual-channel LVDS (up to 1920x1200@60Hz)
 - 1 x iDP interface for HDMI, LVDS, VGA, DVI, DP (co-layout with VGA)
- ◆ Ethernet
 - 1 x Intel® I219LM
 - 1 x Intel® I211AT
- ◆ External I/O Interface
 - 4 x USB 3.2 Gen 1 (5Gbps)
- ◆ Internal I/O Interface
 - 1 x SATA 6Gb/s with 5V SATA power connector
 - 2 x USB 2.0 (2x4 pin, P=2.0)
 - 2 x RS-232/422/485 (1x9 pin, P=1.25)
- ◆ SMBus
 - 1 x SMBus (1x4 pin, P=2.0)
- ◆ Audio
 - 1 x HD audio (2x5 pin, support 7.1 channel HD audio by IEI AC-KIT-888S-R10 kit)
- ◆ Front Panel
 - 1 x Power LED & HDD LED (1x6 pin)
 - 1 x Power button (1x2 pin)
 - 1 x Reset button (1x2 pin)
- ◆ Expansion
 - 1 x Full-size PCIe Mini slot (w/ SATA signal, supports mSATA)
 - 1 x Full-size PCIe Mini slot (w/ SIM card slot support)
 - * 3955U belongs to Skylake ULT Base series which supports PCIe Gen 2 signal only.*
- ◆ Digital I/O
 - 1 x 8-bit digital I/O (2x5 pin)
- ◆ Fan Connector
 - 1 x System fan connector (1x4 pin)
- ◆ Watchdog Timer
 - Software programmable, supports 1~255 sec. system reset
- ◆ Power Supply
 - 12V only DC input
 - 1 x Internal power connector (2x2 pin, or optional terminal block)
- ◆ Power Consumption
 - 12V@4.27A (Intel® Core™ i7-6600U up to 3.4GHz CPU with 16GB 2133MHz DDR4 memory running in 3.0GHz)
- ◆ Operating Temperature: -20°C ~ 60°C
- ◆ Storage Temperature: -30°C ~ 70°C
- ◆ Operating Humidity: 5% ~ 95%, non-condensing
- ◆ Dimensions: 146mm x 102mm
- ◆ Weight: GW: 600g / NW: 250g
- ◆ CE/FCC compliant

- 3.5" SBC with Intel® 6th/7th Generation ULT processor supports DDR4 SO-DIMM (on-board memory support by request)
- Triple display with VGA/iDP, HDMI and LVDS selection
- Two PCIe Mini with mSATA/SIM card slot support
- Intel® GbE LAN with Intel® AMT 11.0 supported

1 x WAFER-ULT3/ULT4 single board computer (heat spreader by default)

1 x Power cable	1 x SATA with power cable kit
1 x RS-232/422/485 cable	1 x QIG

Part No.	Description
WAFER-ULT3-I7-R11	3.5" SBC supports Intel® 6th Generation ULT Core™ i7-6600U processor with DDR4 SO-DIMM, triple display with VGA/iDP, HDMI, LVDS, Dual GbE, PCIe Mini with SIM card slot/mSATA support, SATA 6Gb/s, COM and RoHS
WAFER-ULT3-I5-R11	3.5" SBC supports Intel® 6th Generation ULT Core™ i5-6300U processor with DDR4 SO-DIMM, triple display with VGA/iDP, HDMI, LVDS, Dual GbE, PCIe Mini with SIM card slot/mSATA support, SATA 6Gb/s, COM and RoHS
WAFER-ULT3-I3-R11	3.5" SBC supports Intel® 6th Generation ULT Core™ i3-6100U processor with DDR4 SO-DIMM, triple display with VGA/iDP, HDMI, LVDS, Dual GbE, PCIe Mini with SIM card slot/mSATA support, SATA 6Gb/s, COM and RoHS
WAFER-ULT3-C-R11	3.5" SBC supports Intel® 6th Generation ULT Celeron® 3955U processor with DDR4 SO-DIMM, triple display with VGA/iDP, HDMI, LVDS, Dual GbE, PCIe Mini with SIM card slot/mSATA support, SATA 6Gb/s, COM and RoHS
WAFER-ULT4-I7-R11**	3.5" SBC supports Intel® 7th Generation ULT Core™ i7-7600U processor with DDR4 SO-DIMM, triple display with VGA/iDP, HDMI, LVDS, Dual GbE, PCIe Mini with SIM card slot/mSATA support, SATA 6Gb/s, COM and RoHS
WAFER-ULT4-I5-R11	3.5" SBC supports Intel® 7th Generation ULT Core™ i5-7300U processor with DDR4 SO-DIMM, triple display with VGA/iDP, HDMI, LVDS, Dual GbE, PCIe Mini with SIM card slot/mSATA support, SATA 6Gb/s, COM and RoHS
WAFER-ULT4-I3-R11**	3.5" SBC supports Intel® 7th Generation ULT Core™ i3-7100U processor with DDR4 SO-DIMM, triple display with VGA/iDP, HDMI, LVDS, Dual GbE, PCIe Mini with SIM card slot/mSATA support, SATA 6Gb/s, COM and RoHS
32001-008600-200-RS	Dual-port USB 2.0 cable, 210mm, P=2.0
32005-003500-200-RS	RS-232/422/485 cable, 250mm, P=1.25
34000-000673-RS	Optional fanless heatsink module, 146mm x 102mm x 16mm

★★By order production, MOQ:100

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[IEI:](#)

[WAfer-ULT3-C-R11](#) [WAfer-ULT3-i3-R11](#) [WAfer-ULT3-i5-R11](#) [WAfer-ULT4-i5-R11](#) [WAfer-ULT3-i7-R11](#)