


CRYSTAL CLOCK OSCILLATORS (SMD · Ceramic Package)

RoHS compliant

CSX-750F


1,000pcs/reel

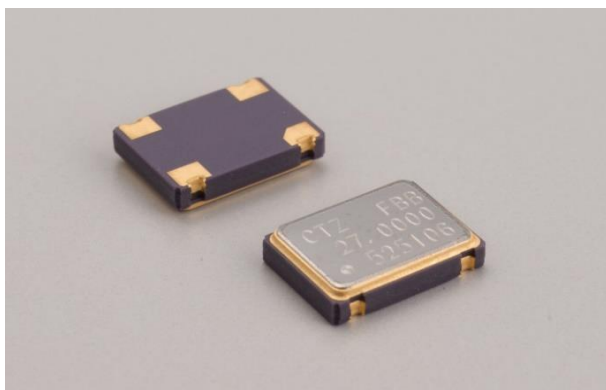


FEATURES

- Frequency range : 1.8432 ~ 39.999MHz
- External dimensions (mm)
L : 7.0 x W : 5.0 x H : 1.6
- Applications
Consumer products

DIMENSION [mm]

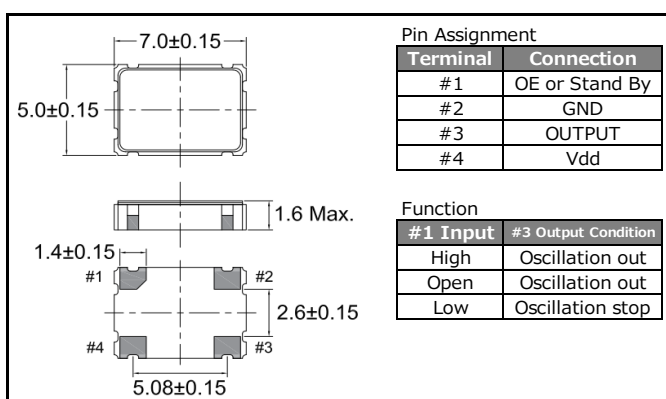

SOLDER PAD LAYOUT [mm]

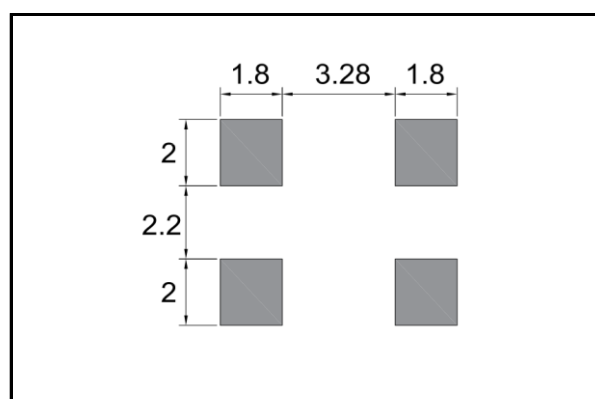


STANDARD SPECIFICATIONS

*Model is determined by selection of OE/ST functions, frequency stability, and supply voltage.


Item	Model	OE	CSX-750FC (*)	CSX-750FB (*)
		STAND-BY		
Frequency Range			1.8432~39.999MHz	
Supply Voltage			Vdd: 5.0V±0.5V	Vdd: 3.3V±0.3V
Frequency Stability	(*)		B: ±50ppm(−20°C ~ +70°C), C: ±100ppm(−20°C ~ +70°C) E: ±50ppm(−40°C ~ +85°C), F: ±100ppm(−40°C ~ +85°C)	
Operating Temperature Range			−20°C ~ +70°C / (−40°C ~ +85°C)	
Storage Temperature Range			−55°C ~ +125°C	
Current consumption			25mA Max.	15mA Max.
Duty	TTL level (1.4V) CMOS level (1/2 Vdd)		40~60%	—
Output Voltage	V _{OH} V _{OL}		0.4V Max.	0.1Vdd Max.
Output Load	TTL CMOS		10TTL Max. 50pF Max.	— 30pF Max.
Rise and Fall Time			8 nsec Max.	
Start-up time			4 msec Max.	
Input Voltage	V _{IH} V _{IL}		2.0V Min. 0.8V Max.	0.4V Max.
Disable current			10mA Max.	5mA Max.
Stand-by current			—	

■ PART NUMBERING SYSTEM

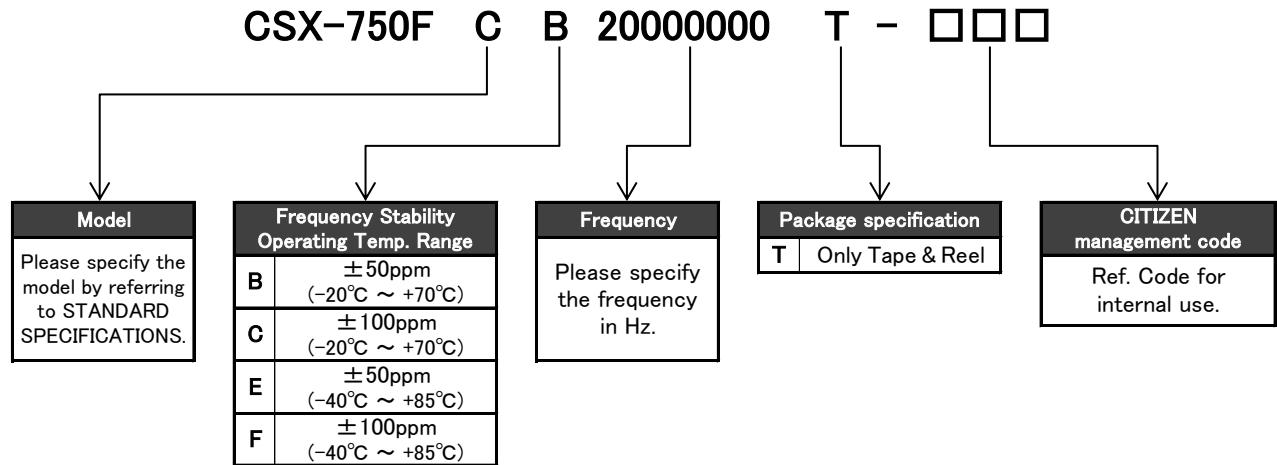

*Please contact us for specifications available.

■ Part Marking [standard]

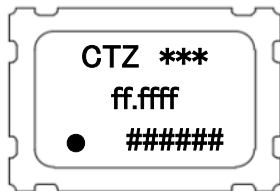


CTZ : Manufacture's ID Code

* : Model


f : Frequency

: Production Lot No.


■ Reflow profile

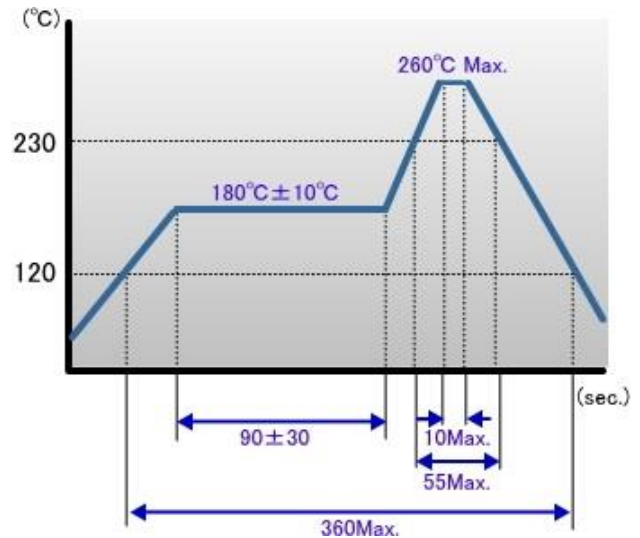

■ Packing

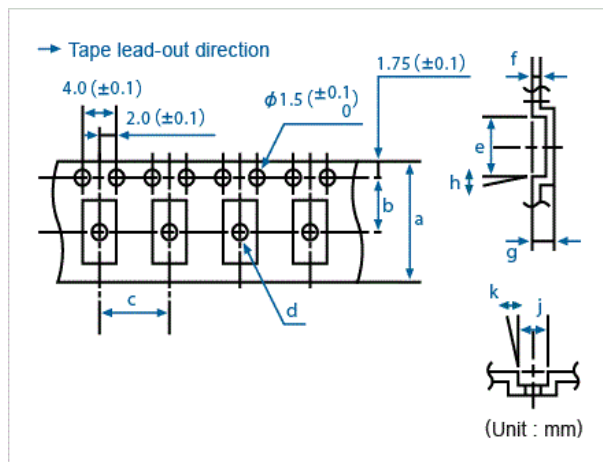

Conforming to JIS C 0806 TB1208NEIAJ and RC-1009B TE1208N

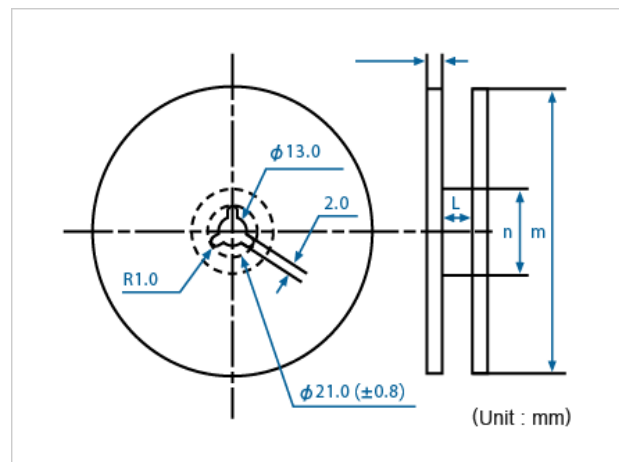

Conforming to JIS C 0806 R12R and EIAJ RC-1009B R15

Q'ty/reel	a	b	c	d (φ)	e	f	g	h	j	k	l	m (φ)	n (φ)
1,000	16.0	7.5	8.0	1.5	7.4	0.3	1.9	5°	5.4	5°	16.0	180	62

Product specifications are subject to change without notice.

Rev.3

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Citizen:

<u>CSX-750FCC15360000T</u>	<u>CSX-750FBB1000000T</u>	<u>CSX-750FBB11059200T</u>	<u>CSX-750FBB12000000T</u>	<u>CSX-</u>
<u>750FBB12288000T</u>	<u>CSX-750FBB14318180T</u>	<u>CSX-750FBB14745600T</u>	<u>CSX-750FBB16000000T</u>	<u>CSX-</u>
<u>750FBB16384000T</u>	<u>CSX-750FBB18432000T</u>	<u>CSX-750FBB20000000T</u>	<u>CSX-750FBB24000000T</u>	<u>CSX-</u>
<u>750FBB24576000T</u>	<u>CSX-750FBB25000000T</u>	<u>CSX-750FBB27000000T</u>	<u>CSX-750FBB29491200T</u>	<u>CSX-</u>
<u>750FBB30000000T</u>	<u>CSX-750FBB32000000T</u>	<u>CSX-750FBB32768000T</u>	<u>CSX-750FBB33333000T</u>	<u>CSX-</u>
<u>750FBB35328000T</u>	<u>CSX-750FBB3686400T</u>	<u>CSX-750FBB4000000T</u>	<u>CSX-750FBB7372800T</u>	<u>CSX-750FBB8000000T</u>