



MJ8-CAT5E

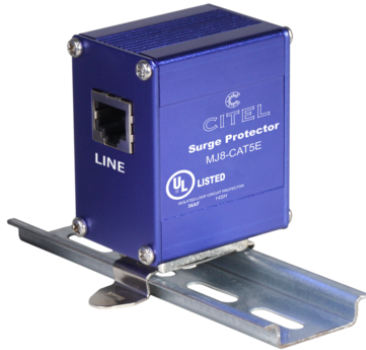

Cat.5,5E,andCat.6SurgeProtector • HybridGDTandDiodeTechnology • 10/100 /1000MbpsCompatible • Bi-DirectionalProtection • ShieldedConnectorConfigurations • DINRail,ScrewLug,andFlangeMounting

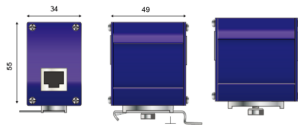

Installation		
Operating Temperature(Min)	°C	-40.0000
Operating Temperature(Max)	°C	85.0000
Operating Temperature(Min)	°F	-40.0000
Operating Temperature(Max)	°F	85.0000
Operating Relative Humidity(Max)	%RH	95
Operating Altitude(Min)	Ft	2000.0000
Operating Altitude(Max)	Ft	6500.0000
Housing/Enclosure material		Aluminum
Mounting		Flange
IP Environmental rating(IP)		IP20
Installation Location		indoor
Product Dimension(L)	mm	44.0000
Product Dimension(H)	mm	54.0000
Product Dimension(W)	mm	34.0000
Product Dimension(L)	In	1.7300
Product Dimension(H)	In	2.1200
Product Dimension(W)	In	1.3300
Miscellaneous		
Individual Pack		Yes
Storage Temperature(Min)	°C	-40.0000
Storage Temperature(Max)	°C	85.0000
Storage Temperature(Min)	°F	-40.0000
Storage Temperature(Max)	°F	85.0000
Installation		
Cable type		Ethernet
Electrical Characteristics		
Insertion loss		< 1 dB
Max. load current	IL	1000 mA
Max. capacitance	C	< 25 pF
Impulse current (2 x 10/350µs Test - D1 Category)	limp	500 A
Capacity(Maximum)	pF	<25
Mechanical Characteristics		
Weight		0.114 kg
Standards		
Certification		UL listed
Part number		
560201		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Citel:

[MJ8-CAT5E](#)