




- Hybrid MOV-GSG Technology
- UL1449 Type 1 LISTED
- 50kA Surge Current Rating per mode
- Extended life with no leakage current
- Visual LED fault indicator and audible alarm
- NEMA 6 (exceeds NEMA 4X or 4)
- Optional Type 2 LISTED with UL1283 Filter
- 10-Year warranty

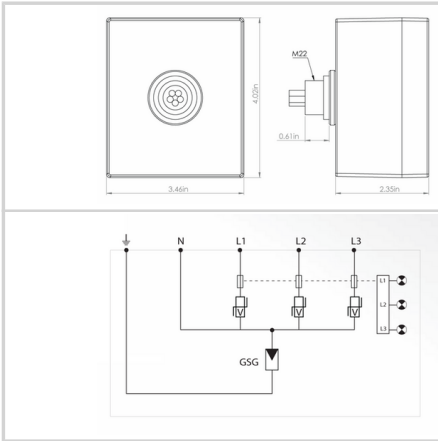

Electrical Characteristics		
Let through Voltage <i>Ures</i> at 20kA	V	1500.0000
Installation		
Operating Temperature _{Min}	°C	-40.0000
Operating Temperature _{Max}	°C	85.0000
Operating Temperature _{Min}	°F	-40.0000
Operating Temperature _{Max}	°F	85.0000
Operating Relative Humidity _{Max}	%RH	Can be submerged
Operating Altitude _{Min}	Ft	2000.0000
Operating Altitude _{Max}	Ft	6500.0000
Housing/Enclosure material		Aluminum cast
Mounting		Side mount
IP Environmental rating/IP		IP66
NEMA Environmental rating/NEMA		NEMA 6
Installation Location		Indoor / outdoor
Accessories		brackets
Product Dimension _L	mm	102.0000
Product Dimension _H	mm	62.0000
Product Dimension _W	mm	88.0000
Product Dimension _L	In	4.0160
Product Dimension _H	In	2.4410
Product Dimension _W	In	3.4650
Miscellaneous		
Individual Pack		Yes
Storage Temperature _{Min}	°C	-40.0000
Storage Temperature _{Max}	°C	85.0000
Storage Temperature _{Min}	°F	-40.0000
Storage Temperature _{Max}	°F	85.0000
Part number		
751511		



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Citel:](#)

[M50-277Y-B](#)