
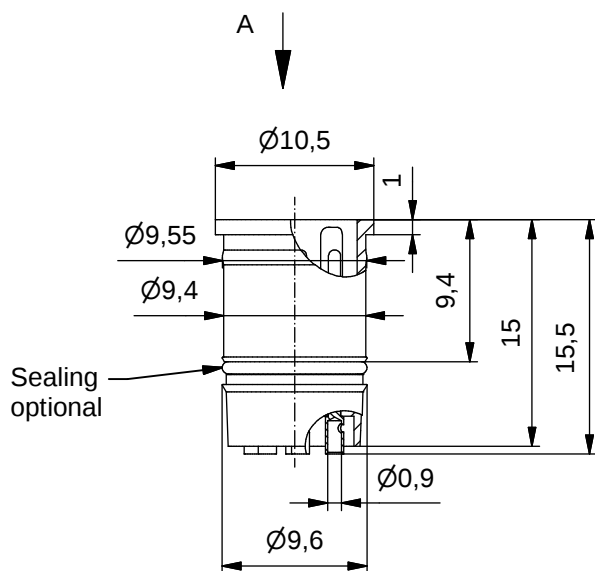


Technical specification:

 
Rated voltage:	30 V
IEC 61076-2-101	
Current rating:	2 A at 40°C
IEC 61076-2-101	
Insulation resistance:	>=100 MΩ
IEC 60512	
Pollution degree:	3/2
IEC 60664-1	
Degree of protection:	IP 67, in mated condition
IEC 60529	
Temperature range:	-30°C ... +130°C
EN 60512-11-10	-40°C
EN 60512-11-4	-40°C ... +130°C
UL 2238	-30°C ... +130°C
Mating cycles:	>=100
IEC 60512-9a	

 
Materials:

Contact:	CuZn, Ni b / Au 0,2 gal.
Contact carrier:	PA GF, UL 94 V-0 like RAL9005
Sealing:	FPM

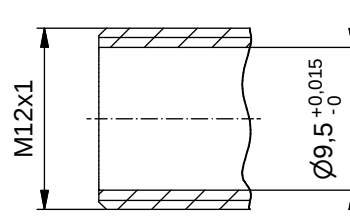

Part no:	Description:	Pos	Construction:
43-01637	SAL - 12 - ES8 - L	8	without sealing
43-01638	SAL - 12 - ESO8 - L	8	with sealing

DO NOT ALTER CAD DRAWING BY HAND	RoHS & REACH compliant	Index: d 11.06.15 fro Ä5678 UL adaptation				dim. in mm		title: Panel plug M12x1 with soldering version		
				date		name		dwg no: 43K1A1176		
				drawn		30.09.10	Franz			
				appd.		30.09.10	Mankopf		part no:	
		general tolerance:		0	± 0,50mm					43K1A1176
				0,0	± 0,25mm					
				0,00	± 0,10mm					
				±	± 1,5°					
THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH										



date	name
30.09.10	Franz
30.09.10	Mankopf



Panel plug M12x1 with soldering version	
43K1A1176	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CONEC:](#)

[43-01637](#)