



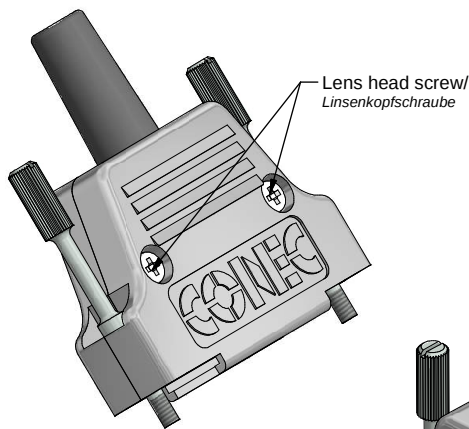

Lens head screw/
Linsenkopfschraube

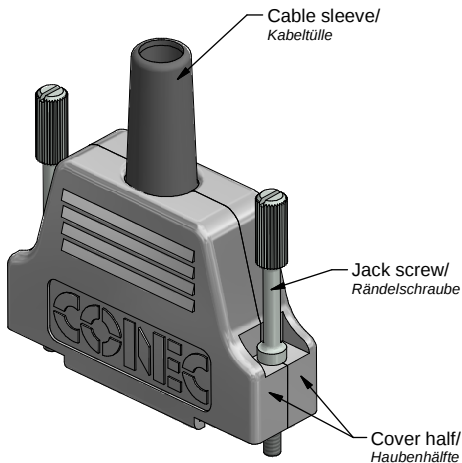

Cable sleeve/
Kabeltülle

Jack screw/
Rändelschraube

Cover half/
Haubenhälfte

b) Technical specification:

Technische Daten:


Temperature range/ $-35\text{ }^{\circ}\text{C} \dots +90\text{ }^{\circ}\text{C}$
Temperaturbereich:

Materials/ Werkstoffe:

Cover half/
Haubenhälfte: GD-Zn, Ni
Cable strain relief/
Kabel Zugentlastung: Steel, Ni
Cable sleeve/
Kabeltülle: Rubber
Jack screw/
Rändelschraube: Steel, Ni
Lens head screw/
Linsenkopfschraube: Steel, Ni

Installation specification/ Montagedaten:

Cable outlet/
Kabelausgang: straight/ gerade

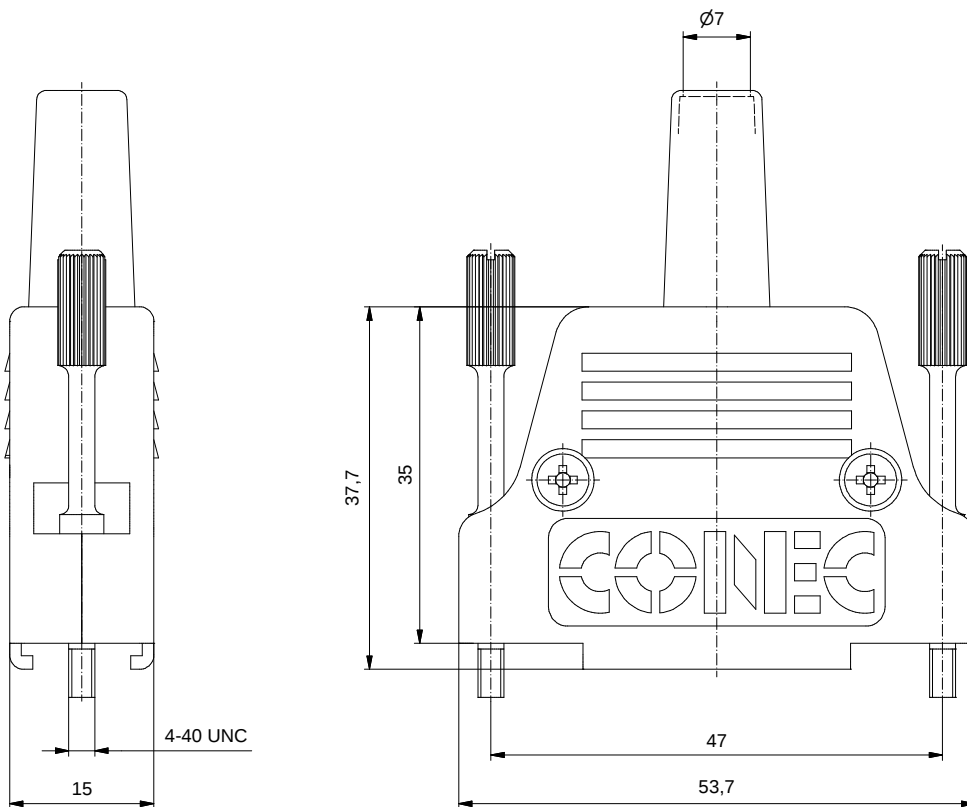

Part no./ Art.-Nr.	
165X17329X	Bulk package/ Massenverpackung
165X17329XE	Single package/ Einzelverpackung

				dim. in mm		Full metal hood 25pos. with straight cable exit Vollmetallhaube 25pol. mit gradem Kabelausgang	
		drawn/ gez.	Date/Datum	Name			
		appd./ gepr.	16.04.2018	Unkrüer			
			17.04.2018	Schmidt			
Index: b Ä7223 16.04.18 L.U.	scale/Maßstab: 2:1			dwg no / Z.-nr.:		16K1A4048	DIN- A3
Status: InBearbeitung							
RoHS compliant/ konform							1 / 1



CONEC®

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CONEC:](#)

[165X17329X](#)