


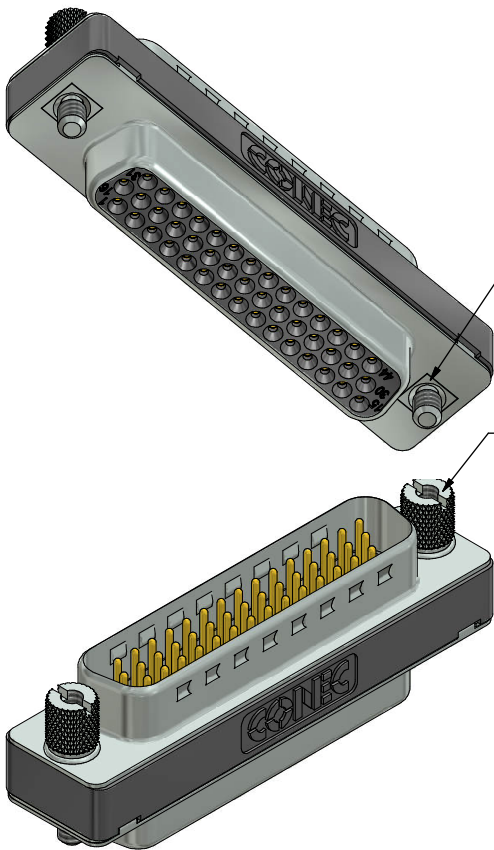

Threaded Insert/
Gewindeeinsatz

Jack Screw/
Rändelschraube

Technical specification:

Technische Daten:

Working voltage/ Betriebsspannung:	100 VDC
Current rating/ Strombelastbarkeit:	3 A (UL,VDE) / 2,5 A (CSA)
Insulation resistance/ Isolationswiderstand:	$\geq 1 \text{ G}\Omega$
Dielectric withstanding voltage/ Spannungsfestigkeit (DWV):	300 VDC
Voltage surge 10/700 μs / Impulsspannung 10/700 μs :	300 V
Temperature working range/ Umgebungstemperatur:	- 25 °C ... + 85 °C
Mating and unmating forces/ Steck- und Ziehkräfte:	$\leq 110 \text{ N}$
Capacitance value/ Kapazitätswert:	180 pF $\pm 20 \%$

Materials/





Werkstoffe:

Contact/ Kontakt:	Cu alloy, Au over Ni
Insulator/ Isolierkörper:	PBT GF UL 94 V-0, black/ schwarz
Shells/ Gehäuse:	Fe, Sn over Ni
Threaded Inserts/ Gewindeeinsätze:	Cu alloy, Sn over Ni
Jack Screws/ Rändelschraube:	Cu alloy, Ni

Installation specification/

Montagedaten:

Recommended torque	max. 6 in.LB/
Value for thread/ empfohlenes Drehmoment für Gewinde:	max. 67 Ncm

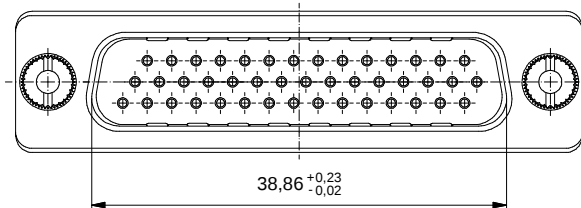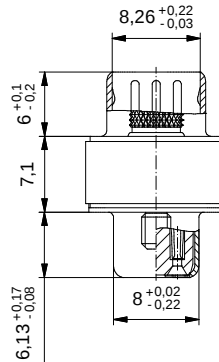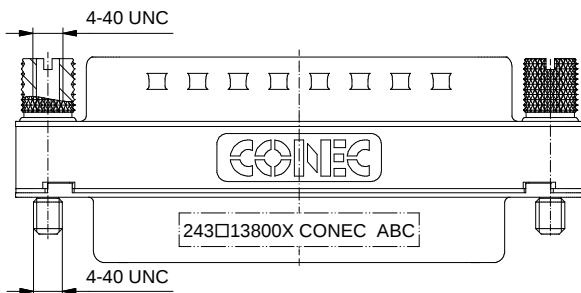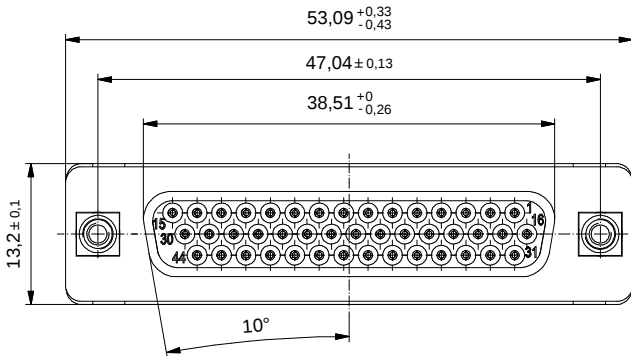

Part no. / Part Marked / Art.-Nr. / Bedruckung:	Quality class/ Gütestufe:	Contact plating / Kontakt Veredelung:
243A13800X	3	Gold Flash over Nickel Gold über Nickel
243B13800X	2	20 μm hard Gold over min. 50 μm Nickel 20 μm Gold über min. 50 μm Nickel
243C13800X	1	30 μm hard Gold over min. 50 μm Nickel 30 μm Gold über min. 50 μm Nickel

Index: Original		scale/Maßstab: 2:1		D-SUB HD LC-Filter Adapter 44pos. with jack screw 4-40 UNC D-SUB HD LC-Filter Adapter 44pol. mit Rändelschraube 4-40 UNC	
Status: InBearbeitung					
RoHS & REACH compliant/ konform				dwg no / Z.-nr.: 24K1A1727	DIN- A3
					1 / 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CONEC:](#)

[243A13800X](#)