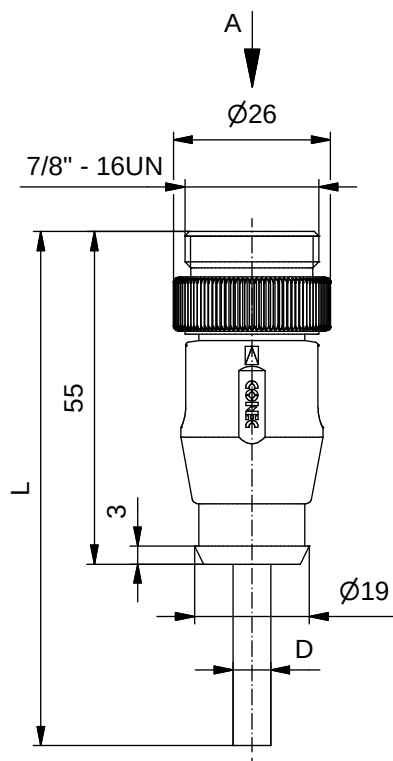


D see data sheet cable

Technical specification:

Rated voltage: IEC 60664-1	300 V
Overvoltage category: IEC 60664-1	2
Overvoltage: IEC 60664-1	2,7 kV
Current rating: IEC 60512-3 at 40°C	0,75mm ² 1,5mm ² 8 A 10 A
Insulation resistance: IEC 60512	>=100 MΩ
Pollution degree: IEC 60664-1	3/2
Degree of protection: IEC 60529	IP 68, in mated condition
Temperature range: IEC 60664-1	-30°C ... +80°C
Mating cycles: IEC 60512-9a	>=100
Termination:	crimped

 
Materials:

Contact:	CuZn
Contact plating:	Nickel, gold plated
Contact carrier:	TPU, UL 94
Coupling screw:	CuZn, nickel plated
Moulding body:	TPU, UL 94, grey

Contact assignment:

1	black
2	blue
PE	green-yellow
4	brown
5	white

Part no:	Description:	Length L:	Cable:
41-01072	SAL - 7/8 - RS4PE - 2 / A3	2m	PVC, UL 2464, grey, 5x0,75mm ² Cable: 781-A37500
41-01073	SAL - 7/8 - RS4PE - 3 / A3	3m	
41-01074	SAL - 7/8 - RS4PE - 5 / A3	5m	
41-01075	SAL - 7/8 - RS4PE - 10 / A3	10m	
41-xxxxx	SAL - 7/8 - RS4PE - ... / A3	x	
41-01169	SAL - 7/8 - RS4PE - 2 / A3 / 150	2m	PVC, UL 2464, grey, 5x1,50mm ² Cable: 781-A38500
41-01170	SAL - 7/8 - RS4PE - 3 / A3 / 150	3m	
41-01171	SAL - 7/8 - RS4PE - 5 / A3 / 150	5m	
41-01172	SAL - 7/8 - RS4PE - 10 / A3 / 150	10m	
41-xxxxx	SAL - 7/8 - RS4PE - ... / A3 / 150	x	

DO NOT ALTER CAD DRAWING BY HAND Directive 2002/95/EC RoHS compliant	Index: b 01.09.10 KH Ä3736 technical specification changed, part no. cable in table added, neutral line added		 dim. in mm		title: Male connector 7/8" axial	
			date	name		
	tolerance of cable: L <= 4m: L + 40mm L > 4m: L + 1%		drawn	19.10.07	Mankopf	dwg no: 41K1A323
			appd.	19.10.07	Franz	
	general tolerance: 0 ± 0,50mm 0,0 ± 0,25mm 0,00 ± 0,10mm					
THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH						

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[41-01171](#) [41-01074](#) [41-01169](#) [41-01072](#) [41-01170](#) [41-01172](#) [41-01073](#) [41-01075](#)