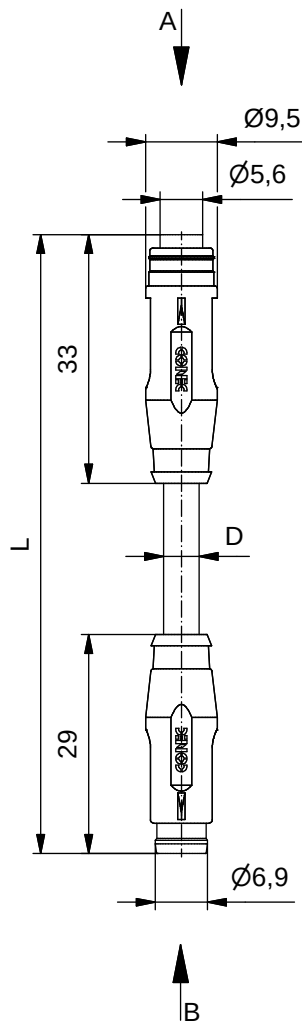


Technical specification :


Rated voltage: IEC 61076-2-104	30 V
Current rating: IEC 61076-2-104	3 A at 40°C
Insulation resistance: IEC 60512	$\geq 100 \text{ M}\Omega$
Pollution degree: IEC 60664-1	3/2
Degree of protection: IEC 60529	IP 67, in mated condition
Temperature range: IEC 60664-1	-30°C ... +80°C
Mating cycles: IEC 60512-9a	≥ 100

Materials:

Contact:	CuZn
Contact plating:	Nickel, gold plated
Contact carrier:	TPU GF, UL 94
Moulding body:	TPU, UL 94, grey

 
Contact assignment:

- 1) brown
- 2) white
- 3) blue
- 4) black

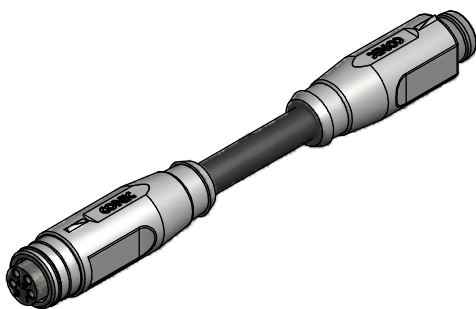

Part no:	Description:	Length L:	Cable:
42-10823	SAL - 8 - RKS4 - RSS4 - 0,3 / K1	0,3m	TPU, UL 20549, black, 4x0,25mm ² Cable: 781-K12400
42-10824	SAL - 8 - RKS4 - RSS4 - 0,6 / K1	0,6m	
42-10825	SAL - 8 - RKS4 - RSS4 - 1,5 / K1	1,5m	
42-10826	SAL - 8 - RKS4 - RSS4 - 3 / K1	3,0m	
42-xxxxx	SAL - 8 - RKS4 - RSS4 - ... / K1	x	

D see data sheet cable

DO NOT ALTER CAD DRAWING BY HAND Directive 2002/95/EC RoHS compliant	Index: a 21.03.11 VF Ä3941 data sheet revised	 dim. in mm	title: Connecting cable Ø8, female connector axial - male connector axial	
	tolerance of cable: L ≤ 4m: L + 40mm L > 4m: L + 1%			
	THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH		dwg no: 42K1A171	
			part no: see table	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[42-10826](#) [42-10823](#) [42-10824](#) [42-10825](#)