 







Male connector – straight and angled – 16, 32 and 48 positions



■ Solder nin

- Solder pin
- Quality class 3 (also available in quality class 2 or 1)
- Premating contacts in row "a", "b" and "c" available
- Special assembly on request

PCB hole pattern

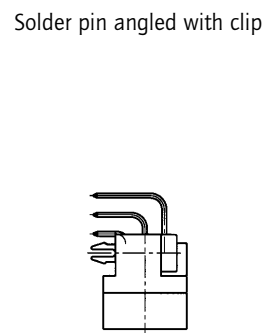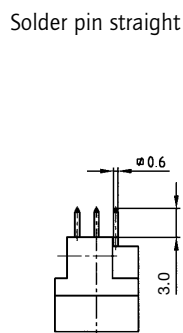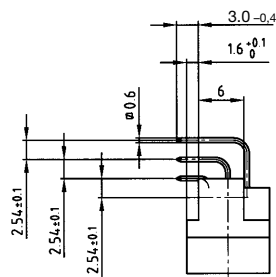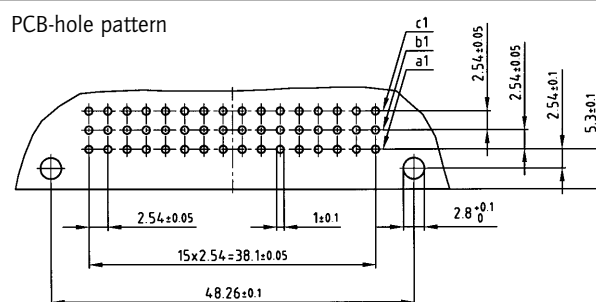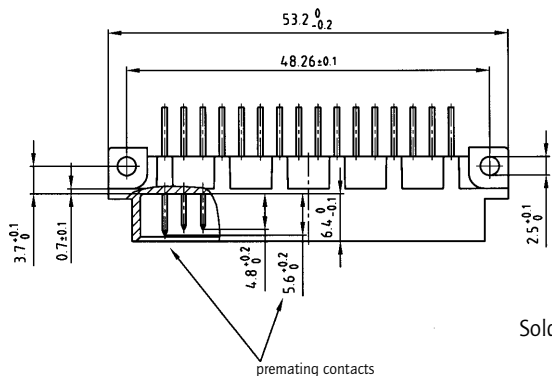

(Dim. = mm)

No. of Pos.	Row	• = contact, + = no contact							Solder pin angled	Solder pin straight	Solder pin angled with clip
		Pos.	1	2	3	4	5	...			
16	c		+	+	+	+	+	+	121 A 10349 X	121 A 10399 X	121 A 20929 X
	b		+	+	+	+	+	+			
	a		•	•	•	•	•	•			
16	c		+	•	+	•	+	•	121 A 10359 X	121 A 10409 X	121 A 20939 X
	b		+	+	+	+	+	+			
	a		+	•	+	•	+	•			
32	c		•	•	•	•	•	•	121 A 10379 X	121 A 10429 X	121 A 20959 X
	b		+	+	+	+	+	+			
	a		•	•	•	•	•	•			
48	c		•	•	•	•	•	•	121 A 10389 X	121 A 10439 X	121 A 20969 X
	b		•	•	•	•	•	•			
	a		•	•	•	•	•	•			

Clip for hole diameter 2.8 ± 0.1 mm, PCB thickness = 1.6 mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CONEC:](#)

[121A20959X](#)