

COMBINATION D-SUB CONTACTS

Coaxial contacts – Angled – Inner- and outer conductor crimp termination



RoHS compliant – CSA listed, File No.: LR 115000-1 – UL listed, File No.: E 228329


DESCRIPTION

- 50 and 75 Ω -design
- Contact platings mating area:
 - .051 μ " / 1.3 μ m Au inner conductor /
 - .032 μ " / 0.8 μ m Au outer conductor
 - .008 μ " / 0.2 μ m Au inner and outer conductor
- Contact platings termination area:
 - .008 μ " / 0.2 μ m Au
 - tin plated
- Other platings on request
- Delivery includes: contacts and sleeve supplied loose


PRODUCT DRAWING

50 Ω version


Socket contact

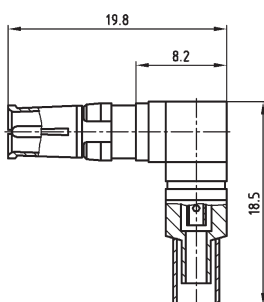

Installation dimension

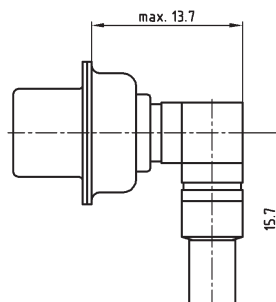


Plug contact

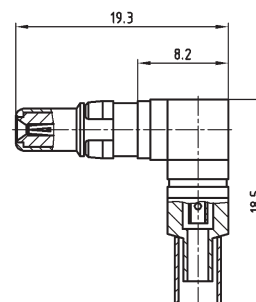


75 Ω version

Socket contact

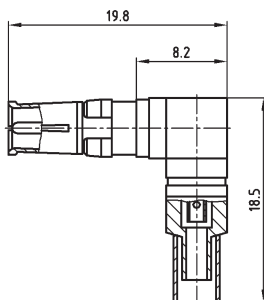


Wire stripping

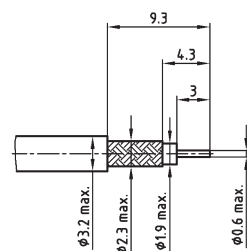

verwendbare Kabel: RG- 174U, 188AU, 316U
Usable Cables

Plug contact

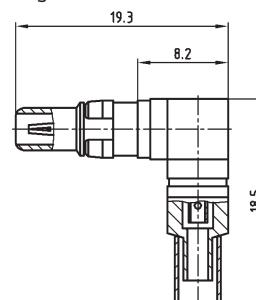

ORDER DATA

SOCKET CONTACT

Imp.	Cable	Part Number 1,3 μ m / tin plated	Part Number 1,3 μ m / 0,2 μ m
50 Ω	174U, 188AU, 316U	13-003304	132J23019X
75 Ω	179BU, 187AU	13-003314	132J33019X

PLUG CONTACT

Imp.	Cable	Part Number 1,3 μ m / tin plated	Part Number 1,3 μ m / 0,2 μ m
50 Ω	174U, 188AU, 316U	13-003324	131J23019X
75 Ω	179BU, 187AU	13-003334	131J33019X

SOCKET CONTACT

Imp.	Cable	Part Number 0,2 μ m / tin plated	Part Number 0,2 μ m / 0,2 μ m
50 Ω	174U, 188AU, 316U	13-003303	132A23019X
75 Ω	179BU, 187AU	13-003313	132A33019X

PLUG CONTACT

Imp.	Cable	Part Number 0,2 μ m / tin plated	Part Number 0,2 μ m / 0,2 μ m
50 Ω	174U, 188AU, 316U	13-003323	131A23019X
75 Ω	179BU, 187AU	13-003333	131A33019X

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CONEC:](#)

[132A23019X](#) [131A23019X](#)