



USB Connector A Type PCB R/A (male)

SPECIFICATIONS


Materials

Insulator: PBT with glass fiber fill
Flammability Rating: UL 94V - 0

Contacts: Phosphor bronze
Shell: Steel, nickel plated

Electrical

Insulation Resistance: 50 MΩ minimum
Contact Resistance: 30 mΩ Max.
Rating: 1A 100V AC
3A 12V DC
Dielectric Withstanding Voltage: 250V AC for one minute
Withdrawal Force: 0.5kg - 2.5kg

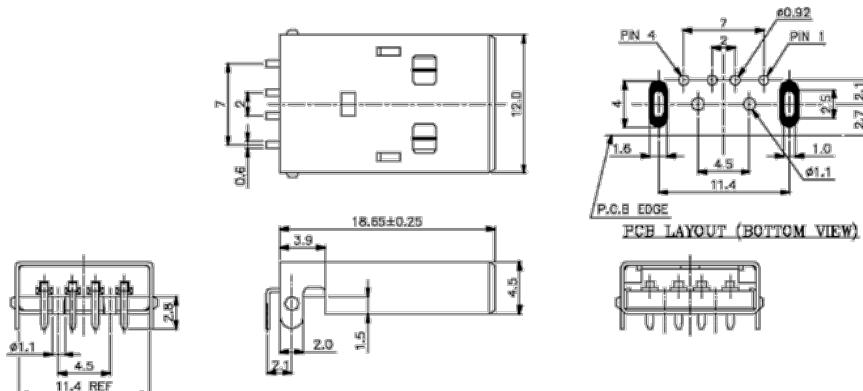

Order Information

33UBA R - 04 P N B 1

1 2 3 4 5 6 7
1. Series No.
33UBA

3. No. of Contacts
04: 4 pin

5. Insulator Color
N: Black
W: White

7. Packaging
1: Packed in tray

2. Terminal Version
R: Right angle

4. Connector Type
P: Male

6. Contact Plating
A: 5µ" gold
B: 30µ" gold



File #: 127344



File #: LR97981

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[33UBAR-04PWB1](#) [33UBAR-04PWA1](#)