

USB Connector B Type PCB R/A

SPECIFICATIONS

Materials

Insulator: thermoplastic, glass filled, UL 94V-0

Contacts: Phosphor bronze

Plated: 10µ" gold plated

SMD Plated: 120µ" tin plated

Plastic: PBT

Shell: Copper alloy, tin plated

Electrical

Insulation Resistance: 1000 MΩ minimum





Contact Resistance: 30 mΩ Max. initial

Dielectric Withstanding Voltage: 750V AC for one minute

Current: 1.5 Ampere max. per contact at 30°C T-rise

Voltage: 30V AC (rms)

Temperature: -55°C ~85°C

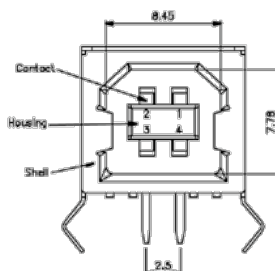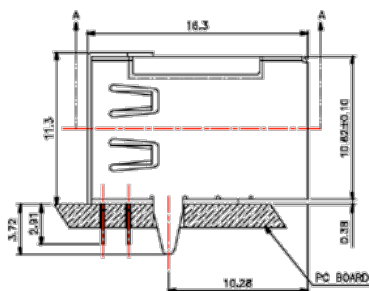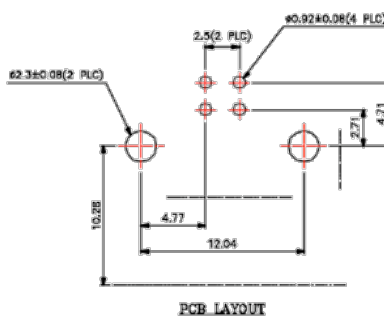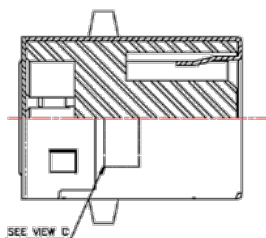

Order Information

33UBB R - 04 S W 1 1

1 2 3 4 5 6 7

1.Series No.

33UBB

3.No. Of Contacts

04: 4 pin

5. Insulator Color

W: White

7. Packaging

1: Packed in tray

2.Terminal Version

R: Right angle

4.Connector Type

S: Female

6. Shield

1: W/O back shell

0: W/ back shell



File #: 127344



File #: LR97981

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[33UBBR-04SW11](#)