

Very Low Profile PCB Jack(Side Entry, SMT Type)

Materials



Housing: Nyloy 46 with glass filled UL94V-0 Black

Contacts: 0.35mm thickness alloy, gold plating over nickel in contact area

Tin Plating over nickel in solder area

Directive 2002/95/EC
"RoHS"
Compliant

Pin	A	B	C
4	11.21	7.62	3.81
6	12.96	10.16	6.35
8	15.00	11.43	8.89
10	15.00	11.43	11.43

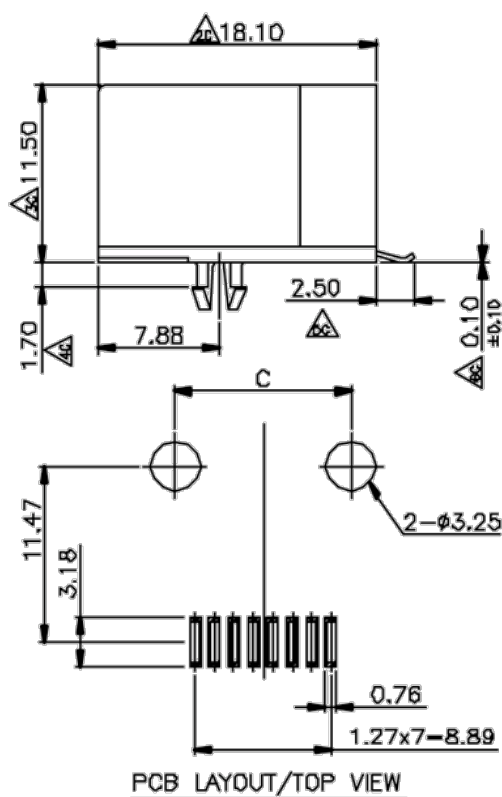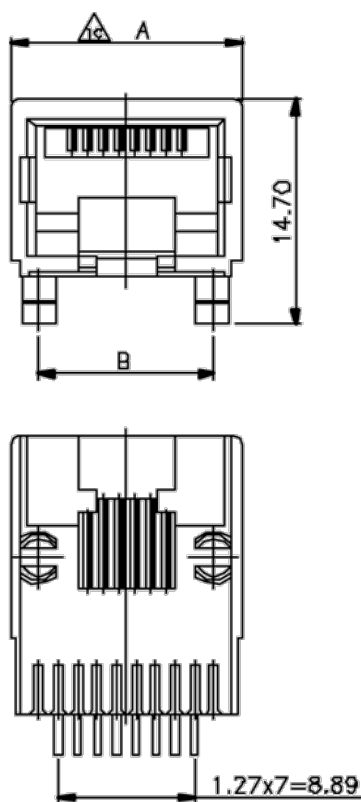

Order Information

33TS3004 - 88 B SMT 1

1 2 3 4 5

1. Series No.

33 TS3004

2. No. Of Contacts

44:4P4C

64:6P4C

66:6P6C

88:8P8C

1010:10P10C

3. Gold Plating

B: 6μ"

For other plating options
contact factory

4. Terminal Version

SMT Type

5. Packaging

1: Packed in tray

2: Tape & reel on request

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[33TS3004-88BSMT2](#) [33TS3004-88BSMT1](#) [33TS3004-64BSMT1](#) [33TS3004-44BSMT1](#)