


D-SUB STANDARD – IP67

Interface adapter – Connector Saver

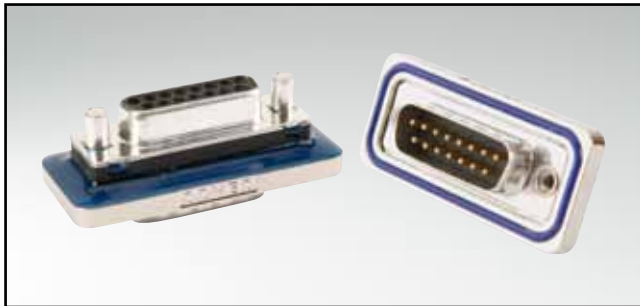


RoHS compliant




DESCRIPTION

- Plug to socket adapter
- Mounting style:
4-40 UNC threaded rear spacer including hex locking bolt
- Precision machined contacts
- Quality class 3 (also available in quality class 1)
- Shell: Brass tin plated
- Nickel plated die-cast frame

PRODUCT DRAWING

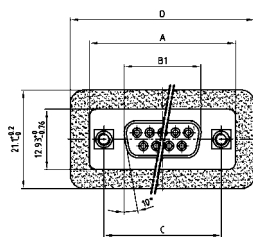

No. of Pos.	A -0.76	B1 -0.25	B2 +0.25	C	D +0.2
9	31.19	16.46	16.79	25.00 $+0.12/-0.13$	39.40
15	39.52	24.79	25.12	33.30 $+0.15/-0.10$	47.70
25	53.42	38.50	38.84	47.04 $+0.13$	61.40
37	69.70	54.96	55.30	63.50 $+0.13$	77.90

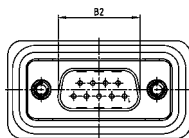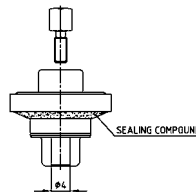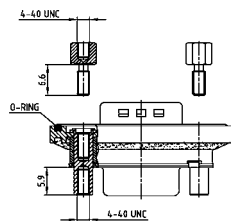

ORDER DATA

ADAPTER PLUG CONNECTOR - SOCKET CONNECTOR

No. of pos.	Mounting style 4-40 UNC	Part Number
09	Threaded rear spacer	6 STD09AAA99B90 X
15	Threaded rear spacer	6 STD15AAA99B90 X
25	Threaded rear spacer	6 STD25AAA99B90 X
37	Threaded rear spacer	6 STD37AAA99B90 X

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[4HDD26SAM99A10X](#) [15-000953](#) [15-000903](#) [15-000963](#)