

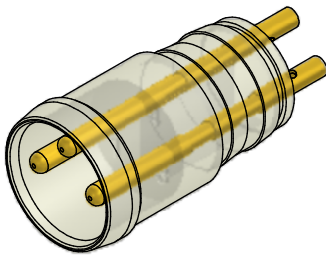
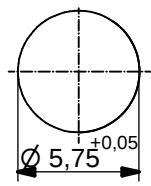


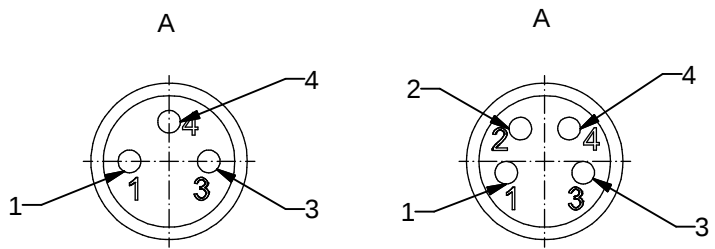

A
↓

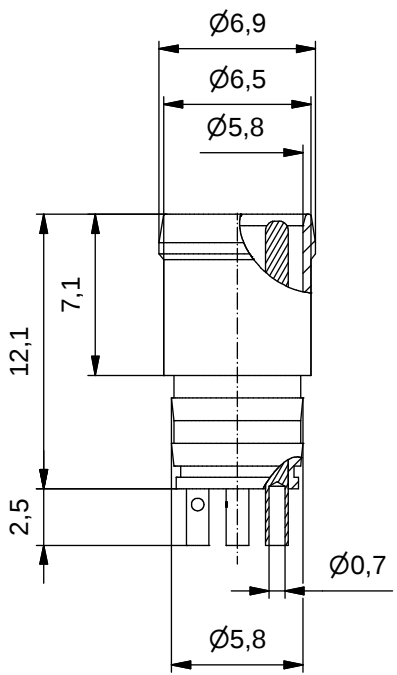

 
Technical specification:

Rated voltage: IEC 61076-2-104	3pos 4pos 60 V 30 V
Current rating: IEC 61076-2-104	3 A bei 40°C
Insulation resistance: IEC 60512	>=100 MΩ
Pollution degree: IEC 60664-1	3/2
Degree of protection: IEC 60529	IP 67, in mated condition
Temperature range: IEC 60664-1	-30°C ... +85°C
Mating cycles: IEC 60512-9a	>=100

Materials:

Contact:	CuZn
Contact plating:	Nickel, gold plated
Contact carrier:	PA, UL 94

Part no:	Description:	Pos	
42-01005	SAL - 8 - ESTP3 - L	3	
42-01007	SAL - 8 - ESTP4 - L	4	

DO NOT ALTER CAD DRAWING BY HAND Directive 2002/95/EC RoHS compliant	Index: a 02.03.11 fro A3914 Data sheet revised	 dim. in mm		title: Male socket M8x1 with soldering version	
		date	name		
		drawn	15.10.08	Fromm	dwg no: 42K1A110
		appd.	15.10.08	Mankopf	
	THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH				part no:



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[42-01005](#) [42-01007](#)