


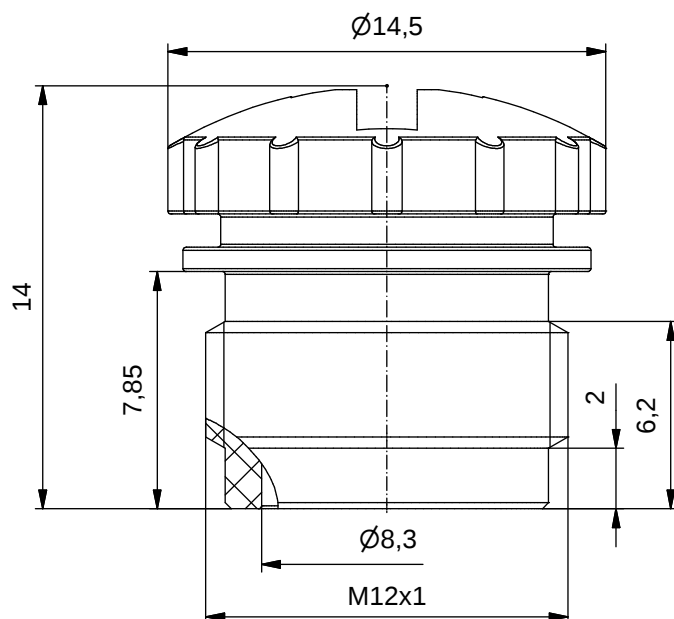

Technical specification:

Degree of protection: IP 67, in mated condition
IEC 60529

Temperature range: -30°C ... +120°C


Materials:

Protecting cap: PA GF

 
Loop: TPU-V

Installation specification:

Recommended torque: 0,6 Nm

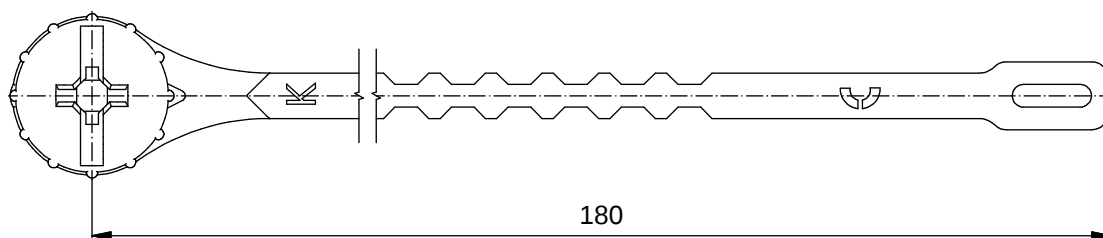

Part no:	Description:	Colour:
43-16212	Protecting cap M12x1 female socket with loop	black

DO NOT ALTER CAD DRAWING BY HAND Directive 2011/65/EU RoHS compliant	Index: b 11.11.13 Brū Ā4989 Data sheet revised, material changed		 dim. in mm		title: Protecting cap M12x1 with loop, female socket	
			date	name		
	tolerance of cable:		drawn	18.01.13	Kniesburgs	dwg no: 43K1A1802
			appd.	18.01.13	Mankopf	
	general tolerance:					part no: see table
	0 ± 0,50mm					
	0,0 ± 0,25mm					
0,00 ± 0,10mm		THIS DRAWING MAY NOT BE COPIED OR REPRODUCED IN ANY WAY, AND MAY NOT BE PASSED ON TO A THIRD PARTY WITHOUT WRITTEN PERMISSION. OWNERSHIP AND COPYRIGHT OF CONEC GmbH				

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CONEC:](#)

[43-16212](#)