


FLATCABLE CONNECTORS

Low profile header – straight

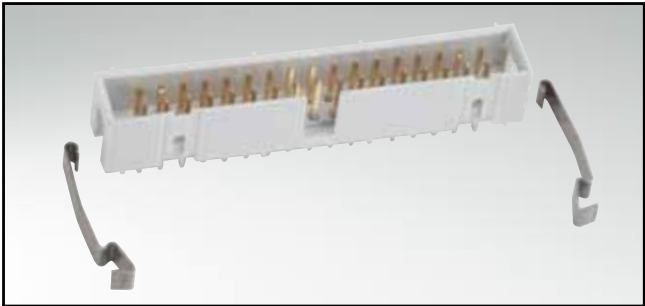


RoHS compliant

DESCRIPTION

- Solder pin
- Pin length 2.9 mm alternative 4.5 mm (*) on request
- 10 to 64 positions
- Center polarization
- Space saving version
- Clip latches need to be ordered separately

PRODUCT DRAWING

PCB-hole pattern

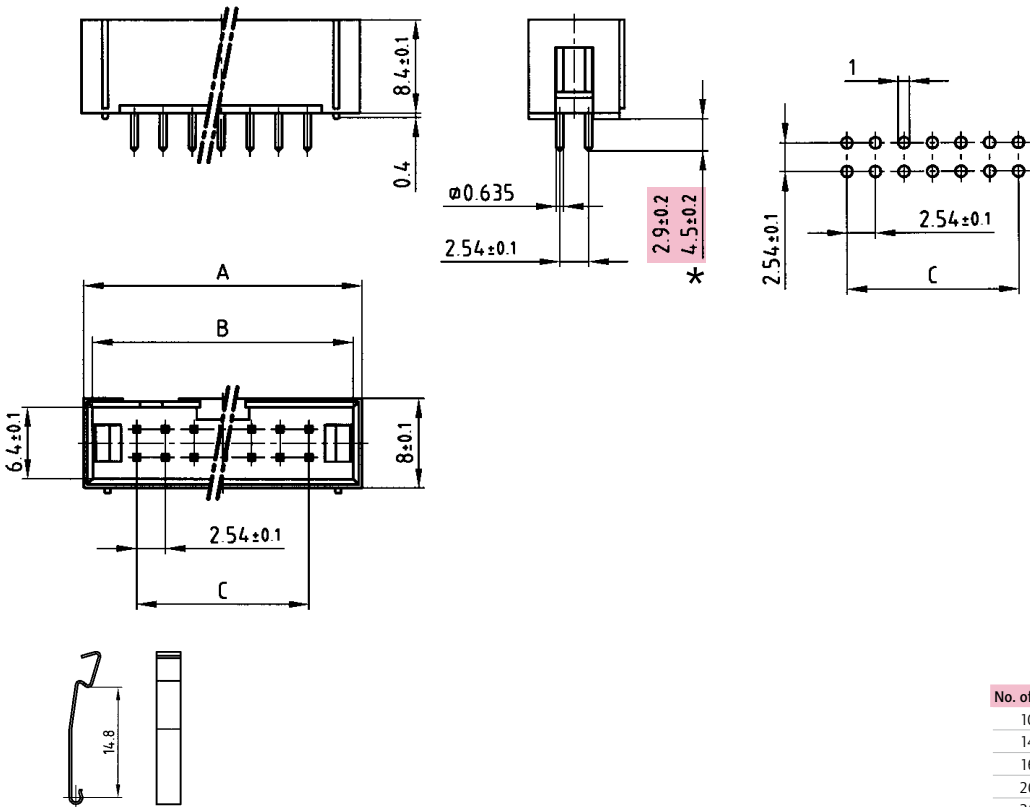

Clip latches
Part no. 140 X 10039 X

No. of Pos.	A ± 0.2	B ± 0.1	C ± 0.1
10	19,50	17,90	4 x 2.54 = 10.16
14	24,60	23,00	6 x 2.54 = 15.24
16	27,20	25,60	7 x 2.54 = 17.78
20	32,30	30,70	9 x 2.54 = 22.86
26	39,90	38,30	12 x 2.54 = 30.48
34	50,10	48,50	16 x 2.54 = 40.64
40	57,80	56,20	19 x 2.54 = 48.26
50	70,50	68,90	24 x 2.54 = 60.96
64	89,10	86,40	31 x 2.54 = 78.74

ORDER DATA

No. of Pos.	Pin length 2.9 mm	Pin length 4.5 mm*	No. of Pos.	Pin length 2.9 mm	Pin length 4.5 mm*
10	141 A 11639 X	141 A 11729 X	34	141 A 11689 X	141 A 11779 X
14	141 A 11649 X	141 A 11739 X	40	141 A 11699 X	141 A 11789 X
16	141 A 11659 X	141 A 11749 X	50	141 A 11709 X	141 A 11799 X
20	141 A 11669 X	141 A 11759 X	60	141 A 12269 X	141 A 12449 X
26	141 A 11679 X	141 A 11769 X			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CONEC:](#)

[141A11709X](#) [141A11689X](#) [141A11799X](#) [141A12269X](#) [141A11669X](#) [141A11649X](#) [141A11679X](#) [141A11639X](#)
[141A11659X](#) [141A11699X](#)