

TYPE C

Female connector – straight and angled – 32, 64 and 96 positions





RoHS compliant

DESCRIPTION



- Solder pin, solder lug and wire wrap
- Quality class 3 (also available in quality class 2 or 1)
- Special assembly on request

PRODUCT DRAWING


PCB-hole pattern

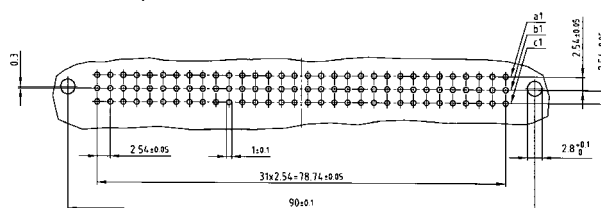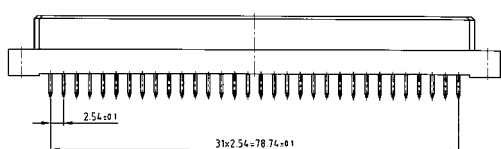


Panel cutout

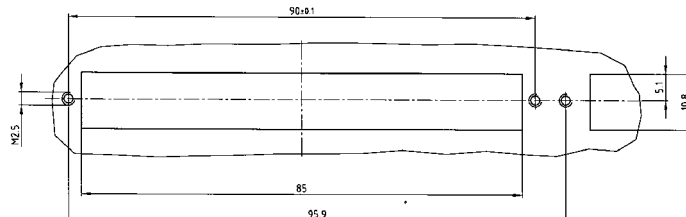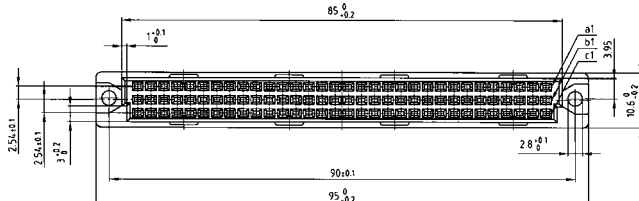


Wire Wrap

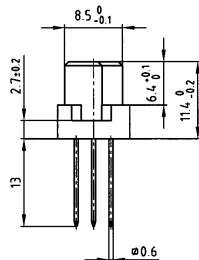


Solder pin straight 2.5 mm

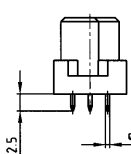


Solder pin straight 4 mm

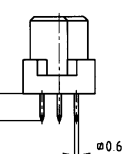


Solder lug

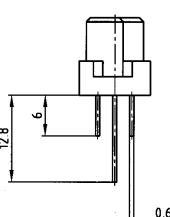

Solder pin angled

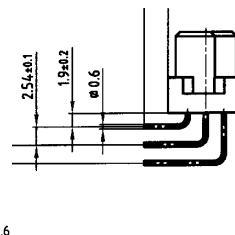

Solder pin straight 2.5 mm with clip

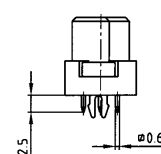

ORDER DATA

(Dim. = mm)

No. of Pos.	Row	• = contact, + = no contact					Wire Wrap	Solder pin straight 2.5 mm	Solder pin straight 4 mm	Solder lug	Solder pin angled	Solder pin straight 2.5 mm with clip
		Pos.	1	2	3	4	5					
32	a	•	•	•	•	•	•					
	b	+	+	+	+	+	+	122 A 10169 X	122 A 10219 X	122 A 10269 X	122 A 10319 X	122 A 10369 X
	c	+	+	+	+	+	+					
32	a	+	•	•	•	•	•	122 A 10179 X	122 A 10229 X	122 A 10279 X	122 A 10329 X	122 A 10379 X
	b	+	+	+	+	+	+					
	c	+	•	•	•	•	•					
64	a	•	•	•	•	•	•					
	b	+	+	+	+	+	+	122 A 10199 X	122 A 10249 X	122 A 10299 X	122 A 10349 X	122 A 10399 X
	c	•	•	•	•	•	•					
96	a	•	•	•	•	•	•					
	b	•	•	•	•	•	•	122 A 10209 X	122 A 10259 X	122 A 10309 X	122 A 10359 X	122 A 10409 X
	c	•	•	•	•	•	•					

Clip for hole diameter 2.8 + 0.1 mm, PCB thickness = 1.6 mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[122A10249X](#) [122A10379X](#) [122A10199X](#) [122A10369X](#) [122A10219X](#) [122A10229X](#) [122A10179X](#) [122A10169X](#)
[122A13249X](#) [122A10279X](#) [122A13259X](#) [122A13289X](#) [122A10269X](#) [122A10209X](#)