



D-SUB STANDARD

IDC for flat cable – Stamped contacts – For wire size AWG 26...28

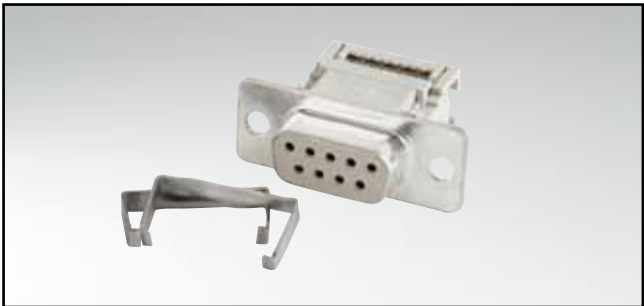

RoHS compliant – CSA listed, File No.: LR 115000-1 – UL listed, File No.: E202784


SOCKET CONNECTOR

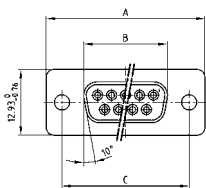

No. of pos.	A -0.76	B +0.25	C	E +0.10
09	30.80	16.30	25.00 +0.12	18.73
15	39.20	24.60	33.30 +0.15 -0.10	26.86
25	53.10	38.30	47.04 ±0.13	40.78
37	69.40	54.80	63.50 ±0.13	57.04

Mounting style: Through-hole

Upper part grouted with strain relief

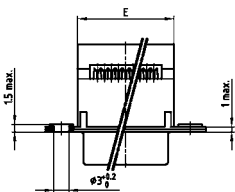


Strain relief



DESCRIPTION

- For wire size **AWG 26...28** flat cable
- Mounting style:
with through-hole, Ø .118" / 3 mm
- Strain relief need to be ordered separately
- Quality class 3 (also available in quality class 1)
- Shell: Steel tin plated


PLUG CONNECTOR

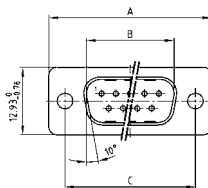


No. of pos.	A -0.76	B +0.25	C	E +0.10
09	30.80	16.79	25.00 +0.12	18.73
15	39.20	25.12	33.30 +0.15 -0.10	26.86
25	53.10	38.84	47.04 ±0.13	40.78
37	69.40	55.30	63.50 ±0.13	57.04

Mounting style: Through-hole

Upper part grouted with strain relief

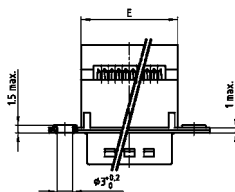

Strain relief

 

ORDER DATA

SOCKET CONNECTOR		
No. of pos.	Mounting style	Part Number
09	Through-hole	162 A 11899 X
15	Through-hole	162 A 11909 X
25	Through-hole	162 A 11919 X
37	Through-hole	162 A 11929 X
09	Strain relief	160 X 10019 X
15	Strain relief	160 X 10029 X
25	Strain relief	160 X 10039 X
37	Strain relief	160 X 10049 X

PLUG CONNECTOR		
No. of pos.	Mounting style	Part Number
09	Through-hole	161 A 13499 X
15	Through-hole	161 A 13509 X
25	Through-hole	161 A 13519 X
37	Through-hole	161 A 13529 X
09	Strain relief	160 X 10019 X
15	Strain relief	160 X 10029 X
25	Strain relief	160 X 10039 X
37	Strain relief	160 X 10049 X

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[160X10039X](#) [162A11899X](#) [162A11919X](#) [162A11929X](#)