



**USB Connector A Type PCB R/A**  
**SPECIFICATIONS**

**Materials**

Insulator: thermoplastic, glass filled, UL 94V-0

Contacts: Phosphor bronze

Plated: 10 $\mu$ " gold plated

SMD Plated: 120 $\mu$ " tin plated

Plastic: PBT

Shell: Copper alloy, tin plated

**Electrical**

Insulation Resistance: 1000 M $\Omega$  minimum


Contact Resistance: 30 m $\Omega$  Max. initial

Dielectric Withstanding Voltage: 750V AC for one minute

Current: 1.5 Ampere max. per contact at 30°C T-rise

Voltage: 30V AC (rms)

Temperature: -55°C ~85°C

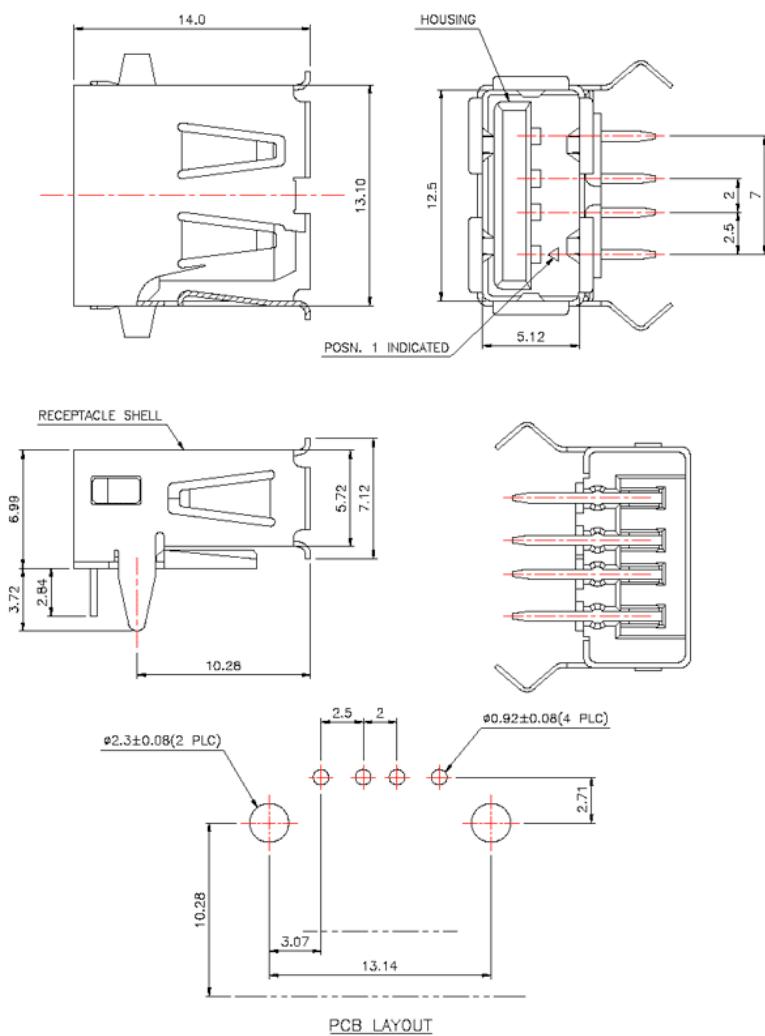

**Order Information**

**33UBA R - 04 S W 1 1**

**1. Series No.**  
33UBA

**3. No. of Contacts**  
04: 4 pin

**5. Insulator Color**  
W: White

**7. Packaging**  
1: Packed in tray

**2.Terminal Version**

R: Right angle

**4.Connector Type**

S: Female

**6. Shield**

1: W/O back shell

0: W/ back shell



File #: 127344



File #: LR97981

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CONEC:](#)

[33UBAR-04SW11](#)