


TYPE B

Female connector – straight and angled – 32 and 64 positions

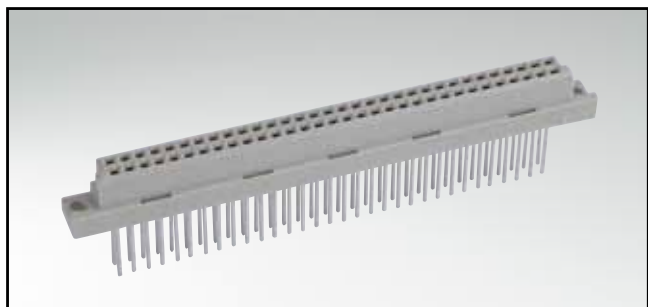



RoHS compliant

DESCRIPTION




- Solder pin, solder lug and wire wrap
- Quality class 3 (also available in quality class 2 or 1)
- Special assembly on request

PRODUCT DRAWING


PCB-hole pattern

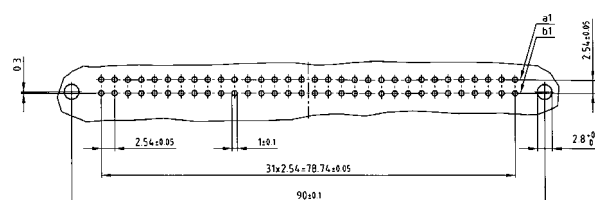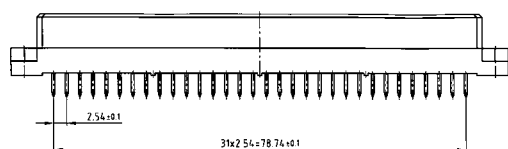


Panel cutout

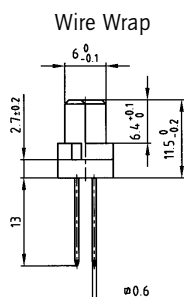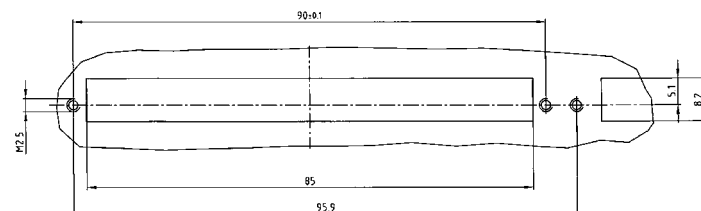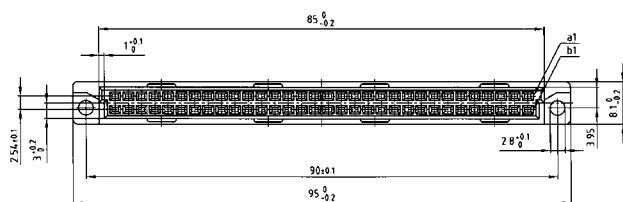


Solder pin straight 2.5 mm

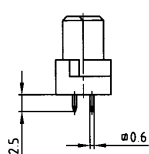


Solder pin straight 4 mm

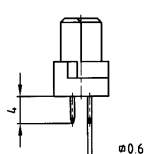


Solder lug

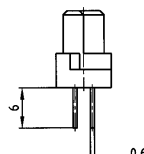

Solder pin angled

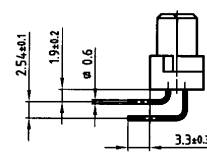

Solder pin straight 2.5 mm with clip

 

ORDER DATA

(Dim. = mm)

No. of Pos.	Row	• = contact, + = no contact					Wire Wrap	Solder pin straight 2.5 mm	Solder pin straight 4 mm	Solder lug	Solder pin angled	Solder pin straight 2.5 mm with clip
		Pos.	1	2	3	4	5					
32	a		•	•	•	•	•	122 A 10019 X	122 A 10049 X	122 A 10079 X	122 A 10109 X	122 A 10139 X
	b		+	+	+	+	+					122 A 13189 X
32	a		+	•	+	•	+	122 A 10029 X	122 A 10059 X	122 A 10089 X	122 A 10119 X	122 A 10149 X
	b		+	•	+	•	+					122 A 13199 X
64	a		•	•	•	•	•	122 A 10039 X	122 A 10069 X	122 A 10099 X	122 A 10129 X	122 A 10159 X
	b		•	•	•	•	•					122 A 13209 X

Clip for hole diameter 2.8 ± 0.1 mm, PCB thickness = 1.6 mm

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[122A13209X](#) [122A10099X](#) [122A10059X](#) [122A13199X](#) [122A10089X](#) [122A10069X](#) [122A10049X](#) [122A13189X](#)
[122A10119X](#) [122A10139X](#) [122A10149X](#) [122A10109X](#) [122A10079X](#) [122A10039X](#)