


D-SUB HIGH DENSITY – IP67

Solder cup – Precision machined contacts – Front mounting – For wire size AWG 22





RoHS compliant - CSA listed, File No.LR115000-1 UL listed, File No. E202784

SOCKET CONNECTOR


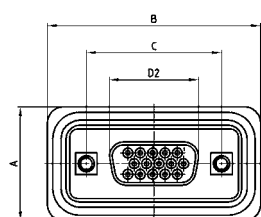


No. of pos.	A +0.2	B +0.2	C	D2 -0.25
15	21.10	39.40	25.00 $\begin{smallmatrix} +0.12 \\ -0.13 \end{smallmatrix}$	16.46
26	21.10	47.70	33.30 $\begin{smallmatrix} +0.15 \\ -0.10 \end{smallmatrix}$	24.79
44	21.10	61.40	47.04 ± 0.13	38.50
62	21.10	77.90	63.50 ± 0.13	54.96
78	23.90	75.50	61.10 $\begin{smallmatrix} +0.14 \\ -0.11 \end{smallmatrix}$	52.55

Mounting style: Front spacer

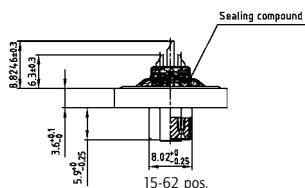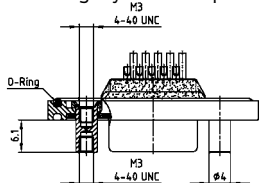


Mounting style: Front spacer and rear mounting stud

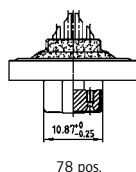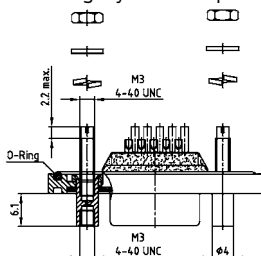

DESCRIPTION



- Suitable for wire size **AWG 22**
- Mounting styles:
 - with M3 or 4-40 UNC front spacer
 - with M3 or 4-40 UNC front spacer and rear mounting stud
- Quality class 3 (also available in quality class 1)
- Shell: Brass tin plated (stainless steel available on request)
- Nickel plated die-cast frame
(Black plastic frame on request)

PLUG CONNECTOR


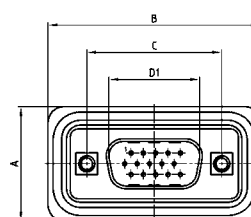


No. of pos.	A +0.2	B +0.2	C	D1 +0.25	E -0.30
15	21.10	39.40	25.00 $\begin{smallmatrix} +0.12 \\ -0.13 \end{smallmatrix}$	16.79	5.82
26	21.10	47.70	33.30 $\begin{smallmatrix} +0.15 \\ -0.10 \end{smallmatrix}$	25.12	5.82
44	21.10	61.40	47.04 ± 0.13	38.84	5.69
62	21.10	77.90	63.50 ± 0.13	55.30	5.69
78	23.90	75.50	61.10 $\begin{smallmatrix} +0.14 \\ -0.11 \end{smallmatrix}$	52.68	5.69

Mounting style: Front spacer

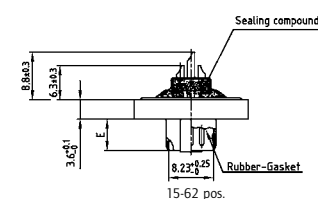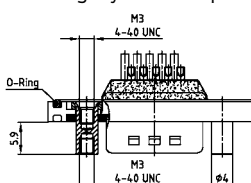

Mounting style: Front spacer and rear mounting stud

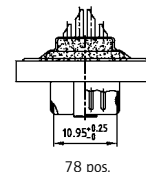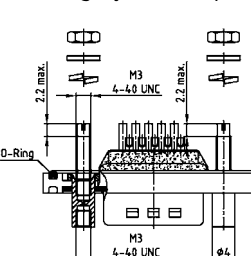

ORDER DATA

SOCKET CONNECTOR		
No. of pos.	Mounting style	Part Number
15	M3 Front spacer	6 HDD15SAM99B40 X
26	M3 Front spacer	6 HDD26SAM99B40 X
44	M3 Front spacer	6 HDD44SAM99B40 X
62	M3 Front spacer	6 HDD62SAM99B40 X
78	M3 Front spacer	6 HDD78SAM99B40 X
15	4-40 UNC Front spacer	6 HDD15SAM99B50 X
26	4-40 UNC Front spacer	6 HDD26SAM99B50 X
44	4-40 UNC Front spacer	6 HDD44SAM99B50 X
62	4-40 UNC Front spacer	6 HDD62SAM99B50 X
78	4-40 UNC Front spacer	6 HDD78SAM99B50 X
15	4-40 UNC Front spacer and rear mounting stud	6 HDD15SAM99B70 X
26	4-40 UNC Front spacer and rear mounting stud	6 HDD26SAM99B70 X
44	4-40 UNC Front spacer and rear mounting stud	6 HDD44SAM99B70 X
62	4-40 UNC Front spacer and rear mounting stud	6 HDD62SAM99B70 X
78	4-40 UNC Front spacer and rear mounting stud	6 HDD78SAM99B70 X

PLUG CONNECTOR		
No. of pos.	Mounting style	Part Number
15	M3 Front spacer	6 HDD15PAM99B40 X
26	M3 Front spacer	6 HDD26PAM99B40 X
44	M3 Front spacer	6 HDD44PAM99B40 X
62	M3 Front spacer	6 HDD62PAM99B40 X
78	M3 Front spacer	6 HDD78PAM99B40 X
15	4-40 UNC Front spacer	6 HDD15PAM99B50 X
26	4-40 UNC Front spacer	6 HDD26PAM99B50 X
44	4-40 UNC Front spacer	6 HDD44PAM99B50 X
62	4-40 UNC Front spacer	6 HDD62PAM99B50 X
78	4-40 UNC Front spacer	6 HDD78PAM99B50 X
15	4-40 UNC Front spacer and rear mounting stud	6 HDD15PAM99B70 X
26	4-40 UNC Front spacer and rear mounting stud	6 HDD26PAM99B70 X
44	4-40 UNC Front spacer and rear mounting stud	6 HDD44PAM99B70 X
62	4-40 UNC Front spacer and rear mounting stud	6 HDD62PAM99B70 X
78	4-40 UNC Front spacer and rear mounting stud	6 HDD78PAM99B70 X

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[6HDD26PAM99B70X](#) [6HDD15SAM99B40X](#) [6HDD44PAM99B70X](#)