


D-SUB STANDARD – IP67

Interface adapter – Connector Saver

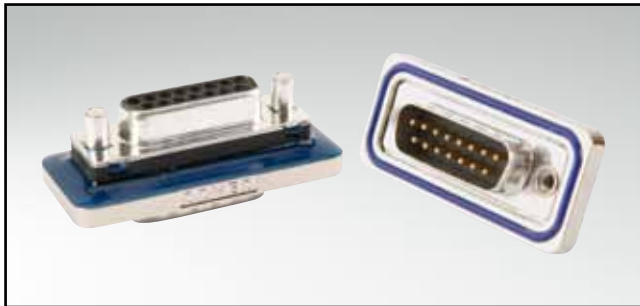


RoHS compliant




DESCRIPTION

- Plug to socket adapter
- Mounting style:
4-40 UNC threaded rear spacer including hex locking bolt
- Precision machined contacts
- Quality class 3 (also available in quality class 1)
- Shell: Brass tin plated
- Nickel plated die-cast frame

PRODUCT DRAWING

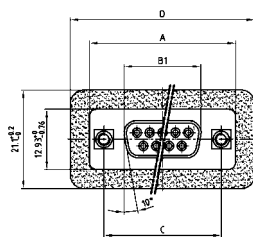

No. of Pos.	A -0.76	B1 -0.25	B2 +0.25	C	D +0.2
9	31.19	16.46	16.79	25.00 $+0.12/-0.13$	39.40
15	39.52	24.79	25.12	33.30 $+0.15/-0.10$	47.70
25	53.42	38.50	38.84	47.04 $+0.13$	61.40
37	69.70	54.96	55.30	63.50 $+0.13$	77.90

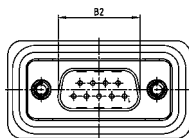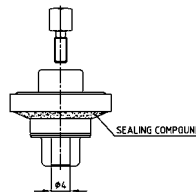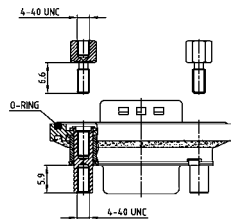

ORDER DATA

ADAPTER PLUG CONNECTOR - SOCKET CONNECTOR

No. of pos.	Mounting style 4-40 UNC	Part Number
09	Threaded rear spacer	6 STD09AAA99B90 X
15	Threaded rear spacer	6 STD15AAA99B90 X
25	Threaded rear spacer	6 STD25AAA99B90 X
37	Threaded rear spacer	6 STD37AAA99B90 X

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[15-000673](#) [6STD09SAM99B70X](#) [6HDD78PAR99E10X](#) [6HDD44SAR99E20X](#) [6HDD15PAM99B30X](#)
[6STD50SAM99B70X](#) [4HDD62PAM99A10X](#) [15-000863](#) [6HDD15SAM99B30X](#) [15-000563](#) [6STD15PAM99B70X](#)
[6STD50PAM99B70X](#) [6STD37PAM99B70X](#) [6HDD26SAM99B30X](#) [6STD37SAM99B40X](#) [4HDD15SAM99A10X](#)
[4HDD78PAM99A10X](#) [15-000843](#) [6STD25PAM99B70X](#) [6HDD15SAR99E20X](#) [6HDD26PAM99B30X](#)
[6HDD78PAM99B30X](#) [15-000853](#) [15-000723](#) [6STD25SAM99B70X](#) [6STD15SAM99B70X](#) [6STD09PAM99B70X](#) [15-](#)
[000813](#) [15-000833](#) [4HDD78SAM99A10X](#) [15-000933](#) [15-000873](#) [6STD09AAA99B90X](#)