





D-SUB STANDARD

Interface adapter – Connector Saver



RoHS compliant – CSA listed, File No.: LR 115000-1 – UL listed, File No.: E202784

PRODUCT DRAWING

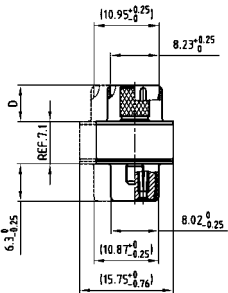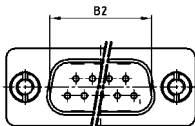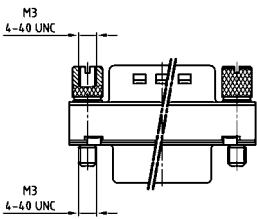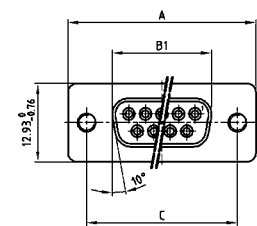

50 pos. = Dim. in (_)

DESCRIPTION

- Variation plug to socket
- Precision machined contacts
- Threaded lock, 4-40 UNC or M3, on the plug side
- Threaded lock on the socket side available on request
- Quality class 3 (also available in quality class 1)
- Shell: Steel tin plated

No. of pos.	A -0.76	B1 -0.25	B2 +0.25	C	D -0.30
09	31.19	16.46	16.79	25.00 ±0.12	6.12
15	39.52	24.79	25.12	33.30 ±0.15 ±0.10	6.12
25	53.42	38.50	38.84	47.04 ±0.13	5.99
37	69.70	54.96	55.30	63.50 ±0.13	5.99
50	67.31	52.55	52.68	61.10 ±0.14 ±0.1	5.99

ORDER DATA

PLUG CONNECTOR – SOCKET CONNECTOR		
No. of pos.	Mounting style	Part Number
09	4-40 UNC Threaded lock	163 A 50009 X
15	4-40 UNC Threaded lock	163 A 50019 X
25	4-40 UNC Threaded lock	163 A 50029 X
37	4-40 UNC Threaded lock	163 A 50039 X
50	4-40 UNC Threaded lock	163 A 50049 X
09	M3 Threaded lock	163 A 50059 X
15	M3 Threaded lock	163 A 50069 X
25	M3 Threaded lock	163 A 50079 X
37	M3 Threaded lock	163 A 50089 X
50	M3 Threaded lock	163 A 50099 X

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[163A50099X](#) [163A50059X](#) [163A50089X](#) [163A50069X](#)