


TYPE E

Male connector – angled – 32 and 48 positions


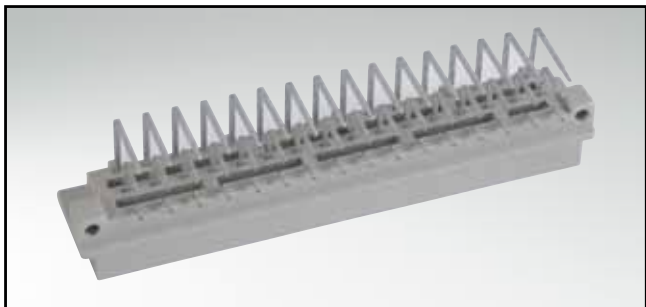


RoHS compliant

DESCRIPTION


- Solder pin
- Quality class 3 (also available in quality class 2 or 1)

PRODUCT DRAWING

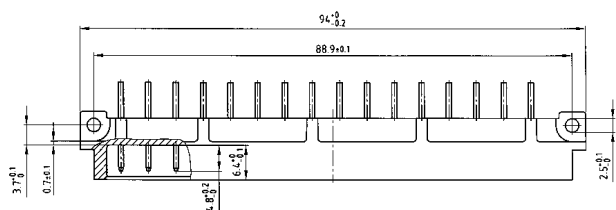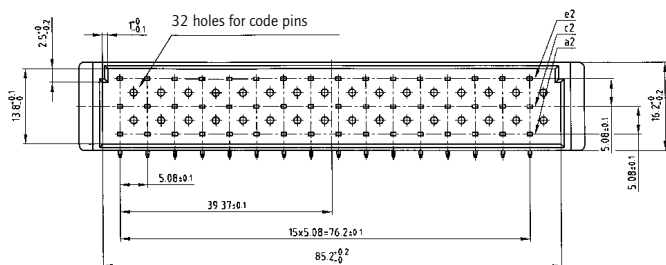


PCB-hole pattern

Solder pin angled 5.08 mm


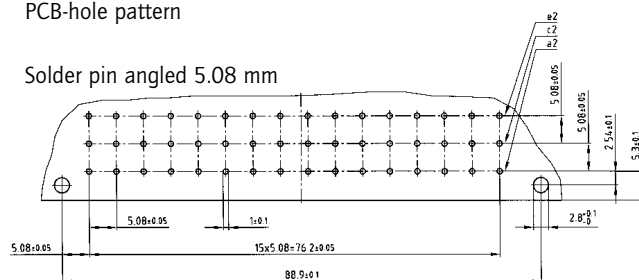


Solder pin angled 2.54 mm

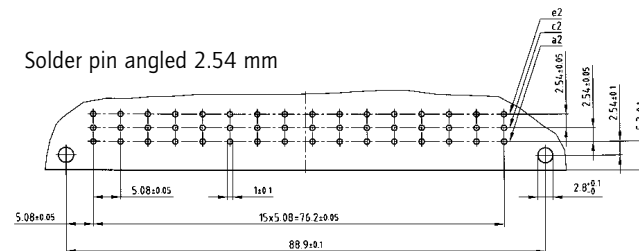

Solder pin angled
contact spacing 5.08 mm

Solder pin angled
contact spacing 2.54 mm

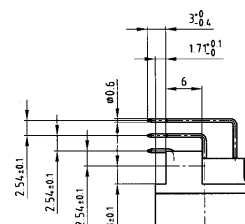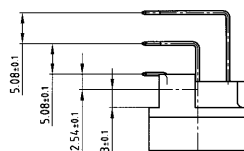

ORDER DATA

(Dim. = mm)

No. of Pos.	Row	• = contact, + = no contact				Solder pin angled contact spacing 5.08 mm	Solder pin angled contact spacing 2.54 mm
		Pos.	2	4	6 ...		
32	e		+	+	+	121 A 20789 X	121 A 20779 X
	c		•	•	•		
	a		•	•	•		
32	e		•	•	•	121 A 20809 X	121 A 20799 X
	c		+	+	+		
	a		•	•	•		
48	e		•	•	•	121 A 10859 X	121 A 10849 X
	c		•	•	•		
	a		•	•	•		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[121A20809X](#) [121A20779X](#) [121A20789X](#)