



D-SUB SHIELDED CAP

Metal design – Shielded – Jack screws



RoHS compliant

SOCKET CONNECTOR

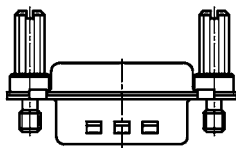
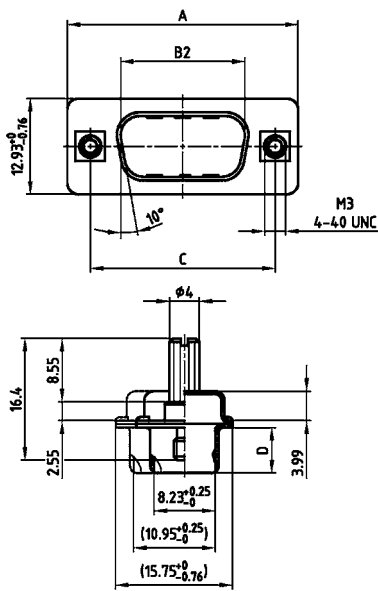


50-pos.= Dim. in (..)

DESCRIPTION

- Shielded cap protecting against EMI/RFI
- Material: Steel tin plated
- Mounting style:
 - with jack screw M3 or
 - with jack screw 4-40 UNC

PLUG CONNECTOR

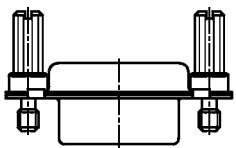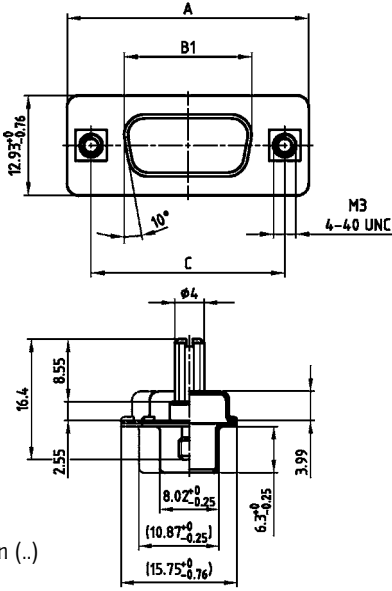

No. of pos.	A _{0.76}	B1 _{0.25}	B2 _{0.25}	C	D _{0.3}
09	31.19	16.46	16.79	25.00 +0.12	6.12
15	39.52	24.79	25.12	33.30 +0.15 -0.10	6.12
25	53.42	38.50	38.84	47.04 +0.13	5.99
37	69.70	54.96	55.30	63.50 +0.13	5.99
50	67.31	52.55	52.68	61.10 +0.14 -0.11	5.99

ORDER DATA

SHIELDED CAP FOR SOCKET CONNECTOR			SHIELDED CAP FOR PLUG CONNECTOR		
No. of pos.	Design	Part Number	No. of pos.	Design	Part Number
09	Metal / M3 Jack screw	165X16859X	09	Metal / M3 Jack screw	165X16959X
15	Metal / M3 Jack screw	165X16869X	15	Metal / M3 Jack screw	165X16969X
25	Metal / M3 Jack screw	165X16879X	25	Metal / M3 Jack screw	165X16979X
37	Metal / M3 Jack screw	165X16889X	37	Metal / M3 Jack screw	165X16989X
50	Metal / M3 Jack screw	165X16899X	50	Metal / M3 Jack screw	165X16999X
09	Metal / 4-40 UNC Jack screw	165X16909X	09	Metal / 4-40 UNC Jack screw	165X17009X
15	Metal / 4-40 UNC Jack screw	165X16919X	15	Metal / 4-40 UNC Jack screw	165X17019X
25	Metal / 4-40 UNC Jack screw	165X16929X	25	Metal / 4-40 UNC Jack screw	165X17029X
37	Metal / 4-40 UNC Jack screw	165X16939X	37	Metal / 4-40 UNC Jack screw	165X17039X
50	Metal / 4-40 UNC Jack screw	165X16949X	50	Metal / 4-40 UNC Jack screw	165X17049X

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

CONEC:

[165X16859X](#) [165X17019X](#) [165X17029X](#) [165X16959X](#) [165X16889X](#) [165X17039X](#)