


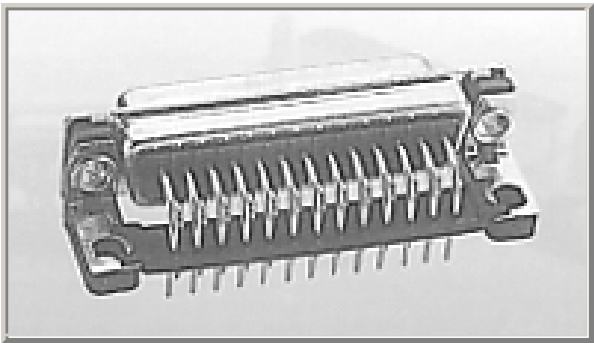


Solder pin angled .370" with mounting, grounding bracket and threaded insert


Directive 2002/95/EC
„RoHS“
Compliant

(click on the schematic(s) for a more detailed view)

Socket connector

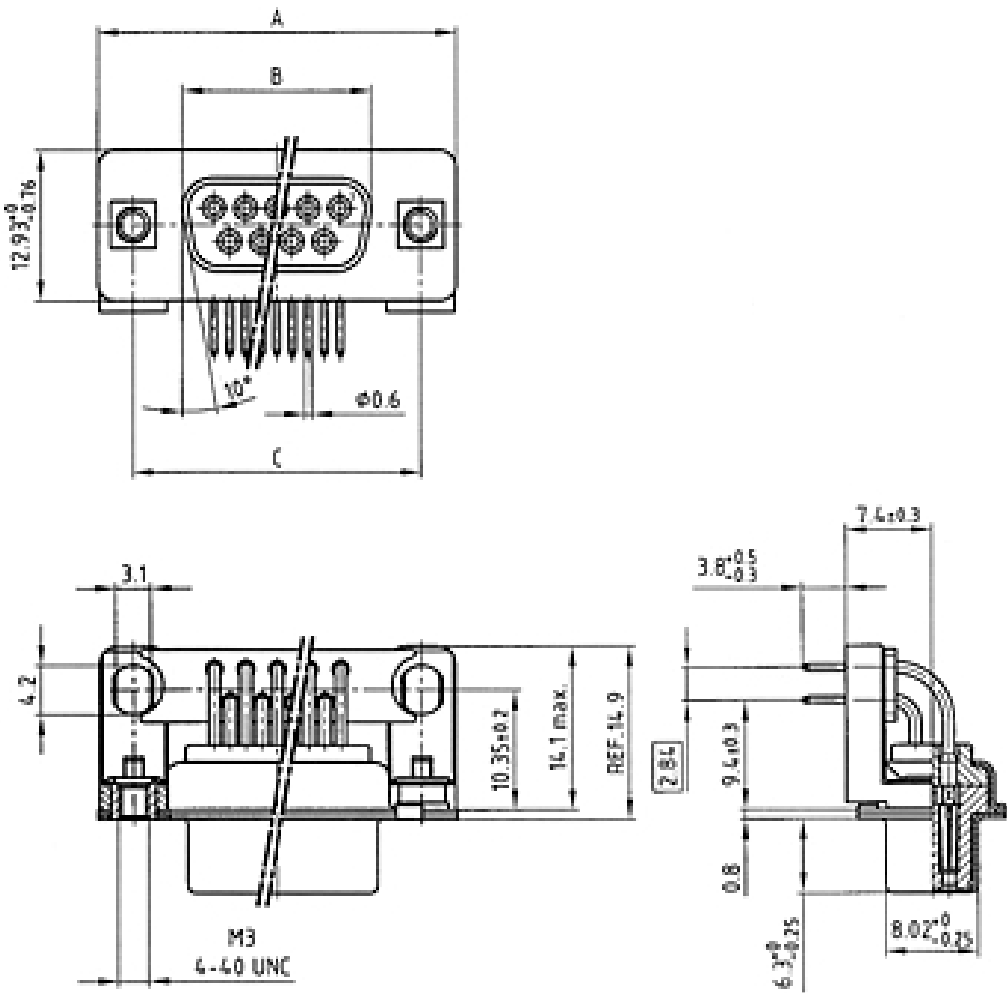

Plug connector

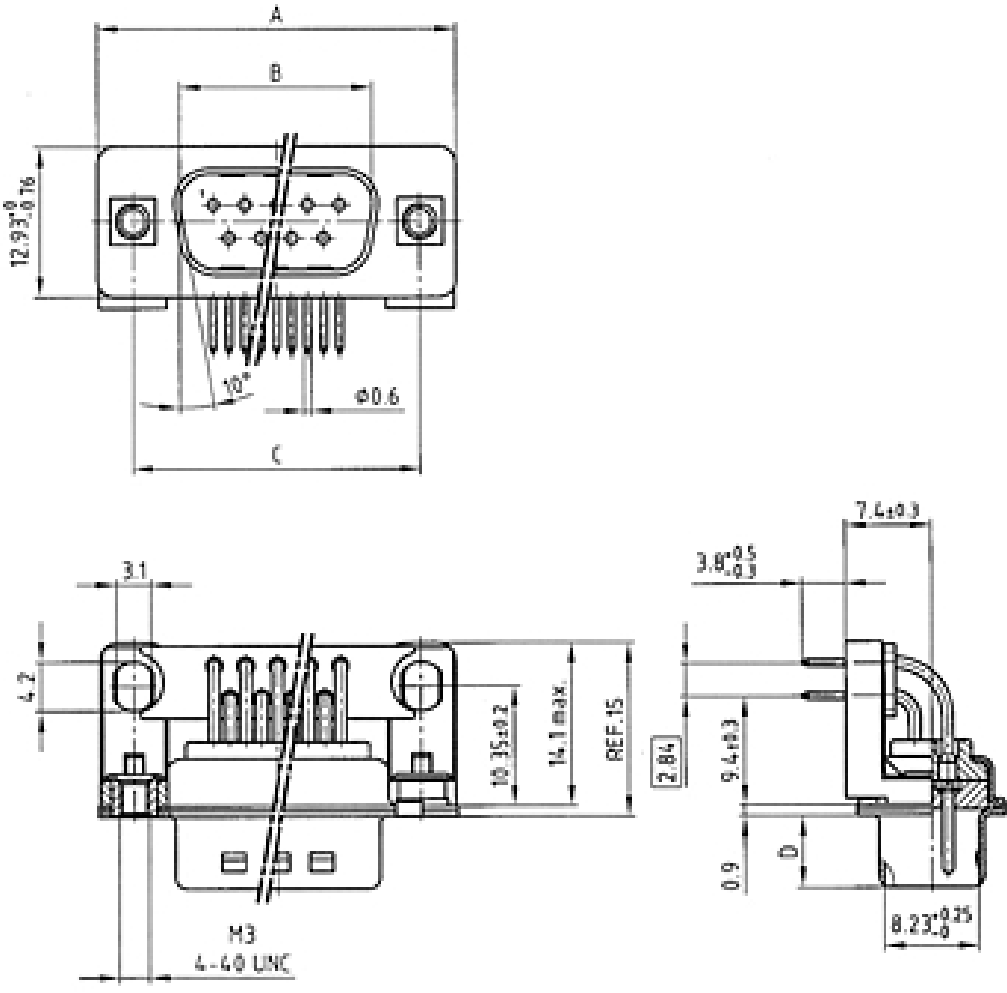

Socket Connector			
No. of pos.	A - 0,76	B - 0,25	C
09	31,19	16,46	25,00 + 0,12 - 0,13
15	39,52	24,79	33,30 + 0,15 - 0,10
25	53,42	38,50	47,04 ± 0,13
37	69,70	54,96	63,50 ± 0,13

Plug Connector				
No. of pos.	A - 0,76	B + 0,25	C	D - 0,30
09	31,19	16,79	25,00 + 0,12 - 0,13	6,12
15	39,52	25,12	33,30 + 0,15 - 0,10	6,12
25	53,42	38,84	47,04 ± 0,13	5,99
37	69,70	55,30	63,50 ± 0,13	5,99

Part Numbers

No.of Pos.	Socket connector tin -plated	
	4-40 UNC	M3
09	164 A 19179 X	164 A 19219 X
15	164 A 19189 X	164 A 19229 X
25	164 A 19199 X	164 A 19239 X
37	164 A 19209 X	164 A 19249 X

No.of Pos.	Plug connector tin -plated with ground indent	
	4-40 UNC	M3
09	163 A 18749 X	163 A 18789 X
15	163 A 18759 X	163 A 18799 X
25	163 A 18769 X	163 A 18809 X
37	163 A 18779 X	163 A 18819 X

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[CONEC:](#)

[163A18769X](#)