

# SPECIFICATION

## 1.General Characteristics:

0.5mm Board To Board Double Slot Type Male XXP  
SMT 180° With Post Stacking Height=6.0mm With Cap

## 2.Material&Finish:

Housing:LCP(UL94V-0),White  
Contact:Phosphor Bronze,Gold Plated Over Nickel

## 3.Electrical Characteristics:

Current Rating:0.5A AC/DC  
Voltage Rating:50V AC/DC  
Withstanding Voltage:100V AC For One Minute  
Contact Resistance:30 Milliohms Max.  
Insulation Resistance:100 Megaohms Min. At 100V DC

## 4.Environmental Characteristics:

Operation Temperature Range:-20°C~+105°C



## 5.RoHS Compliant

Type X:


| Type | Pin    | Dim.(mm) |
|------|--------|----------|
| 1    | 10~48  | 5.00     |
| 2    | 50~120 | 12.0     |

| Part No.(Socket) | Part No.(Plug) | A1   | B1   |
|------------------|----------------|------|------|
| 1660             | 1661           | 4.40 | 6.00 |

| Pin | A     | B     | C     | D     |
|-----|-------|-------|-------|-------|
| 10  | 5.20  | 2.00  | 2.96  | 3.90  |
| 14  | 6.20  | 3.00  | 3.96  | 4.90  |
| 20  | 7.70  | 4.50  | 5.46  | 6.40  |
| 30  | 10.20 | 7.00  | 7.96  | 8.90  |
| 40  | 12.70 | 9.50  | 10.46 | 11.40 |
| 50  | 15.20 | 12.00 | 12.96 | 13.90 |
| 60  | 17.70 | 14.50 | 15.46 | 16.40 |
| 70  | 20.20 | 17.00 | 17.96 | 18.90 |
| 80  | 22.70 | 19.50 | 20.46 | 21.40 |
| 90  | 25.20 | 22.00 | 22.96 | 23.90 |
| 100 | 27.70 | 24.50 | 25.46 | 26.40 |
| 120 | 32.70 | 29.50 | 30.46 | 31.40 |

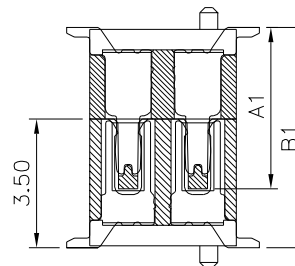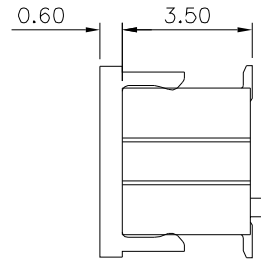

Mating Draw (Ref.)

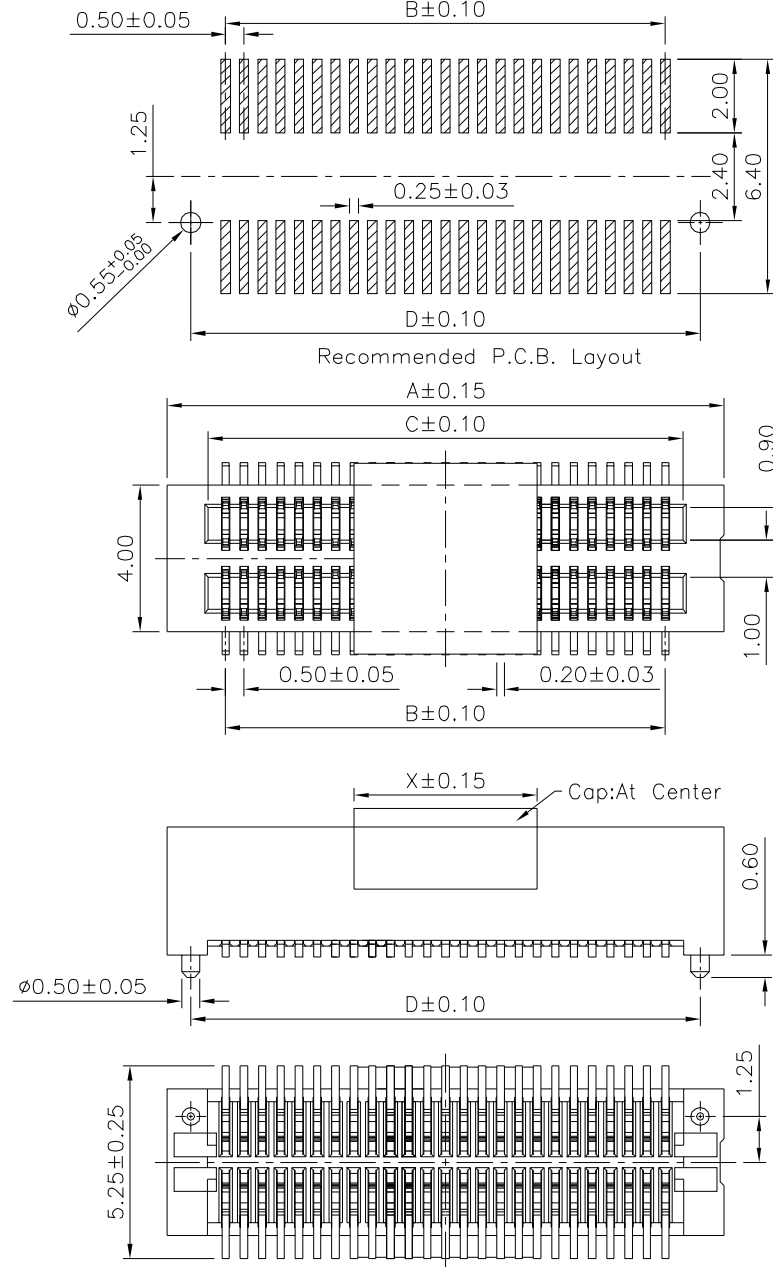

**4UCON**

元化興業股份有限公司  
4UCON TECHNOLOGY INC.

DRAWING No.

19022

SCALE

NONE

APPROVED BY

MEI

CHECKED BY

HZF

DRAWING BY

CYP

REV.

 
BO

UNLESS OTHERWISE  
SPECIFIED  
TOLERANCES ARE

.X ±0.2

.XX ±0.15

UNIT  
mm



NO. REV.

BO NEW RELEASE

REVISIONS

HZF

09/25/2018

CHK

DATE

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[SparkFun Electronics:](#)

[PRT-16891](#)