





Aqua Tech Trading Corp. Ltd, located in Chongqing, China, which is focused on developing, manufacturing and distributing water valves and associated water used equipments.



We are a rapidly expanding company perceived as a growing force in the area of fluid control, we attribute our success to extensive product knowledge, our understanding of and responsiveness to market requirements and the value we place on excellent customer service.



Aqua Valves have been widely used in agriculture, water supply, water control and water purification industries.

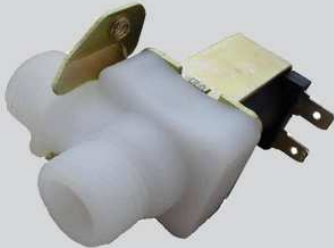
The following products are our solenoid valves.

			
Model No.	AQT15S	Model No.	AQT15SC
Thread Size	1/2" BSP inlet and outlet	Thread Size	1/2" BSP inlet and outlet
Material	PET	Material	PET
Working Temp	0-40℃	Working Temp	0-40℃
Working Pressure	0.02~0.8MPa	Working Pressure	0.02~0.8MPa
Voltage	DC12V,DC24V,AC220V	Voltage	AC/DC 6/9/12/24/36110/220V
Voltage Range	15%	Voltage Range	15%
Style	Closed Valve	Style	Closed Valve
Working Environment	Water, Gas and Oil	Working Environment	Water, Gas and Oil
Lifespan	More than 200,000 times	Lifespan	More than 200,000 times
Certification	CQC/CE	Certification	CQC/CE
Usage: Suit for many kinds of washing machine, drinking water machine, sanitary equipment, water heater, etc. Our products have passed CQC and CE. And it meets the requirement of WEEE and ROHS.			


			
Model No.	AQT10S	Model No.	AQT15SL
Thread Size	1/2"10mm BSP inlet and outlet	Thread Size	1/2" BSP inlet and outlet
Material	Plastic and Brass	Material	Plastic and Brass
Working Temp	0~60/100℃	Working Temp	0~100℃
Working Pressure	0.02~0.8MPa, static pressure ≥ 2.0MPa	Working Pressure	400 millimeter water column
Voltage	DC12V,DC24V,AC220V	Voltage	AC/DC 6/9/12/24/36110/220V
Voltage Range	15%	Voltage Range	15%
Style	Closed Valve	Style	Opened Valve
Working Environment	Water, Gas and Oil	Working Environment	Water, Gas and Oil
Lifespan	More than 200,000 times	Lifespan	More than 200,000 times
Certification	CQC/CE	Certification	CQC/CE
Usage: washing machine used solenoid valve		Usage: Specially working in low pressure environment	

			
Model No.	AQT12SL	Model No.	AQT12SLT
Thread Size	1/2"BSP inlet and 12mm outlet	Thread Size	1/2"BSP inlet and 12mm outlet
Material	Plastic and Brass	Material	Plastic and Brass
Working Temp	0~100℃	Working Temp	0~100℃
Working Pressure	400 millimeter water column	Working Pressure	400 millimeter water column
Voltage	DC12V,DC24V,AC220V	Voltage	AC/DC 6/9/12/24/36110/220V
Voltage Range	15%	Voltage Range	15%
Style	Opened Valve	Style	Opened Valve
Working Environment	Water, Gas and Oil	Working Environment	Water, Gas and Oil
Lifespan	More than 200,000 times	Lifespan	More than 200,000 times
Certification	CQC/CE	Certification	CQC/CE

Usage: Specially working in low pressure environment		Usage: Specially working in low pressure environment	
			
Model No.	AQT15SCB	Model No.	AQT15SP
Thread Size	1/2"BSP inlet and let	Thread Size	1/2"BSP inlet and 12mm outlet
Material	Brass	Material	Plastic
Working Temp	0~100℃	Working Temp	1℃-75℃
Working Pressure	0.02~0.8MPa	Flow rate	0.02Mpa ≥ 3 L/min, 0.1Mpa ≥ 12 L/min, 0.8Mpa ≥ 35 L/min
Voltage	DC12V,DC24V,AC220V	Voltage	AC220V
Voltage Range	15%	Voltage Range	15%
Style	Closed Valve	Resistance Coil	4.75K Ω ± 0.25K Ω (20℃)
Working Environment	Water, Gas and Oil	Working Environment	Water
Lifespan	More than 200,000 times	Lifespan	More than 1,000,000times
Certification	CQC/CE	Certification	0
Usage: Specially working in low pressure environment		Usage: Water used solenoid valve	

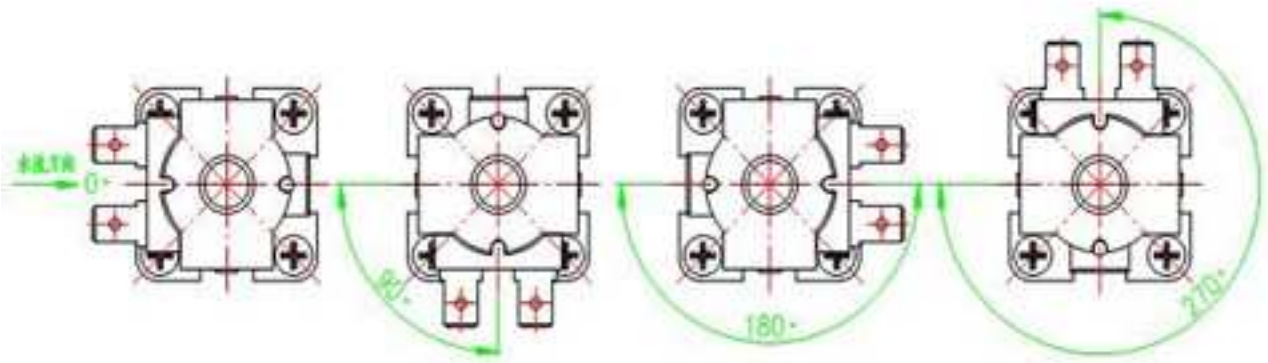

And the diagram picture of these valves as follows:

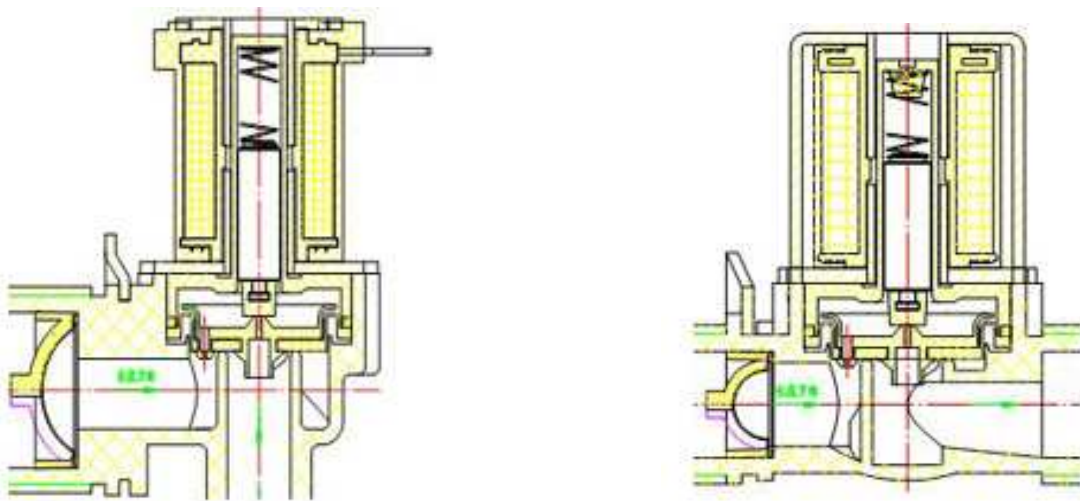

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[SparkFun Electronics:](#)

[ROB-10456](#)