




3W RGB LED Module



Product Description

- This is a High Power RGB Module in a aluminum PCB board, each channel 3W
- When it light up all 3 color together in same time, the board will very hot and it request
- To mount into a another board for heat disipation , please notice the Voltage per color during application

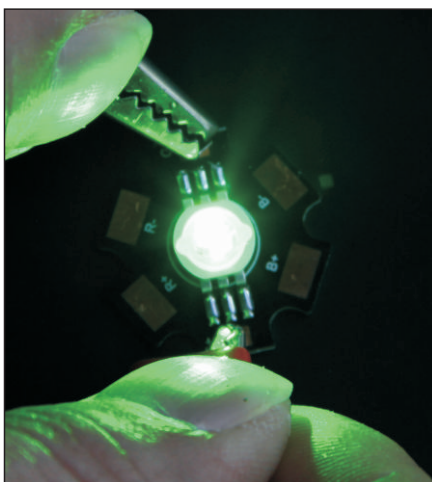




Product Datasheet

Product	Number	M018001MA3LZ
Light	Source	Imitation lumen lamp beads
Beam	Angle	140°
Size	(mm)	18 ϕ
Emitting	Color	RGB
Operating	Voltage	R: 2.2-2.6V G: 3.2-3.8V B: 3.2-3.8V
Power	(W/M)	W: 3.6W
wavelength		R: 620 G: 520 B: 460
Waterproof	Rating	IP20
Operation	Temperature	-30℃-50℃

Outline Dimension

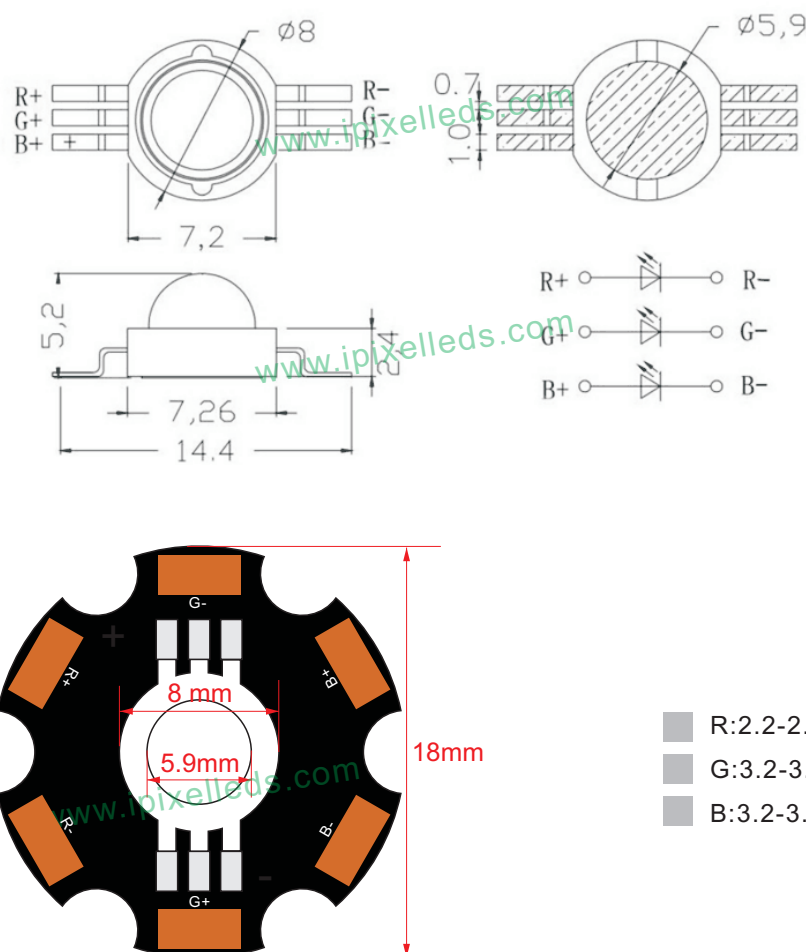

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[SparkFun Electronics:](#)

[DD-15320](#)